




DATA SHEET

P/N: CL10 9R4120

Mechanical Specifications

D	10.0 mm Max
T	3.5 mm Max
Lead Diameter	0.5 mm $\pm$ 0.1mm
S	5.0 mm $\pm$ 0.5mm
L	7.0 mm Nom
B	4.0 mm Nom

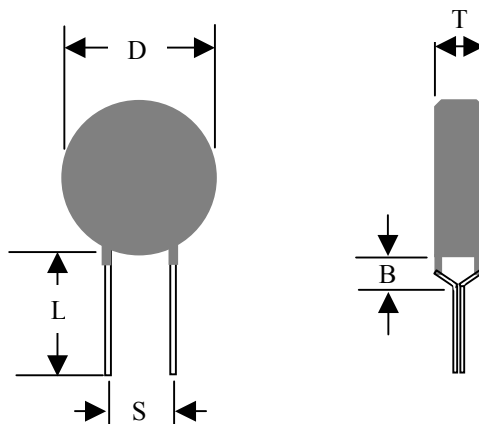

Electrical Specifications

Resistance @ 25°C	9.4 $\Omega \pm 30\%$
Transition Temp	100 Deg C
Max Voltage Rating	250 Vrms
Switch Current	260 mA
Continuous Current @ 25°C	130 mA
Residual current at 100% of Max voltage	13 mA

Ametherm, Inc
961 Fairview Drive
Carson City, NV 89701
Telephone: **800-808-2434**
Fax: 775 884-0670
www.Ametherm.com

Reliability Delivered On Time

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Ametherm:](#)

[CL109R4120](#)