


Mechanical Specifications

D	20.0 mm Max
T	6.0 mm Max
Lead Diameter	1.0 mm Nom
S	7.8 mm Nom
L	38.0 mm Min
Straight Leads	Standard

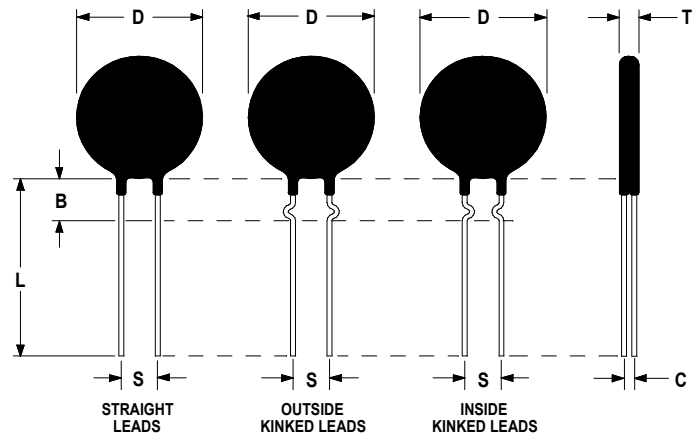

Electrical Specifications

Resistance @ 25°C	25.0 $\Omega \pm 25\%$
Transition Temp	120 Deg C
Max voltage Rating	480 v rms
Maximum Energy rating	400 Joules.
Switch Current @ 25°C	0.600A
Continuous Current @ 25°C	0.300A
Heat Capacity	2.0 Joules/°C
Dissipation Constant	22.50 mW/°C
Thermal Time Constant	65.0 seconds
Max Body Temperature @ Max voltage	172°C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Ametherm:](#)

[CL20 250120](#) [CL20 250120-B](#) [CL20 250120-A](#)