



Part Number: MM35 1R050-DIN

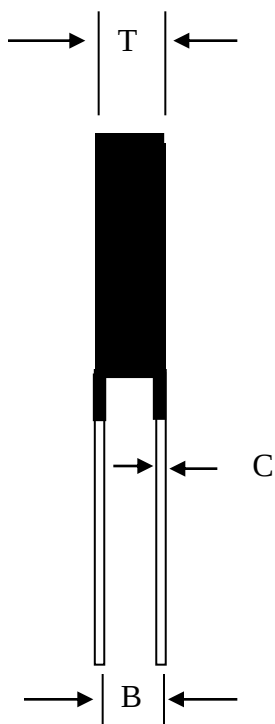

Electrical Specifications:

Resistance @ 25°C	1.0 $\Omega \pm 25\%$
Max Steady State Current Up to 65°C	50.0 A
Max recommended energy rating (Joules)	1200.0 Joules
Rhot @100% Steady State Current	0.010 Ω
Rhot @75% Steady State Current	0.017 Ω
Rhot @50% Steady State Current	0.030 Ω
Rhot @25% Steady State Current	0.078 Ω
Body Temperature @ 100% Current rating	214°C
Max Recommended Voltage	680V
Material Type	B
Max Power	38.4W

Note: 2X 35DM2R0-X

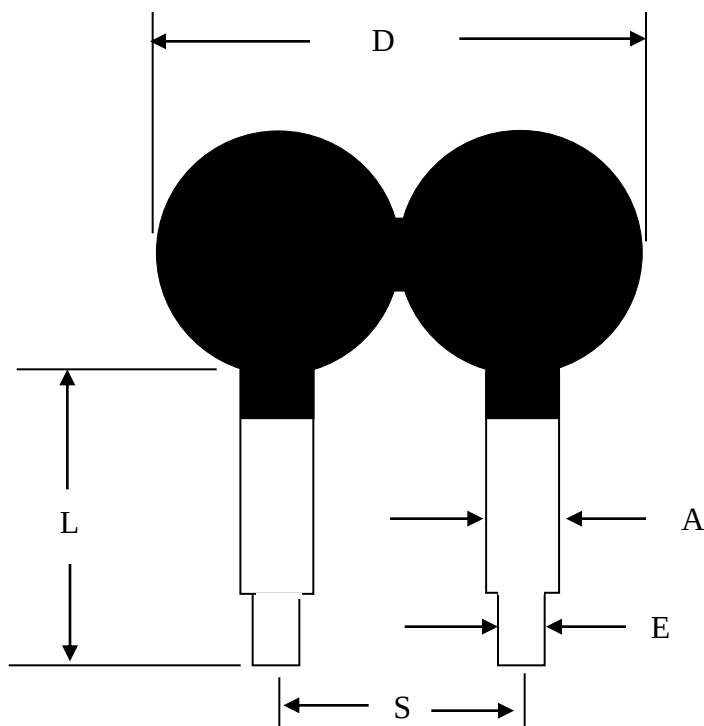

Mechanical Specifications:

D	68.0mm Max
T	8.5mm Max
S	34.0mm Nom
L	38.5 mm Nom
A (Lead Width)	9.6mm Nom
B	6.0mm Nom
C (Lead Thickness)	0.8mm Nom
E	5.7mm Nom

Ametherm, Inc. 961 Fairview Drive Carson City, NV 89701
Telephone: (800) 808-2434 (775) 884-2434 Fax: (775) 884-0670
www.ametherm.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Ametherm:](#)

[MM35 1R050-DIN](#) [MM35 1R050](#)