

Solder Cup Cable Connectors

The PowerAmp connector family is a 1- and 2-row high reliability connector solution with a pitch of 5.72 millimeters (0.225"). Available with 5 to 20 contacts and rated up to 23A per contact make it ideal for robust power connections. The connectors can also be customized to address unique design requirements.

- Current rating up to 23A per contact
- High vibration and shock resistant
- Withstands extreme temperatures of -65°C to +125°C
- Accepts wire sizes up to AWG 12 (4 mm²)
- UL94V-0 flammability rated insulator
- UL Approved, UL 1977 ECBT2.E466640



Part Number Builder

iP	Rows	Body Style	Mounting Ears	Size	Termination	Hardware Style
Series	1 2	P Plug R Receptacle	0 Without	05 10 20	PSC Pin: Vertical Solder Cup SSC Socket: Vertical Solder Cup	J Fixed Jackset JTB Turning Jackset QTT-1 Quarter Turn (Turning) QTF-1 Quarter-Turn (Fixed)

Technical Information

Material Specifications

Insulator Material:
Glass-filled PPS (polyphenylene sulfide)

Insulator Color: White

Material (Contacts): Pins: copper alloy
Sockets: beryllium copper

Terminal Material: Copper alloy

Plating (Contacts):
Minimum 15 µin Au over 30 µin Ni

Hardware: Stainless steel

UL File: SE466640

Electromechanical Performance

Rated Current: 23A per contact

Durability: ≥ 250 mating cycles

Test Voltage: 2,000 V AC for 1 minute

Insulation Resistance: 5 GΩ min.

Contact Resistance: 1 mΩ max.

Insertion Force (Max): 4 oz. (4.45N) per contact

Withdrawal Force (Min.):
0.5 oz. (0.14N) per contact


Environmental Specifications

Operating Temperature: -65° to +125°C

Vibration: 10Hz to 2,000Hz, 1.52mm, 147.1m/s² (15G), duration 12h


RoHS: Compliant

iSeries
BASED ON MIL-SPEC. BUILT FOR INDUSTRIAL.

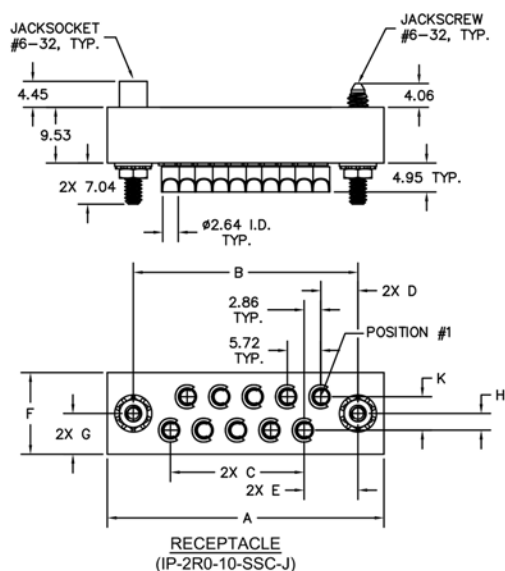


NOTES:
 SIZE 5 - SINGLE ROW
 SIZE 10 - 2-ROW STAGGERED GRID
 SIZE 20 - 2-ROW SQUARE GRID

	DIMENSIONS								
SIZE	A	B	C	D	E	F	G	H	K
5	44.45	35.56	22.86	6.35	N/A	9.53	4.78	N/A	N/A
10	47.29	38.40	22.86	6.35	9.22	13.97	6.99	2.86	5.72
20	73.03	64.14	51.44	6.35	6.35	13.97	6.99	2.86	5.72

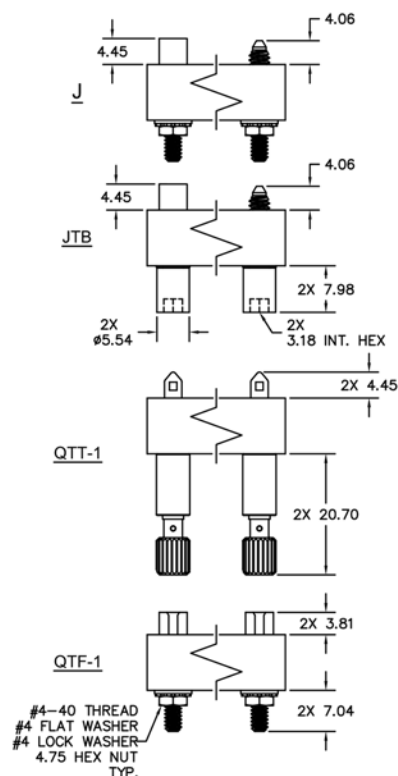


HARDWARE OPTIONS
 (J, JTB, QTT-1, QTF-1)

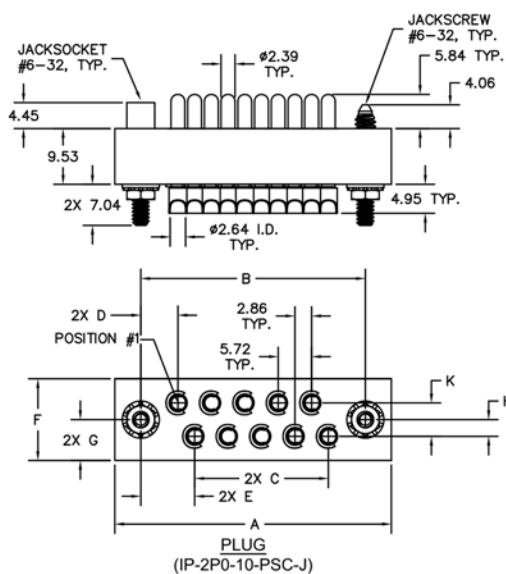

NOTES:
 SIZE 5 - SINGLE ROW
 SIZE 10 - 2-ROW STAGGERED GRID
 SIZE 20 - 2-ROW SQUARE GRID

	DIMENSIONS								
SIZE	A	B	C	D	E	F	G	H	K
5	44.45	35.56	22.86	6.35	N/A	9.53	4.78	N/A	N/A
10	47.29	38.40	22.86	6.35	9.22	13.97	6.99	2.87	5.72
20	73.03	64.14	51.44	6.35	6.35	13.97	6.99	2.87	5.72

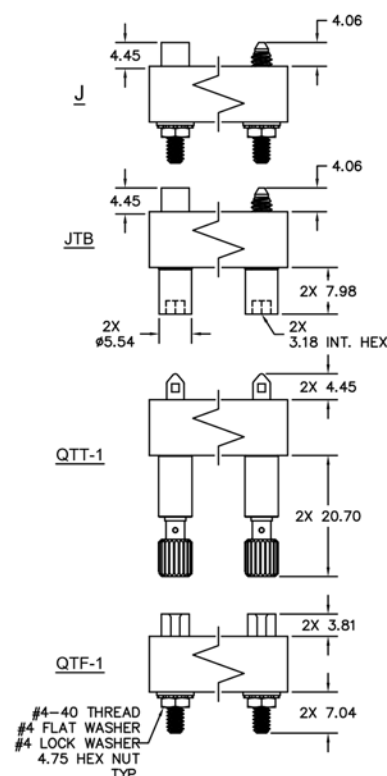

HARDWARE OPTIONS
 (J, JTB, QTT-1, QTF-1)

All dimensions
 in millimeters.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AirBorn:

[IP-1P0-05-PSC-J](#) [IP-1P0-05-PVT11-J](#) [IP-1R0-05-SSC-J](#) [IP-1R0-05-SVT11-JTB](#) [IP-2P0-10-PSC-J](#) [IP-2P0-10-PVT11-J](#) [IP-2P0-10-PVT11-JTB](#) [IP-2P0-20-PSC-J](#) [IP-2P0-20-PVT11-J](#) [IP-2R0-10-SSC-JTB](#) [IP-2R0-10-SVT11-J](#) [IP-2R0-10-SVT11-JTB](#) [IP-2R0-20-SSC-J](#) [IP-2R0-20-SVT11-JTB](#) [IP-1P0-05-PSC-JTB](#) [IP-1P0-05-PSC-QTF-1](#) [IP-1P0-05-PSC-QTT-1](#) [IP-1P0-05-PVT11-JTB](#) [IP-1P0-05-PVT11-QTF-1](#) [IP-1P0-05-PVT11-QTT-1](#) [IP-1R0-05-SSC-JTB](#) [IP-1R0-05-SSC-QTF-1](#) [IP-1R0-05-SSC-QTT-1](#) [IP-1R0-05-SVT11-J](#) [IP-1R0-05-SVT11-QTF-1](#) [IP-1R0-05-SVT11-QTT-1](#) [IP-2P0-10-PSC-JTB](#) [IP-2P0-10-PSC-QTF-1](#) [IP-2P0-10-PSC-QTT-1](#) [IP-2P0-10-PVT11-QTF-1](#) [IP-2P0-10-PVT11-QTT-1](#) [IP-2P0-20-PSC-JTB](#) [IP-2P0-20-PSC-QTF-1](#) [IP-2P0-20-PSC-QTT-1](#) [IP-2P0-20-PVT11-JTB](#) [IP-2P0-20-PVT11-QTF-1](#) [IP-2P0-20-PVT11-QTT-1](#) [IP-2R0-10-SSC-J](#) [IP-2R0-10-SSC-QTF-1](#) [IP-2R0-10-SSC-QTT-1](#) [IP-2R0-10-SVT11-QTF-1](#) [IP-2R0-10-SVT11-QTT-1](#) [IP-2R0-20-SSC-JTB](#) [IP-2R0-20-SSC-QTF-1](#) [IP-2R0-20-SSC-QTT-1](#) [IP-2R0-20-SVT11-J](#) [IP-2R0-20-SVT11-QTF-1](#) [IP-2R0-20-SVT11-QTT-1](#)