

Cable to Cable

.050"


9 thru 100 Contacts

Rugged Metal

MM

Rugged Plastic

MN

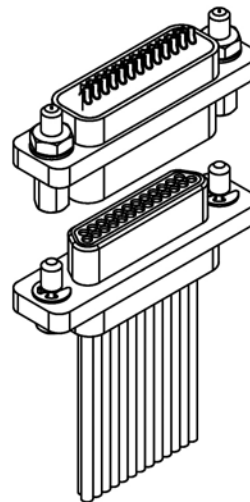


MM-223-025-2A3-2200
(METAL)

MN-221-025-2A3-2200
(PLASTIC)

MM-212-025-161-41WA
(METAL)

MN-211-025-161-41WA
(PLASTIC)

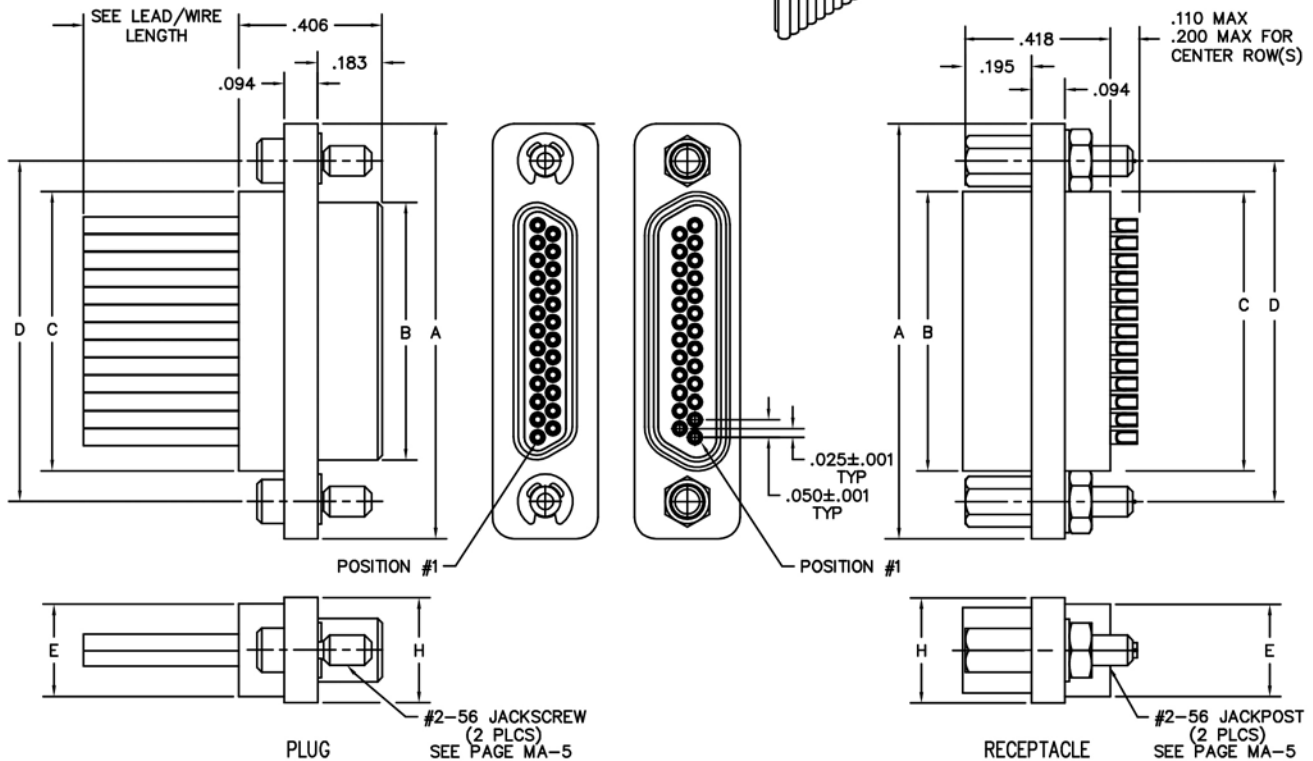

DIMENSIONS								
SIZE	CONTACT ROWS	A	B		C	D	E	H
			PLUG MAX	RCPT MAX			POTTING WELL MAX	
9	2	.775	.334	.400	.390	.565	.270	.298
15		.925	.484	.550	.540	.715		
21		1.075	.634	.700	.690	.865		
25		1.175	.734	.800	.790	.965		
31		1.325	.884	.950	.940	1.115		
37		1.475	1.034	1.100	1.090	1.265		
51**	3	1.825	1.384	1.450	1.440	1.615	.310	.341
51		1.425	.984	1.050	1.040	1.215		
69		1.725	1.284	1.350	1.340	1.515		
100	4	2.160	1.384	1.508	1.432	1.800	.360	.384

* = 69 POSITION CONNECTORS ARE AVAILABLE IN METAL ONLY.

** = 2 ROW, 51 POSITION CONNECTORS ARE AVAILABLE IN METAL ONLY,
(NON MIL-SPEC INTERFACE).

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AirBorn:

[MM-222-025-261-41WR](#) [MM-212-009-113-9900-KS55](#) [MM-212-009-161-00WA](#) [MM-212-009-161-41WA](#) [MM-212-009-161-41WC](#) [MM-212-009-1A3-2200](#) [MM-212-015-161-00WA](#) [MM-212-021-1A3-2200](#) [MM-212-025-113-2200](#) [MM-212-025-161-41Y4](#) [MM-212-037-161-00AH](#) [MM-212-037-161-00AP](#) [MM-213-037-161-41WP](#) [MM-213-037-161-41WU](#) [MM-222-009-261-41WP](#) [MM-222-009-261-45WP](#) [MM-222-009-2A3-2200](#) [MM-222-015-261-41WA-900](#) [MM-222-015-2A3-4100-900](#) [MM-222-025-213-4400](#) [MM-222-025-261-41WS](#) [MM-222-037-2A3-0000](#) [MM-223-015-261-99Y1-KS11](#) [MM-223-051-213-4100](#) [MM-224-021-213-4100](#) [MM-312-051-161-00WC](#) [MM-312-069-161-41WD](#) [MM-312-069-161-455C](#) [MM-313-069-161-41W1](#) [MM-322-069-261-22WQ](#) [MM-322-069-2A3-2200](#) [MM-415-100-161-81V2](#) [MM-422-100-261-00UJ](#) [MM-422-100-261-62WQ](#) [MM-212-037-1A3-2200](#) [MM-212-025-161-45EM](#) [MM-212-037-161-45EM](#) [MM-312-069-161-22EM](#) [MM-212-015-161-005D](#) [MM-222-021-261-43WB](#) [MM-212-037-161-00CM](#) [MM-222-021-213-4200](#) [MM-212-015-161-45Y1](#) [MM-212-021-161-45Y1](#) [MM-222-009-261-45Y1](#) [MM-222-015-261-45Y1](#) [MM-222-021-261-45Y1](#) [MM-222-025-261-45Y1](#) [MM-222-031-261-45Y1](#) [MM-213-037-161-42WR](#) [MM-313-051-161-42WR](#) [MM-312-069-161-00YG](#) [MM-222-025-2A3-0000-900](#) [MM-212-021-161-00WG](#) [MM-223-051-261-41BF](#) [MM-322-051-261-22EM](#) [MM-212-021-161-22WW](#) [MM-212-031-161-00CD](#) [MM-212-051-161-00WB](#) [MM-212-051-161-00WH](#) [MM-222-015-261-005D](#) [MM-222-031-261-43WQ](#) [MM-222-037-213-4400](#) [MM-222-037-245-2200](#) [MM-223-051-261-45WQ](#) [MM-312-051-161-00CK](#) [MM-313-051-113-2200](#) [MM-313-051-113-4500](#) [MM-313-069-161-43WC](#) [MM-313-069-1A3-4100](#) [MM-322-069-261-43WQ](#) [MM-422-100-261-816D](#) [MM-422-100-261-99UG-KJ11](#)