




**Right Angle
Boardmount
(Compressed Footprint)**
.050"
9 thru 100 Contacts



MK

MATING MATRIX	
CONNECTOR	MATES WITH
MK-2P...	MK, ML, MM, MN receptacles
MK-2Q...	MK, ML, MM, MN plugs

MK-2P2-031-A35-220S
(PLUG)

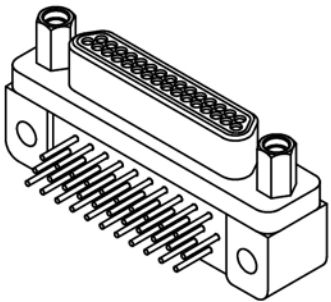

MK-2Q2-031-B45-220S
(RECEPTACLE)

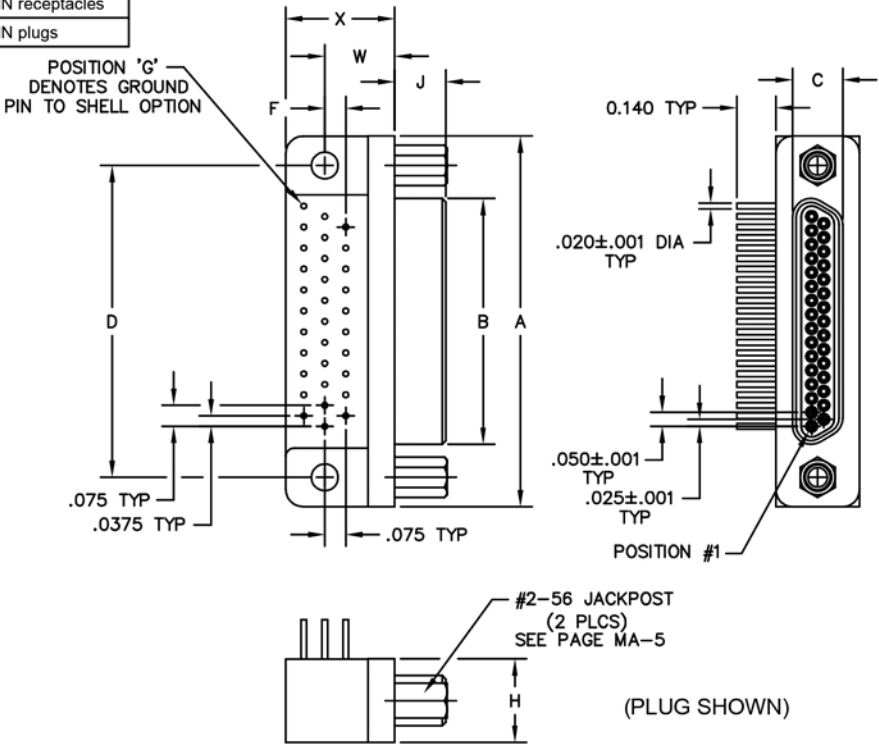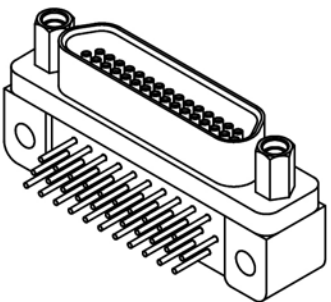

DIMENSIONS															
SIZE	CONTACT ROWS	A	B		C		D	F	H	J		W	X MAX	HARDWARE	MOUNTING HOLE
			PLUG MAX	RCPT MAX	PLUG MAX	RCPT MAX				PLUG	RCPT				
9	2	.775	.334	.400	.185	.251	.565	.0375	.298	.183	.195	.250	.400	#2-56 UNC THD	.096 DIA OR #2-56 UNC THREADED INSERT
15		.925	.484	.550			.715								
21		1.075	.634	.700			.865								
25		1.175	.734	.800			.965								
31		1.325	.884	.950			1.115								
37		1.475	1.034	1.100			1.265								
51	3	1.425	.984	1.050	.228	.294	1.215	.1125	.341			.300	.490		
69		1.725	1.284	1.350			1.515								
100	4	2.160	1.384	1.508	.271	.394	1.800	.1875	.384			.400	.660	#4-40 UNC THD	.125 DIA OR #4-40 UNC THREADED INSERT

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AirBorn:

[MM-212-031-143-JP00-93A](#) [MM-212-031-143-JS00-93A](#) [MM-212-051-143-2200-93A](#) [MM-232-025-AAA-4400](#) [MM-232-037-AAA-4400](#) [MM-232-051-000-4100](#) [MM-252-051-000-4100](#) [MM-272-025-000-4100](#) [MM-332-051-AAA-4400](#) [MM-332-069-AAA-2200](#) [MM-332-069-AAA-4100](#) [MM-432-100-AAA-8100](#) [MM-332-069-000-0000](#) [MM-432-100-AAA-6200](#) [MK-2P2-025-A35-220S-0B7](#) [MK-4Q2-100-B45-620S-0B7](#) [MK-3P2-051-A45-000S-0B7](#)