


DSB-310

Fanless Digital Signage Player

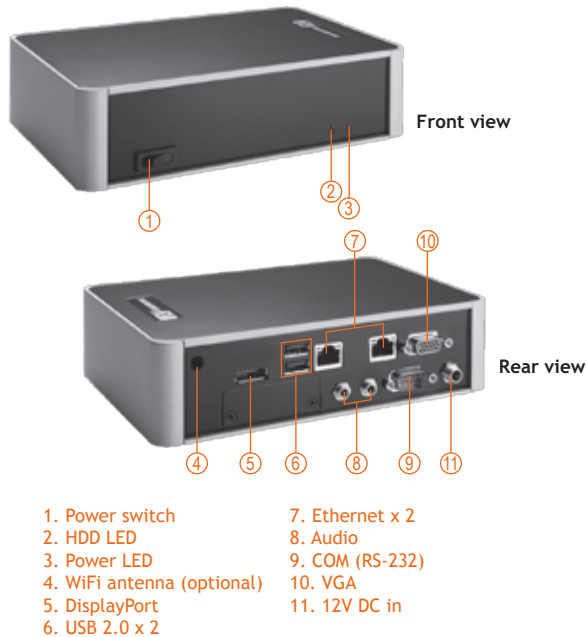

Specifications

Standard Color	Black/Grey
CPU	AMD G-Series APU T40E 1.0 GHz dual core onboard
Chipset	AMD Fusion Controller Hub A50M
System Memory	1 x 204-pin DDR3-1066/1333 SO-DIMM max. up to 4 GB
Storage	1 x 2.5" SATA HDD 1 x CompactFlash™
System I/O Outlet	1 x DisplayPort 1 x VGA 2 x USB 2.0 1 x Audio (Line-out/Mic-in) 1 x RS-232 2 x 10/100/1000Mbps Ethernet 1 x Power on/off button
Indicator	1 x LED for system power ON, 1 x LED for HDD
WiFi	Optional 802.11 b/g/n
Expansion Slot	1 x PCI Express Mini Card
Power Supply	12VDC, with AC-DC Adapter
Operating Temperature	0°C ~ +45°C (32°F ~ 113°F)
Dimensions	186 mm (7.32") (W) x 116 mm (4.56") (D) x 49 mm (1.92") (D)
Packing Dimensions	TBD
Weight (net/gross)	TBD
Certification	CE

Features



- Fanless operation
- Supports AMD G-Series APU T40E 1.0 GHz dual core onboard
- Low power consumption
- Optional wireless LAN module
- Supports wall mount and VESA mount

Overview

Industrial Panel Computers & Monitors

Heavy-duty Fanless Touch Panel Computers

Digital Signage Solutions

Healthcare & Medical Solutions

Open Frame Panel Computers

Accessories

Ordering Information

Standard	
DSB-310	Fanless digital signage player with AMD G-Series T40E APU onboard
Optional	
Wireless Lan kit	Wi-Fi module and antenna
HDMI cable	Cable for DisplayPort to HDMI
DVI cable	Cable for DisplayPort to DVI

* Specification and certifications are based on options and may vary.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Axiomtek:](#)

[DSB-310-110](#)