

eBOX532-100-FL

Fanless Embedded System with AMD G-Series APU T40R 1.0 GHz

Features

- AMD G-Series APU T40R 1.0 GHz onboard
- AMD A50M FCH
- Ultra slim and compact design
- 4 USB 2.0 ports and 2 COM ports
- 1 GbE LAN port
- One 2.5" SATA HDD drive bay, 1 CompactFlash™
- VGA or DisplayPort



Specifications

Standard Color	Silver-Black
Construction	Aluminum extrusion and heavy-duty steel, IP40
CPU	AMD G-Series APU T40R 1.0 GHz onboard
System Memory	1 x 204-pin DDR3 SO-DIMM, up to 4GB
Chipset	AMD A50M FCH
BIOS	AMI
System I/O Outlet	2 x RS-232 (COM 1/2) 1 x VGA or 1 x DisplayPort 1 x Audio (Mic-in/Line-out) 1 x PS/2 keyboard/mouse 1 x 10/100/1000Mbps Ethernet (Realtek RTL8111E) 4 x USB 2.0 1 x VDC 5V power input
Watchdog Timer	255 levels, 1 ~ 255 sec.
Storage	1 x 2.5" SATA HDD drive bay 1 x CompactFlash™ slot
Expansion Interface	N/A
System Indicator	1 x green LED for system power-on 1 x orange LED for HDD active
Power Supply	Input: AC 100 ~ 240V, AC 40W adapter with lock Output: DC 5V @ 8A
Operating Temperature	0°C ~ +45°C (32°F ~ 113°F) (with W.T. HDD) 0°C ~ +50°C (32°F ~ 122°F) (with W.T. SSD & W.T. CF)
Humidity	10% ~ 90%, non-condensing
Dimensions	132 mm (5.19") (W) x 95.4 mm (3.75") (D) x 47.5 mm (1.87") (H)
Weight (net/gross)	0.5 kg (1.1 lb) / 0.6 kg (1.32 lb)
Certificate	CE
EOS Support	XPE, Linux, WES, WES7

Packing List

- 1 x Quick manual
- 1 x Driver CD
- 1 x Y cable for PS/2 keyboard/mouse
- 1 x Screw pack
- 4 x Foot pad
- 1 x Power adapter
- 1 x Wall mount kit
- 1 x Power cord
- 1 x HDD mylar



▲ Front view



▲ Rear view

Power Protection

AC Version

- OVP (over voltage protection)
- SCP (short circuit protection)
- OPP (over power protection)

Ordering Information

Standard


eBOX532-100-FL1.0G-VGA	Fanless embedded system with AMD G-Series APU T40R 1.0 GHz, 1 GbE LAN, 4 USB, 2 COM, 40W AC/DC adapter and VGA
eBOX532-100-FL1.0G-PGA	Fanless embedded system with AMD G-Series APU T40R 1.0 GHz, 1 GbE LAN, 4 USB, 2 COM, 40W AC/DC adapter and DisplayPort

Optional

2.5" SATA HDD	40GB or above
2.5" SATA SSD	4GB or above
DDR3 SO-DIMM	512MB ~ 4GB
CompactFlash™	1GB or above
DIN-rail kit	881605300A0E
VESA mount kit	881605301A0E
Power cord	

*Specifications and certifications are based on options and may vary.

Dimensions

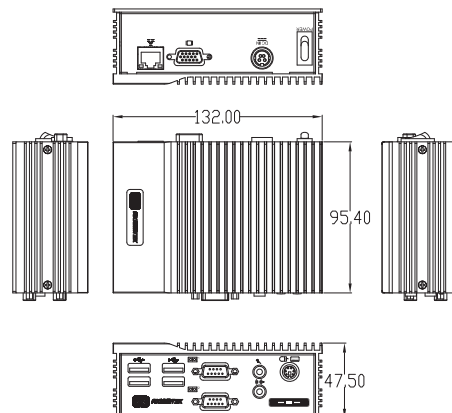

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Axiomtek:](#)

[EBOX532-100-1G/VGA](#)