


eBOX621-801-FL

Fanless Embedded System with Intel® Atom™ Processor D525 1.8 GHz and 9 ~ 34VDC Input

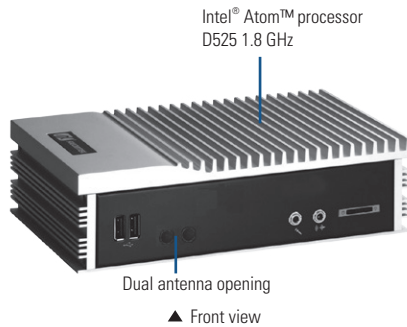

Specifications

Standard Color	Silver-Black
Construction	Aluminum extrusion and heavy-duty steel, IP40
CPU	Intel® Atom™ processor D525 1.8 GHz dual core
System Memory	1 x 204-pin DDR3-800 SO-DIMM max. up to 4 GB
Chipset	Intel® ICH8M
BIOS	AMI
System I/O Outlet	1 x RS-232/422/485 (COM 1) 2 x RS-232 (COM 2/3) 1 x VGA 1 x Audio (Mic-in/Line-out) 2 x 10/100/1000Mbps Ethernet (Intel® 82567V & 82583V) 4 x USB 2.0 2 x SMA type connector opening for antenna 1 x VDC power input connector 1 x ATX power switch
Watchdog Timer	255 levels, 1 ~ 255 sec.
Storage	1 x 2.5" SATA HDD drive bay 1 x CompactFlash™ slot
Expansion Interface	1 x PCI Express Mini Card slot (USB+PCI Express signal) 1 x internal USB WiFi mounting space
System Indicator	1 x green LED for system power-on 1 x orange LED for HDD active
Power Supply	42.5W 9 ~ 34VDC
Operating Temperature	-10°C ~ +55°C (14°F ~ 131°F) (with 1.8 GHz CPU, W.T.HDD)
Storage Temperature	-20°C ~ +80°C (-4°F ~ +176°F)
Humidity	10% ~ 90% , non-condensing
Vibration Endurance	2 Grms w/ CF (5-500Hz, X, Y, Z directions)
Dimensions	200 mm (7.87") (W) x 120 mm (4.72") (D) x 56 mm (2.2") (H)
Weight (net/gross)	1.98 kg (4.36 lb)/2.6 kg (5.73 lb)
Certification	CE
EOS Support	XPE, WinCE, Linux, WES, WES7

* XPE: Windows® XP Embedded

* WES: Windows® XP Embedded Standard

* WES7: Windows® Embedded Standard 7


* WES8: Windows® Embedded Standard 8

Packing List

1 x quick manual
1 x driver CD
1 x screw pack
4 x foot pad
2 x thermal Pad
2 x CF mylar
1 x HDD mylar
1 x DC-in connector

Features

- Intel® Atom™ processor D525 1.8 GHz onboard
- Intel® ICH8M chipset
- 1 RS-232/422/485 and 2 RS-232 ports
- Fanless operation design with full feature I/O
- High performance DDR3-800 SO-DIMM max.up to 4 GB
- One 2.5" SATA drive bay and 1 CompactFlash™ 2.0 slot
- 9~34VDC wide range DC input
- Supports Jumbo Frame (9k), WoL, PXE Remote Boot, iAMT

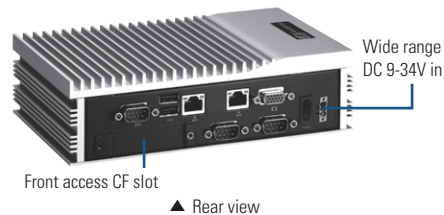

Power Protection

AC Version

OVP (over voltage protection)

OCP (over current protection)

SCP (short circuit protection)

Ordering Information

Standard


eBOX621-801-FL-D525-1.8G	Fanless embedded system with Intel® Atom™ processor D525 1.8 GHz, VGA, 2 GbE LAN, 3 COM, 4 USB, CF & HDD support and 9 ~ 34VDC input
--------------------------	--

Optional

2.5" SATA HDD	40 GB or above
2.5" SATA SSD	4 GB or above
DDR3 SODIMM	512 MB or above
CompactFlash™	256 MB or above
Wifi module	
USB wifi module	
GPS module	
Graphic codec module	
Din rail kit	
Wall mount kit	
VESA mount kit	

*Specifications and certifications are based on options and may vary.

Dimensions

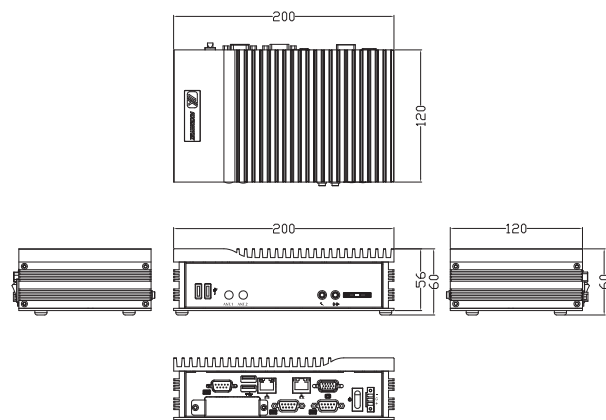

* All specifications and photos are subject to change without notice.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Axiomtek:](#)

[EBOX621-801-D525](#)