


IFO2225-873

22" WSXGA TFT Fanless Super Slim Touch Panel Computer with Intel® Core™ i7/i5/i3 & Celeron® Processor

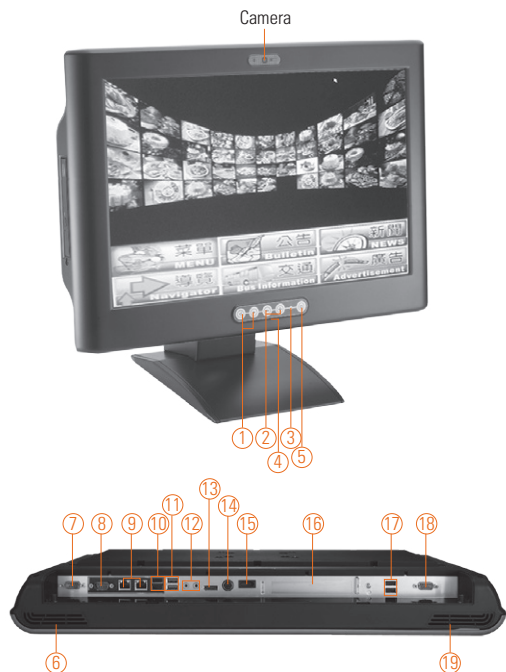

1. Brightness adjust +/-
2. Volume adjust
3. Power LED
4. Mic
5. Power switch
6. Speaker (R)
7. COM 2 (RS-232)
8. COM 1 (RS-232/422/485)
9. Gigabit LAN x 2
10. USB 2.0 x 2
11. USB 3.0 x 2
12. Audio (Line-out/Mic-in)
13. DisplayPort
14. Power connector
15. Power switch
16. PCI or PCIe x 4
17. USB 2.0 x 2
18. COM 3 (RS-232)
19. Speaker (L)



Introduction

The IFO2225-873 is a slim panel computer equipped with a 22-inch 250 nits high brightness WSXGA LCD display that supports an 3rd generation Intel® Core™ i7/i5/i3 & Celeron® processor up to 35W with Intel® QM77 chipset. The Intel® HD Graphics 4000/2500 engine with DX11 support is built into the chipset to provide fast graphics performance. The panel PC also supports DualView and multiple I/O options including 4 USB 2.0 and 3 RS-232 ports. The built-in 5 mega pixels camera and microphone/speakers can provide a solution for VoIP and remote monitoring. The IFO2225-873 also supports an antenna for wireless (802.11 b/g/n) connection. Its dual Gigabit Ethernet ports provide high speed Ethernet as well as a high reliable redundancy host connection. This robust unit is designed to be work under minimal noise levels, low power consumption, high reliability and while maintaining efficient performance. Its excellent industrial design (ID) and user friendly interface design make it an ideal solution best suited for infotainment, advertising messaging, and other digital signage applications.

Water/dust-proof design for entire system: IPX1

The IPX1-rated water/dust-proof housing protects the entire 22" panel system from outside damage caused by water drip damage while installed at public or enclosed environments. Its unique design improves system stability while saving time and money on maintenance costs and re-installation time.

Features

- 22" (250 nits) WSXGA TFT LCD
- Socket rPGA988B 3rd generation Intel® Core™ i7/i5/i3 (Ivy Bridge) & Celeron® processor
- Intel® QM77 chipset
- USB 3.0 supported
- IP65 front bezel and IPX1 full enclosure water/dust proof design
- 1 PCI or PCIe x4 expansion slot and 2 PCIe Mini Card slots
- Optional Bluetooth/Wi-Fi (802.11 a/b/g/n)
- Built-in 5 mega pixels camera
- Supports optional Wall mount, VESA arm and desktop stand



▲ Rear view

Specifications

Front Bezel	Plastic ABS	
LCD Panel	Display Type	22" WSXGA TFT
	Brightness (cd/m ²)	250 nits
	Resolution	1680 x 1050
	Viewing Angle (H/V)	178°/178°
Main System	CPU	Socket rPGA988B 3rd generation Intel® Core™ i7/i5/i3 & Celeron® processor, TDP up to 35W
	Chipset	Intel® QM77
	System Memory	2 x 204-pin DDR3 SO-DIMM max. up to 16GB
	BIOS	AMI UEFI BIOS with OA 3.0 built
	Storage	1 x 2.5" SATA HDD 1 x mSATA SSD (optional)
	Optical Drive	1 x Super Multi drive (optional)
	Watchdog Timer	255 levels, 0-255 sec.
	Onboard Graphics	Intel® HD Graphic

Specifications

I/O Connector	2 x RS-232 (COM 2/3) 1 x RS-232/422/485 2 x 10/100/1000 Mbps Ethernet 4 x USB 2.0 2 x USB 3.0 1 x Audio (Line-out) 1 x Audio (Mic-in) 1 x DisplayPort
Expansion Interface	1 x PCI or 1 x PCIe x4 slot 2 x PCI Express Mini Card slot (optional)
Speaker	2 x 2W
Camera	1 x 5M pixels camera
Touchscreen	5-wire resistive type
Function Key	LCD brightness up/down, audio volume up/down, power on/off
Power Supply	External 19VDC or 24VDC with AC/DC power adapter
Dimensions	573.5 mm (22.57") (W) x 75.9 mm (2.98") (D) x 398.9 mm (15.7") (H)
Packing Dimensions	730 mm (28.74") (W) x 240 mm (9.45") (D) x 650 mm (25.59") (H)
Weight (net/gross)	10.58 kg (23.32 lb)/15.16 kg (33.42 lb)
Environment	Operating temperature: 0°C ~ +40°C (+32°F ~ +104°F) Relative humidity: 20% ~ 90% @ 40°C; non-condensing
Certificate	CE

Ordering Information

IF02225-873-NP-DRW	22" WSXGA fanless touch panel computer with 3rd generation Intel® Core™ processor, 5-wire resistive touch screen, super multi drive and AC-DC 120W power adapter (screw type connector)
IF02225-873-NP w/o DRW	22" WSXGA fanless touch panel computer with 3rd generation Intel® Core™ processor, 5-wire resistive touch screen and AC-DC 120W power adapter (screw type connector)

* Specification and certifications are based on options and may vary.

**Super Multi drive includes DVD-R, DVD-RW and DVD-RAM.


Optional Accessories

E202003330	VM-101 VESA ARM (clamp type)
E202003329	VM-105 VESA ARM (wall mount type)
E222175103	22" stand kit

Optional OS Installation

Windows® XP
Windows® 7
Windows® 8.1
WEBS

Dimensions

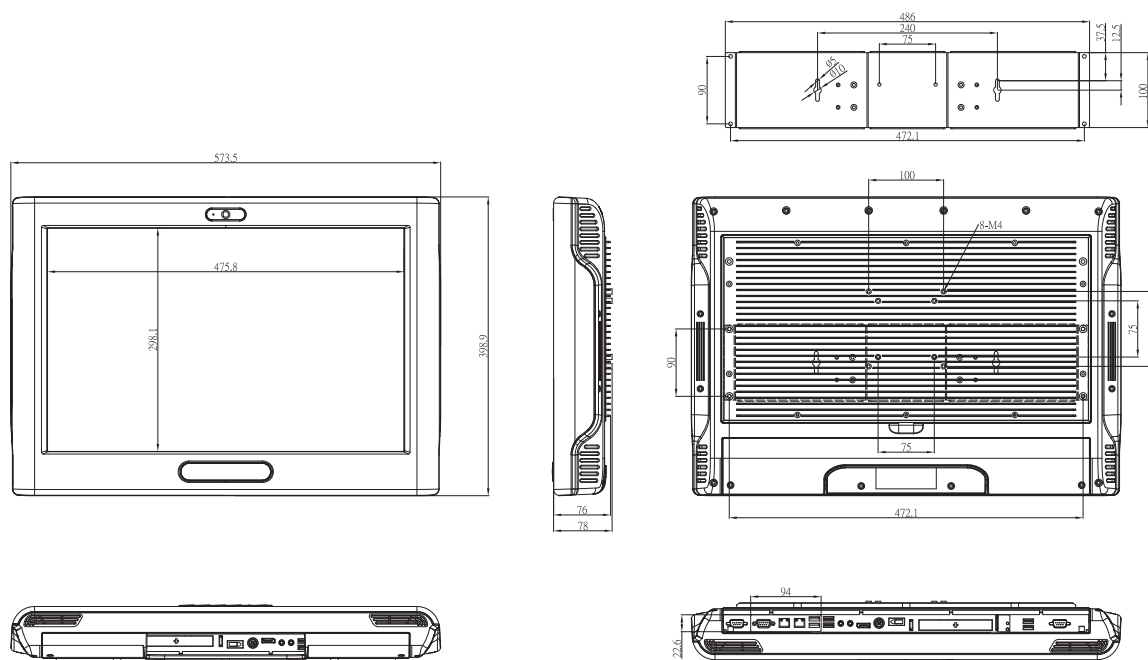

Overview

Fanless
Touch Panel
Computers

Heavy-duty
Fanless Touch
Panel Computers

Industrial
Touch Panel
Computers

Industrial Touch
panel Monitors

5
Infotainment
Touch Panel
Computers

Healthcare
& Medical
Solutions

Open
Frame Panel
Computers

Accessories



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Axiomtek:](#)

[IFO2225-873-NP w/o DRW](#) [IFO2225-873-NP-DRW](#)