


NA720

1U Rackmount Network Appliance Platform with Intel® Xeon® Processor D-1527 and up to 26 LAN

Features

- Intel® Xeon® processor D-1527
- Four DDR4-2400 R-DIMM/U-DIMM, up to 128GB memory
- Max. up to 24 LAN ports and 2 SFP+ ports
- Two expandable LAN modules supporting 1GbE/10GbE/Fiber/Copper/Bypass (optional)
- Supports 1U redundant power supply for optional
- Supports IPMI for optional
- Suitable for enterprise firewall, network bandwidth controller and UTM applications

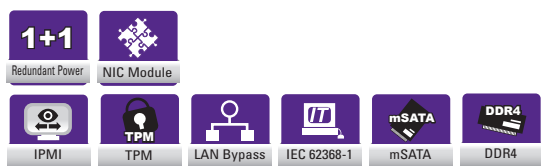


Specifications

System	
CPU	Intel® Xeon® processor D-1527 (Broadwell-DE)
Chipset	SoC Integrated
Memory	4 x DDR4-2400 R-DIMM/U-DIMM, up to 128GB non-buffer non-ECC/ECC memory
BIOS	AMI SPI Flash BIOS
Storage	2 x 2.5" SATA HDD 1 x Full-size mSATA
Network Interface	8 x GbE R-J45 (Intel® i210) 2 x 10 GbE SFP+ 2 x LAN module (optional), max. up to 26 LAN ports
I/O	1 x Console (RJ-type) 2 x USB 3.0 8 x RJ-45 + 2 x SFP+ 1 x VGA (optional)
TPM	Onboard TPM 2.0 (optional)
IPMI	Onboard BMC AST2500, IPMI 2.0 for optional
Other Features	LAN Bypass function through latch relay (two pairs)
Expansion Slot	1 x PCIe x8 (optional)
Watchdog Timer	255 stepping for system reset 8 stepping for LAN Bypass
Power Supply	300 W ATX power supply 400 W 1U redundant power supply (optional)
OS Compatibility	Linux

Mechanical/ Environmental

Form Factor	1U rackmount
LED	Power, HDD, GPIO programmable, LAN Bypass, Link/Act with transfer rate
Operating Temp.	0°C to +45°C (+32°F to +113°F)
Humidity	10% to 95% RH, non-condensing
Chassis Material	Steel
Dimensions	44 mm (1.73") (H) x 430 mm (16.93") (W) x 390 mm (15.34") (D)
Weight	8.5 kg (18.74 lb)/9.8 kg (21.61 lb)
Certificates	CE/FCC Class A

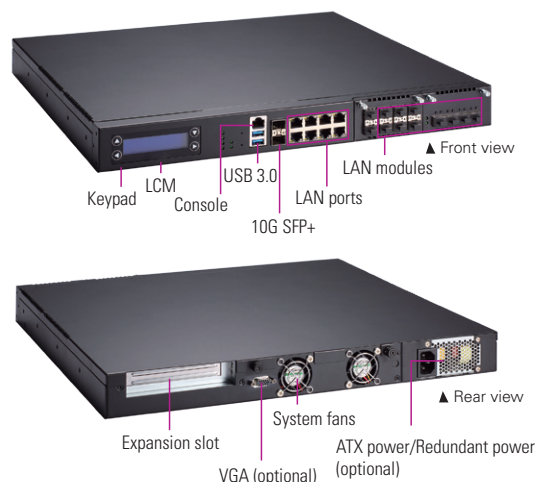

Ordering Information

Standard	
NA720-RAMI-1527-US w/2LBP w/o IPMI/TPM (P/N: E26E720101)	1U rackmount network appliance with Intel® Xeon® Processor D-1527, 8 GbE LANs, 2 10 GbE SFP+ and 2-pair LAN Bypass

Optional


5916E552000E	DB9F-RJ-45 1.8M console cable for Cisco
--------------	---

* Specifications and certifications may vary contingent on options.

Packing List

2 x SATA cable
1 x Power cord

Dimensions

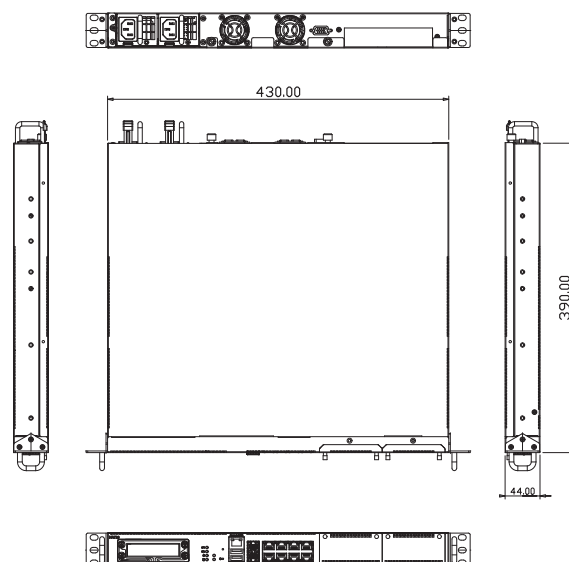

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Axiomtek:](#)

[NA720-RAMI-1527-US w/2LBP w/o IPMI/TPM](#) [NA720-RAMI-1508-US w/2LBP wo IPMI/TP\(PH\)](#)