


OFP921-834

21.5" Full HD Digital Signage System for Bus PC Supports Intel® Core™2 Duo E4300 1.8 GHz

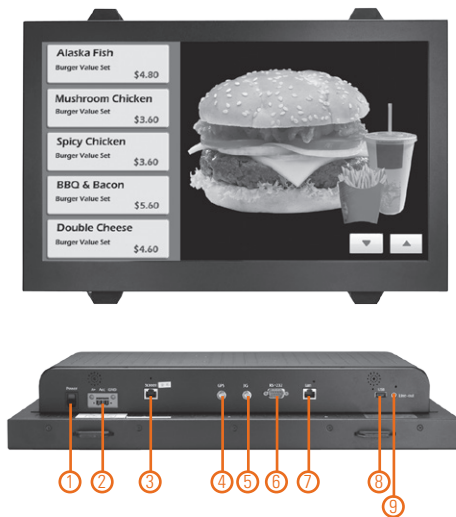

1. Power switch
2. 24V DC input
3. DVI over CAT5
4. GPS antenna
5. 3G antenna
6. COM (RS-232)
7. Ethernet
8. USB 2.0
9. Audio (Line-out)



Specifications

LCD Panel	Size	21.5"
	Contrast	1000:1
	Pixel Pitch	248.25 x 248.25 (um)
	Viewing Angle (H/V)	170° x 160°
	Response Time	5ms
	Color	16.7M
	Brightness (cd/m²)	250
	Watchdog Timer	255 levels, 1V ~ 255 sec.
Board	CPU	Intel® Core™2 Duo E4300 1.8 GHz
	Chipset	Intel® 945GC + ICH7
	Front Side Bus	800 MHz
	Onboard Graphics	Intel® Graphics Media Accelerator 950
	Memory	1 GB 240-pin DIMM
I/O	HDD	CompactFlash™ 8 GB
	1 x USB 2.0	
	1 x RS-232	
	1 x DVI over CAT5	
	1 x GPS antenna	
	1 x 3G antenna	
	1 x power switch	
Ethernet	1 x 10/100/1000 Mbps Ethernet	
Expansion Slot	NA	
Audio	Line-out	
Touchscreen	N/A	
Power Supply	9 - 36VDC, PHOENIX DC power connector	
Dimensions	527 mm (20.74") (W) x 90.8 mm (3.57") (H) x 334 mm (13.14") (D)	
Packing Dimensions	720 mm (28.34") (W) x 205 mm (8.07") (D) x 540 mm (21.25") (H)	
Weight (net/gross)	15.3 kg (33.63lb)/ 19.5 kg (48.86lb)	
Environment	0°C ~ +40°C (+32°F ~ +113°F), operation, 10% ~ 90% relative humidity	

Features

- 21.5" LED LCD – Full HD 1920 x 1080P
- Intel® Core™2 Duo E4300 1.8 GHz
- DVI over CAT5 long distance dual display
- GPS antenna and 3G antenna
- Supports VESA mount and special snap rings



▲ Side view



▲ Rear view

Ordering Information


Standard

OFP921-834-CHT	21.5" digital signage platform with Intel® Core™2 Duo E4300 and 1920 x 1080 full HD resolution
E22K921101	DSE921-M 2nd display monitor

Optional

722F9210900E	AL hook for OFP921-834
--------------	------------------------

Ordering Information

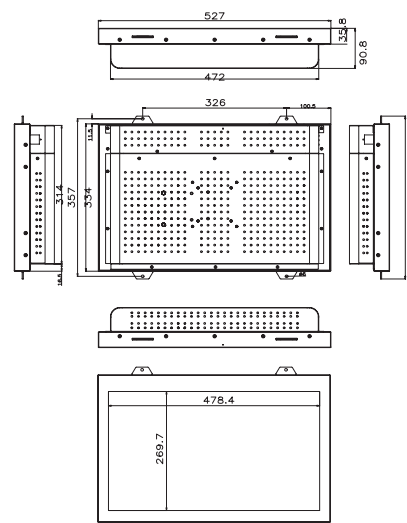

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Axiomtek:](#)

[OFP921-834-CHT](#)