

# P6101 NEW



10.4" XGA TFT Industrial LCD Monitor

## Features

- 10.4" XGA TFT LED backlight LCD
- NEMA 4/12 (IP65)- compliant flat panel monitor
- Supports panel mount, wall mount, rack mount and VESA arm
- Resistive touchscreen
- Full range screw-type (locked) AC-in or 12V/24V DC-in (option)
- DVI-D, VGA and HDMI with multi-signal inputs



▲ Ultra-slim mechanism design

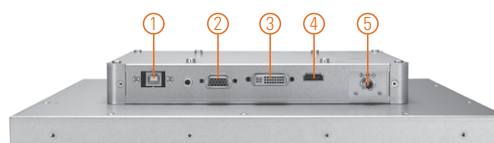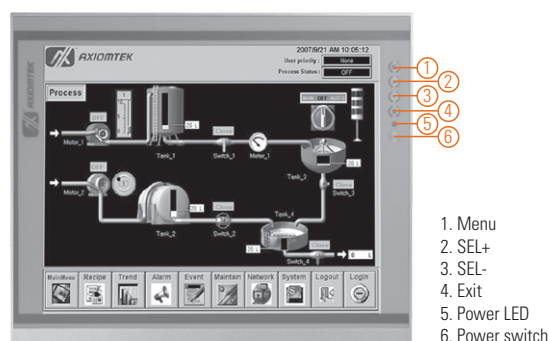

- |             |          |
|-------------|----------|
| 1. T/S port | 4. HDMI  |
| 2. VGA      | 5. Power |
| 3. DVI-D    |          |

## Introduction

The P6101 is an ultra slim industrial LCD monitor, which adopts 10.4-inch 350 nits XGA LED backlight LCD display and supports multi-signal interfaces including DVI, VGA and HDMI. Featuring NEMA 4/12 & IP65 compliant front bezel, screw-type adaptor plug design, and 12/24V DC-in means it is fit for all kinds of industrial environments. Moreover, the P6101 supports panel mount, wall mount or VESA FPMPI (Video Electronics Standards Association Flat Panel Monitor Physical Mounting Interface) mounting. With the compact mechanism design, users can enjoy free from space constraint. It is especially suitable for POI/POS, excellent HMI and all kinds of heavy-duty industrial fields.

## Specifications

Front Bezel	NEMA 4/12 (IP65)-compliant, metal front bezel	
Mounting	Panel mount, wall mount, rack mount or VESA arm FPMPI mounting (video electronics standards association flat panel monitor physical mounting interface)	
LCD Panel	Display	10.4" XGA TFT LCD
	Max. Resolution	1024 x 768
	Max. Colors	16.7 M
	Active Area (mm)	211.2 x 158.4
	Pixel Pitch (mm)	0.2063 x 0.2063
	Response Time	16ms
	Backlight	LED backlight
	Backlight MTBF	30,000 hrs
	Viewing Angle (H/V)	150°/150°
	Contrast Ratio	900 (TYP.)
	Brightness (cd/m <sup>2</sup> )	350 nits
Display Control	OSD (on screen display)	
Display Mode	VGA 640 x 350 (70Hz), VGA 640 x 480 (60/72/75Hz), VGA 720 x 400 (70Hz), SVGA 800 x 600 (60/72/75Hz), XGA 1024 x 768 (60/72/75Hz)	

## Specifications

Input Signal	DVI-D VGA HDMI Touchscreen: Serial RS-232 or USB interface
I/O Connectors	1 x RS-232 or USB for touchscreen version 1 x DVI-D 1 x VGA 1 x HDMI 1 x Screw-type DC power input
Power Adapter	Screw-type external AC/DC power adapter
Power Consumption	TBD
Touchscreen	Thickness Resistive: 3.2 mm Light Transmission Resistive: 80% Power Consumption Resistive: +5V @ 100mA Touch Life Resistive: 35 million touches Controller interface: RS-232 D-type 9-pin male connector or USB
Dimensions	277.5 mm (10.93") x 48 mm (1.89") x 223.55 mm (8.8")
Packing Dimensions	362 mm (14.25") x 165 mm (6.5") x 397 mm (15.63")
Weight (net/gross)	TBD
Environment	Operating temperature: 0°C ~ +50°C (+32°F ~ +122°F) Relative humidity: 20% ~ 90% @ +40°C, non-condensing
Packing List	1 x VGA cable 1 x RS-232 or USB cable for touchscreen (for touch version) 1 x Audio cable 1 x EU/US power cord (for AC version)
Certificate	CE


## Ordering Information

AC Power	Resistive (RS-232)	P6101PR-AC-RS-US-EU
	Resistive (USB)	P6101PR-AC-U-US-EU
	Glass	P6101PG-AC-US-EU
12V/24VDC Power	Resistive (RS-232)	P6101PR-DC-RS
	Resistive (USB)	P6101PR-DC-U
	Glass	P6101PG-DC

## Optional Accessories

5946L203800E	HDMI cable
5946L1713400E	DVI cable
8226101000E	Panel mount kit
82231770050E	Wall mount kit
E226171106	Desktop stand

## Dimensions

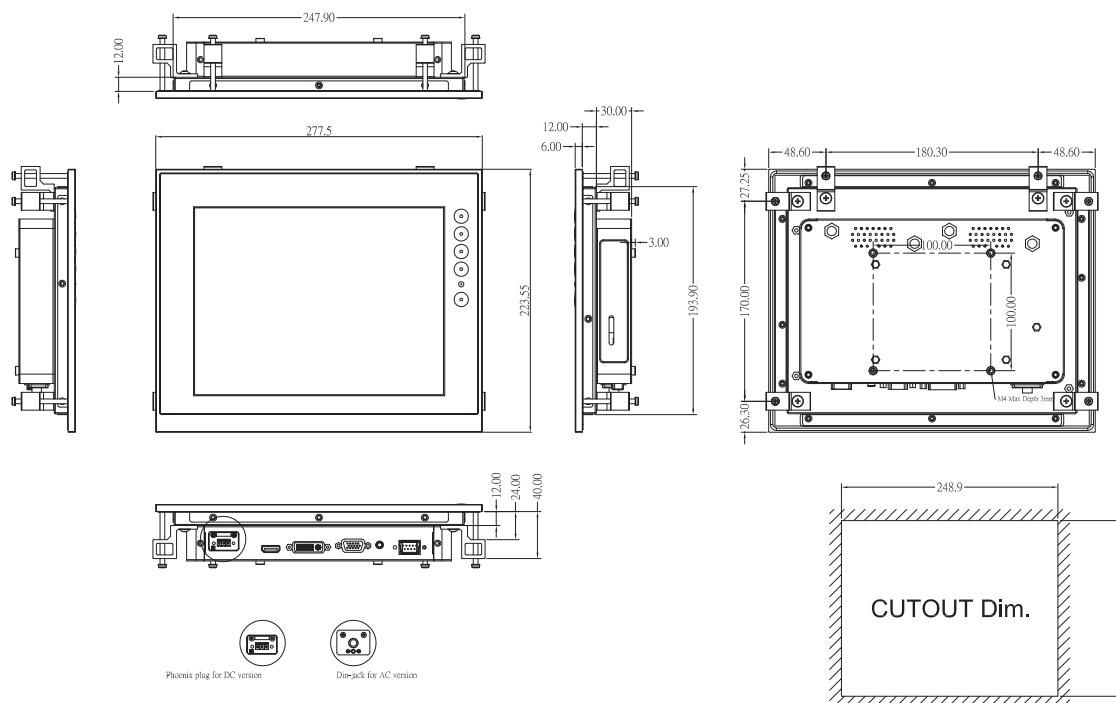

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Axiomtek:](#)

[P6101PG-AC-US-EU](#) [P6101PR-24VDC-RS](#) [P6101PR-24VDC-U](#) [P6101PR-AC-RS-US-EU](#) [P6101PR-AC-U-US-EU](#)  
[P6101PG-24VDC](#)