


PICO512

Pico-ITX SBC with 7th Gen Intel® Core™ i7/i5/i3 & Celeron® Processor, HDMI/LVDS and GbE LAN

Features

- 7th gen Intel® Core™ i7/i5/i3 & Celeron® processor
- 1 DDR4 SO-DIMM, up to 16GB
- PCI Express Mini Card slot with mSATA supported
- Intel® AMT 11 supported

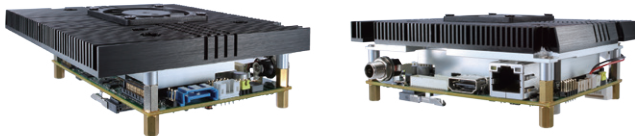

▲ Assembly view



Core System



CPU	7th gen Intel® i7/i5/i3 & Celeron® processor onboard
System Memory	1 x 260-pin DDR4-2133 SO-DIMM, up to 16GB
Chipset	N/A
BIOS	AMI
SSD	N/A
Watchdog Timer	65535 levels, 1 ~ 65535 sec.
Expansion Interface	1 x full-size PCI Express Mini Card slot with mSATA 1 x PCIe x1, 1 x LPC, 1 x DDI, 4 x USB 3.0, 1 x HD audio and 1 x SMBus (through expansion connector)
Battery Lithium	Lithium 3V/220mAh
Power Input	DC Jack +12V DC-in only AT Auto Power On function supported
Power Requirements	Intel® i7-7600U @ 2.8 GHz 16GB DDR4 max. RMS. +12V @ 2.5A Intel® i5-7300U @ 2.6 GHz 16GB DDR4 max. RMS. +12V @ 2.4A Intel® i3-7100U @ 2.4 GHz 16GB DDR4 max. RMS. +12V @ 2.2A Intel® Celeron®-3965U @ 2.2 GHz 16GB DDR4 max. RMS. +12V @ 1.7A
Size	100 x 72 mm
Board Thickness	1.6 mm
Temperature	-20°C ~ +70°C (-4°F ~ +158°F), operation
Relative Humidity	10% ~ 95% relative humidity, non-condensing

I/O

MIO	N/A
SATA	1 x SATA-600
Hardware Monitoring	Detect CPU/system temperature, voltage and fan speed
Ethernet	1 port 10/100/1000 Mbps supports Wake-on-LAN, PXE Boot ROM with Intel® i219LM
Audio	N/A
USB	1 x USB 2.0
SMBus/i ² C	Yes, for advanced monitoring/control
Digital I/O	8 channels in/out programmable
TPM	ST ST33TPM12LPC with TPM 1.2 compliant

Display

Chipset	Intel® integrated Gfx graphic engine
Memory Size	Share system memory
Display Interface	1 x HDMI 1 x LVDS; 18/24-bit single/dual channel

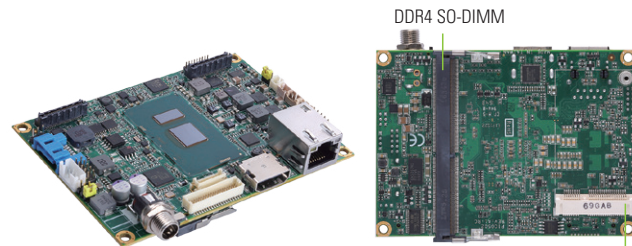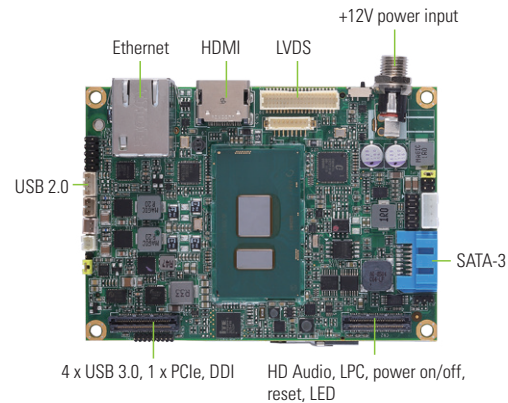

▲ Side view

▲ Rear view

Full-size PCI Express
Mini Card slot with
mSATA supported

Packing List

Standard

Quick installation guide, user's manual/utility CD and accessories

Accessories

Part Number	Description	Qty
59403208000E	SATA cable	1
594P8800600E	SATA power cable	1
59190400500E	Fan cable	1
594P8802810E	USB cable	1
5078H500000E	Heatspreader	1
5078H500100E	Cooler	1

Ordering Information

Standard

PICO512HG-i7-7600U	Pico-ITX SBC with Intel® Core™ i7-7600U processor (2.8 ~ 3.9 GHz, 4MB cache, 15W), HDMI/LVDS, 1 GbE LAN, 1 USB
PICO512HG-i5-7300U	Pico-ITX SBC with Intel® Core™ i5-7300U processor (2.6 ~ 3.5 GHz, 3MB cache, 15W), HDMI/LVDS, 1 GbE LAN, 1 USB
PICO512HG-i3-7100U	Pico-ITX SBC with Intel® Core™ i3-7100U processor (2.4 GHz, 3MB cache, 15W), HDMI/LVDS, 1 GbE LAN, 1 USB
PICO512HG-Celeron-3965U	Pico-ITX SBC with Intel® Celeron® 3965U processor (2.2 GHz, 2MB cache, 15W), HDMI/LVDS, 1 GbE LAN, 1 USB

Optional

AX93A00	I/O board for 1 x RS-232/422/485, 1 x RS-232, 4 x USB 3.0, 1 x VGA, 1 x Audio
AX93A01	I/O board for 1 x RS-232/422/485, 1 x RS-232, 4 x USB 3.0, 1 x HDMI, 1 x GbE LAN
AX93A02	I/O board for 1 x RS-232/422/485, 1 x RS-232, 4 x USB 3.0, 1 x Audio
AX93A09	I/O board for 1 x RS-232/422/485, 1 x RS-232, 4 x USB 2.0, 1 x Audio



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Axiomtek:](#)

[PICO512HG-Cel-3965U](#) [PICO512HG-i3-7100U](#) [PICO512HG-i5-7300U](#) [PICO512HG-i7-7600U](#)