


Q7B301

Qseven Rev 2.1 Application Board with LVDS, HDMI, Dual LAN and Audio

Features

- 100 x 72 mini size form factor
- 2 GbE LAN
- SATA-600
- LVDS and HDMI
- 1 USB 2.0 and 2 USB 3.0
- 2 PCI Express Mini Card slots

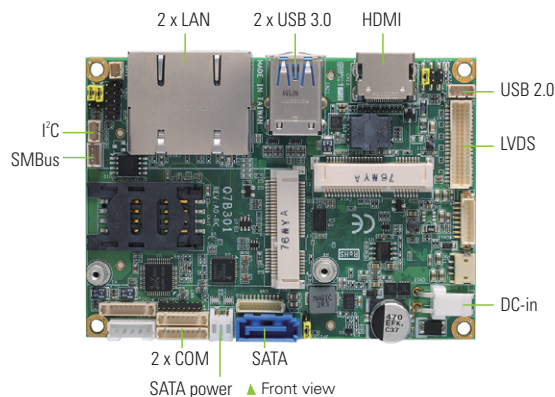


Core System

CPU	On the module
System Memory	On the module
Chipset	On the module
BIOS	On the module
SSD	N/A
Watchdog Timer	On the module
Expansion Interface	1 x Full-size PCI Express Mini Card slot (mSATA supported) 1 x Half-size PCI Express Mini Card slot 1 x SIM card slot 1 x Micro SD card slot
Battery Lithium	N/A
Power Input	2-pin DC-in 12V connector
Dimensions	100 x 72 mm
Board Thickness	1.6 mm
Operating Temperature	-40°C to +85°C (-40°F to +185°F)
Humidity	10% - 95% relative humidity, non-condensing

I/O

SATA	1 x SATA-600
Hardware Monitoring	Yes
Ethernet	1 x 10/100/1000 Mbps Ethernet with Intel® i210-IT; supports Wake-on-LAN, PXE Boot ROM 1 x 10/100/1000 Mbps signals routed from CPU module
Audio	HD audio with Line-out & MIC-in
USB	1 x USB 2.0 2 x USB 3.0
Serial	2 x RS-232/422/485
TPM	N/A
SMBus	Yes
Others	1 x I ² C
GPIO	4-CH in & 4-CH out
Display	1 x LVDS; 18/24-bit single channel 1 x HDMI

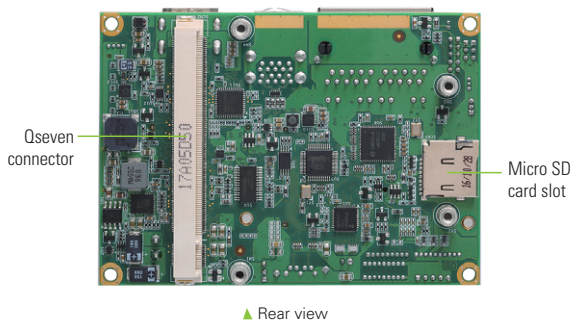

Packing List

Quick installation guide

Ordering Information

Standard	
Q7B301LVDS (P/N: E399301100)	Qseven Rev 2.1 application board with 2 PCI Express Mini Card slots, 2 GbE LAN, LVDS and HDMI

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Axiomtek:](#)

[Q7B301](#)