


PB · PMA · PDA Series Attachment

BASE Attachment

Plate model	Applicable models
F-PBA10-1	PBA10F
F-PBA15-1	PBA15F, PBW15F, PDA15F
F-PBA30-1	PBA30F, PBW30F, PMA15F, PDA30F
F-PBA50-1	PBA50F, PBW50F, PMA30F, PDA50F
F-PBA75-1	PBA75F, PMA60F
F-PBA100-1	PBA100F, PDA100F
F-PBA150-1	PBA150F, PMA100F, PDA150F

Example

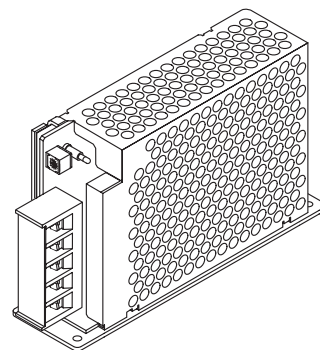

< TOP VIEW > (Unit : mm) (Tolerance : ±1)

F-PBA10-1 Size ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 60g max	F-PBA15-1 Size ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 70g max
★ M3 Flat screw is requested when mounting. Please check catalog for the size of screw.	
Mounting hole size FRONT←	Mounting hole size FRONT←
F-PBA30-1 Size ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 85g max	F-PBA50-1 Size ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 95g max
★ M3 Flat screw is requested when mounting. Please check catalog for the size of screw.	
Mounting hole size FRONT←	Mounting hole size FRONT←


< TOP VIEW > (Unit : mm) (Tolerance : ±1)

F-PBA75-1 Size ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 110g max	F-PBA100-1 Size ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 110g max
★ M3 Flat screw is requested when mounting. Please check catalog for the size of screw.	
Mounting hole size FRONT ←	Mounting hole size FRONT ←
F-PBA150-1 Size ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 130g max	
★ M3 Flat screw is requested when mounting. Please check catalog for the size of screw.	
Mounting hole size FRONT ←	

FRONT · REVERSE Attachment

Plate model	Applicable models
F-PBA10-2	PBA10F
F-PBA15-2	PBA15F, PBW15F, PDA15F
F-PBA30-2	PBA30F, PBW30F, PMA15F, PDA30F
F-PBA50-2	PBA50F, PBW50F, PMA30F, PDA50F
F-PBA75-2	PBA75F, PMA60F
F-PBA100-2	PBA100F, PDA100F
F-PBA150-2	PBA150F, PMA100F, PDA150F

Example

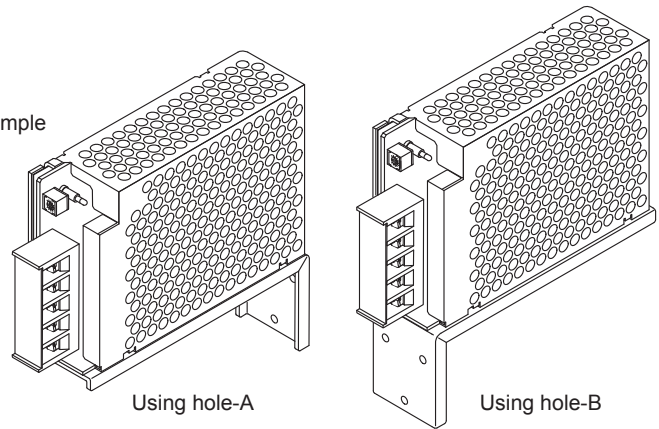




Using hole-A

Using hole-B

〈 TOP VIEW 〉 (Unit : mm) (Tolerance : ±1)

F-PBA10-2	F-PBA15-2
Size ★ Material : SECC ★ Thickness : 1.6 ★ Weight : 60g max	Size ★ Material : SECC ★ Thickness : 1.6 ★ Weight : 70g max
★ M3 screw is requested when mounting. Please check catalog for the size of screw.	
F-PBA30-2	F-PBA50-2
Size ★ Material : SECC ★ Thickness : 1.6 ★ Weight : 80g max	Size ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 120g max
★ M3 screw is requested when mounting. Please check catalog for the size of screw.	

< TOP VIEW > (Unit : mm) (Tolerance : ±1)

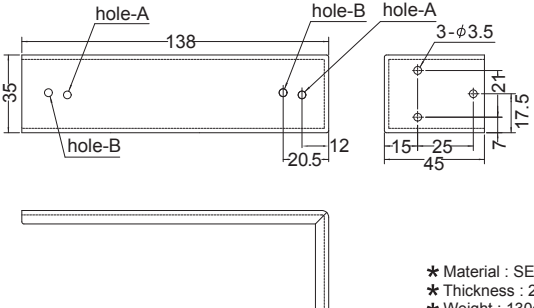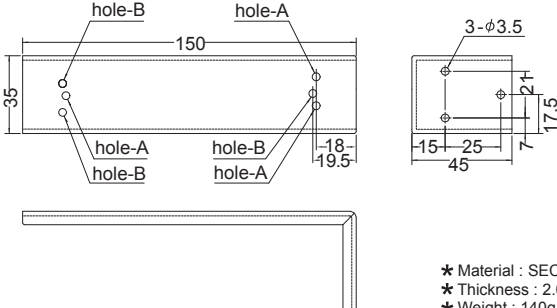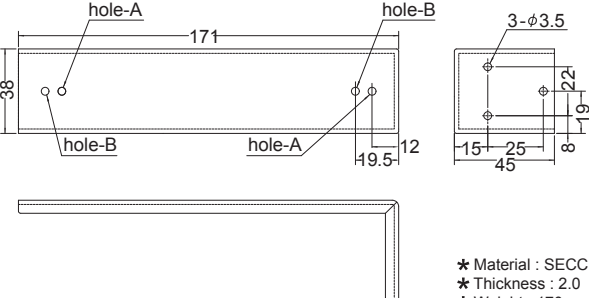F-PBA75-2	F-PBA100-2
Size  ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 130g max	Size  ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 140g max
★ M3 screw is requested when mounting. Please check catalog for the size of screw.	
F-PBA150-2	
Size  ★ Material : SECC ★ Thickness : 2.0 ★ Weight : 170g max ★ M3 screw is requested when mounting. Please check catalog for the size of screw.	

■DIN rail Attachment Plate(PB Series)

APPLICABLE TO MODEL

DIN rail width : 35mm

Plate model	Model	screws for installation	
		Type	Qty
FD-PBA10	PBA10F	M3	2pcs
FD-PBA15	PBA15F, PBW15F		
FD-PBA30	PBA30F, PBW30F		
FD-PBA50	PBA50F, PBW50F, PBA75F		
FD-PBA100	PBA100F	M3	3pcs
	PBA150F	M3	2pcs
FD-PBA300	PBA300F	M4	2pcs

FD-PBA10, FD-PBA15, FD-PBA30 EXTERNAL VIEW

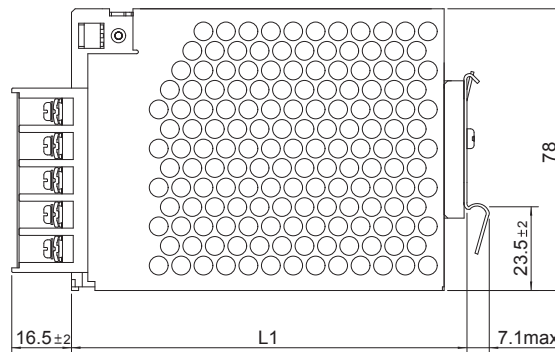
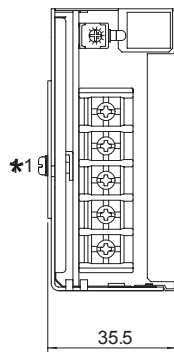


Plate model	Model	L1
FD-PBA10	PBA10F	75.0±2
FD-PBA15	PBA15F, PBW15F	92.0±2
FD-PBA30	PBA30F, PBW30F	110.0±2

- * Material : SECC
- * Thickness : 1.0
- * Tolerance : ±1
- * 1 Screws for installation (attached to Plate)
- * Weight : FD-PBA10 45g max
FD-PBA15 55g max
FD-PBA30 60g max

FD-PBA50, FD-PBA100 EXTERNAL VIEW

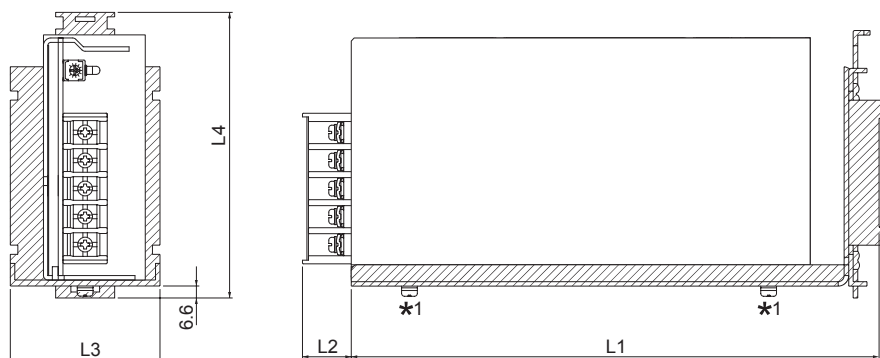


Plate model	Model	L1	L2	L3	L4	★ Material : SECC ★ Thickness : 1.6 ★ Tolerance : ±1 ★ 1 Screws for installation (attached to Plate) ★ Weight : FD-PBA50 220g max Weight : FD-PBA100 260g max
FD-PBA50	PBA50F	135	16.5±2	41	102.5	
	PBA75F	150				
FD-PBA100	PBA100F	162	13.5±2	42.5	112	
	PBA150F	183				

FD-PBA300 EXTERNAL VIEW

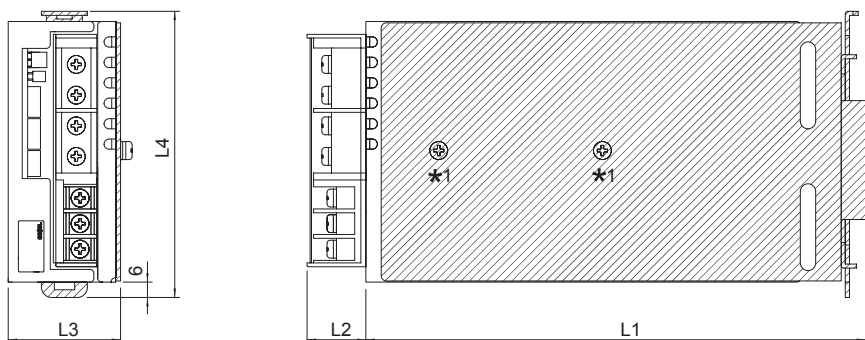


Plate model	Model	L1	L2	L3	L4	* Material : SPHC * Thickness : 2.0 * Tolerance : ± 1 * 1 Screws for installation (attached to Plate) * Weight : 500g max
FD-PBA300	PBA300F	195.5	25max	44	112	

Harness to use the function is prepared in PB series.

PB Series

Mating harness

Model	Harness model #	Contents
PBA10F, PBA15F, PBW15F, PBA30F, PBW30F, PBA50F, PBW50F, PBA75F, PBA100F, PBA150F ★1	H-IN-3 or H-IN-27	Input harness when I/O interface is connector (Mfr: J.S.T.) type (option : -J1)
PBA10F, PBA15F, PBA30F, PBA50F	H-OU-9	Output harness when I/O interface is connector (Mfr: J.S.T.) type (option : -J1)
PBA75F, PBA100F, PBA150F ★1	H-OU-18	Output harness when I/O interface is connector (Mfr: J.S.T.) type (option : -J1)
PBW15F, PBW30F, PBW50F	H-OU-48	Output harness when I/O interface is connector (Mfr: J.S.T.) type (option : -J1)
PBA50F, PBW50F, PBA75F, PBA100F, PBA150F	H-RC-1	Harness for using option : -R
PBA100F, PBA150F ★2	H-SN-1	Harness for using option : -K
PBA10F, PBA15F, PBW15F, PBA30F, PBW30F, PBA50F, PBW50F, PBA75F, PBA100F, PBA150F	H-SN-18	Harness for using option : -V
PBA300F	H-PA-3	Harness for parallel operation
PBA600F	H-SN-20	Harness for using all functions of CN1 and CN2
PBA1000F	H-SN-21	Harness for using all functions except remote sensing of CN2
PBA1500F	H-SN-22	Harness for using all functions of CN3
PBA1500T	H-SN-24	Harness for using example remote ON/OFF circuit (C)

★1 Available for 12V, 15V, 24V, 36V and 48V output model in PBA100F / 150F.

 
★2 Available for 3.3V and 5V output model in PBA100F / 150F.

●Model number

H-IN-3

Housing : VHR-5N (J.S.T.)
Pin : SVH-21T-P1.1 (J.S.T.)
Weight : 20g max

●Type



●Wire


Pin #	Wire	AWG	Color	Length ℓ (mm)
1	UL1015	20	white	500
2				
3	UL1015	20	black	500
4				
5	UL1015	20	green	500

●Model number

H-IN-27

Housing : VHR-5N (J.S.T.)
Pin : SVH-21T-P1.1 (J.S.T.)
Weight : 20g max

 ●Type



●Wire


Pin #	Wire	AWG	Color	Length ℓ (mm)
1	UL1015	20	white	500
2				
3	UL1015	20	black	500
4				
5	UL1015	20	green/yellow	500

●Model number

H-OU-9

Housing : VHR-6N (J.S.T.)
Pin : SVH-21T-P1.1 (J.S.T.)
Weight : 40g max

 ●Type



●Wire


Pin #	Wire	AWG	Color	Length ℓ (mm)
1	UL1015	18	black	500
2	UL1015	18	black	500
3	UL1015	18	red	500
4	UL1015	18	red	500

●Model number

H-OU-18

Housing : VHR-6N (J.S.T.)
Pin : SVH-21T-P1.1 (J.S.T.)
Weight : 60g max

●Type

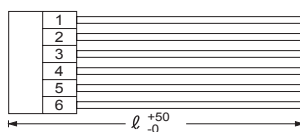

●Wire


Pin #	Wire	AWG	Color	Length ℓ (mm)
1 - 3	UL1015	18	black	500
4 - 6	UL1015	18	red	500

●Model number

H-OU-48

Housing : VHR-4N (J.S.T.)
Pin : SVH-21T-P1.1 (J.S.T.)
Weight : 40g max

 ●Type



●Wire


Pin #	Wire	AWG	Color	Length ℓ (mm)
1	UL1015	18	purple	500
2	UL1015	18	black	500
3	UL1015	18	black	500
4	UL1015	18	red	500

●Model number

H-RC-1

Housing : XHP-2 (J.S.T.)
Pin : SXH-001T-P0.6 (J.S.T.)
Weight : 7g max

 ●Type



●Wire


Pin #	Wire	AWG	Color	Length ℓ (mm)
1	UL1007	22	orange	500
2	UL1007	22	blue	500

●Model number

H-SN-1

Housing : XHP-4 (J.S.T.)
Pin : SXH-001T-P0.6 (J.S.T.)
Weight : 3g max

 ●Type



●Wire


Pin #	Wire	AWG	Color	Length ℓ (mm)
1				
2	UL1061	28	black	500
3	UL1061	28	red	500
4				

●Model number

H-SN-18

Housing : PHR-2 (J.S.T.)
Pin : SPH-002T-P0.5S (J.S.T.)
Weight : 4g max

 ●Type



●Wire


Pin #	Wire	AWG	Color	Length ℓ (mm)
1	UL1007	26	yellow	500
2	UL1007	26	orange	500

●Model number

H-PA-3

Housing : PHDR-10VS(J.S.T.)
Pin : SPHD-002T-P0.5(J.S.T.)
Weight : 5g max

●Type

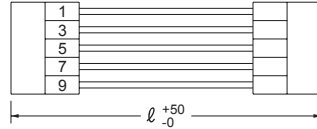

●Wire


Pin #	Wire	AWG	Color	Length ℓ (mm)
1	-	-	-	-
2	UL1061	28	red	270
3	-	-	-	-
4	UL1061	28	black	270
5	UL1061	28	yellow	270
6	UL1061	28	green	270
7	UL1061	28	blue	270
8	-	-	-	-
9	UL1061	28	orange	270
10	UL1061	28	purple	270

●Model number

H-SN-20

Housing : PHDR-10VS(J.S.T.)
Pin : SPHD-002T-P0.5(J.S.T.)
Weight : 8g max

●Type

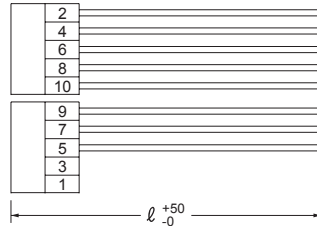

●Wire

Pin #	Wire	AWG	Color	Length ℓ (mm)
1	-	-	-	-
2	UL1061	28	red	500
3	-	-	-	-
4	UL1061	28	black	500
5	UL1061	28	yellow	500
6	UL1061	28	green	500
7	UL1061	28	blue	500
8	UL1061	28	black	500
9	UL1061	28	orange	500
10	UL1061	28	purple	500

●Model number


H-SN-21

Housing : PHDR-10VS(J.S.T)

Pin : SPHD-002T-P0.5(J.S.T)

Weight : 6g max

●Type

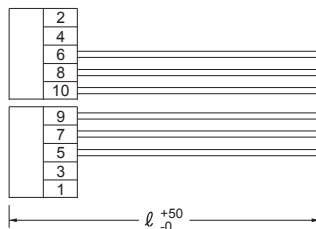

●Wire

Pin #	Wire	AWG	Color	Length ℓ (mm)
1	-	-	-	-
2	-	-	-	-
3	-	-	-	-
4	-	-	-	-
5	UL1061	28	yellow	500
6	UL1061	28	green	500
7	UL1061	28	blue	500
8	UL1061	28	black	500
9	UL1061	28	orange	500
10	UL1061	28	purple	500

●Model number


H-SN-22

Housing : PHDR-8VS(J.S.T)

Pin : SPHD-002T-P0.5(J.S.T)

Weight : 5g max

●Type

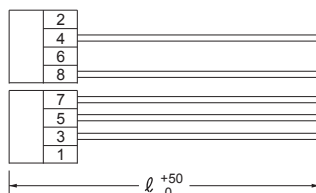

●Wire

Pin #	Wire	AWG	Color	Length ℓ (mm)
1	-	-	-	-
2	-	-	-	-
3	UL1061	28	pink	500
4	UL1061	28	brown	500
5	UL1061	28	white	500
6	-	-	-	-
7	UL1061	28	yellow	500
8	UL1061	28	gray	500

●Model number

H-SN-24

CN A :

Housing : PHDR-10VS(J.S.T)

Pin : SPHD-002T-P0.5(J.S.T)


CN B :

Housing : PHDR-08VS(J.S.T)

Pin : SPHD-002T-P0.5(J.S.T)

Weight : 2g max

●Type

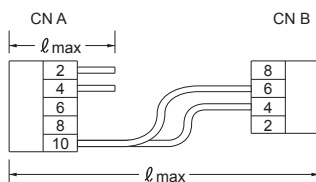

●Wire

Pin #		Wire	AWG	Color	Length ℓ (mm)
CN A	1	UL1061	28	red	30
	2	UL1061	28	red	30
	3	UL1061	28	black	30
	4	UL1061	28	black	30
	5	-	-	-	-
	6	-	-	-	-
	7	-	-	-	-
	8	-	-	-	-
	9	UL1061	28	black	70
	10	UL1061	28	black	70
CN B	1	-	-	-	-
	2	-	-	-	-
	3	-	-	-	-
	4	UL1061	28	black	70
	5	UL1061	28	black	70
	6	-	-	-	-
	7	-	-	-	-
	8	-	-	-	-

- * Pin #1 and #2, Pin #3 and #4 in CN A are connected by harness.
- * Pin #9 in CN A and Pin #4 in CN B are connected by harness.
- * Pin #10 in CN A and Pin #5 in CN B are connected by harness.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cosel:](#)

[F-PPBA30-1](#) [F-PPBA100-1](#) [F-PPBA50-1](#) [F-PPBA150-1](#) [F-PPBA15-1](#)