


Attachment for Replacement

This is an attachment when replacing to PMC series from KMC · 2KMC series.

Classification	Plate model	Applicable models
Vertical	F-KMC15-1	KMC15 → PMC15
Horizontal	F-KMC15-2	2KMC15
Vertical	F-KMC30-1	KMC30 → PMC30
Horizontal	F-KMC30-2	2KMC30

Example
(PMC15)

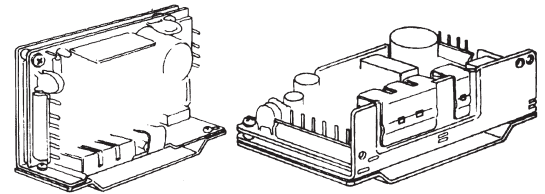

Vertical

Horizontal

(Unit : mm) (Tolerance : ±1)

F-KMC15-1 Size Mounting (TOP VIEW) When change to PMC15, external size becomes larger.	F-KMC15-2 Size Mounting (SIDE VIEW) When change to PMC15, external size becomes larger.
★ M3 screw is requested when mounting. Please check the instruction manual for the size of screw.	
Mounting hole size	Mounting hole size
F-KMC30-1 Size Mounting (SIDE VIEW) When change to PMC30, external size becomes larger.	F-KMC30-2 Size Mounting (SIDE VIEW) When change to PMC30, external size becomes larger.
★ M3 screw is requested when mounting. Please check the instruction manual for the size of screw.	
Mounting hole size	Mounting hole size

Harness Mating harness

MMC Series PMC Series

Model	Harness model #	
	Input	Output
MMC8A	H-IN-2 or H-IN-9	H-OU-2
MMC50A	H-IN-1 or H-IN-8	H-OU-4
MMC75B	H-IN-1 or H-IN-8	H-OU-4
MMC100B	H-IN-1 or H-IN-8	H-OU-4

Model	Harness model #	
	Input	Output
PMC15	H-IN-1 or H-IN-8	H-OU-1
PMC30	H-IN-2 or H-IN-9	H-OU-1
PMC50	H-IN-2 or H-IN-9	H-OU-4
PMC75	H-IN-1 or H-IN-8	H-OU-4
PMC100	H-IN-1 or H-IN-8	H-OU-4

●Model number H-IN-1 Housing : 10-63-3044 (Molex) Pin : 08-70-1030 or 08-70-1031 (Molex) Weight : 25g max	●Type	●Wire <table><thead><tr><th>Pin #</th><th>Wire</th><th>AWG</th><th>Color</th><th>Length ℓ (mm)</th></tr></thead><tbody><tr><td>1</td><td>UL1015</td><td>20</td><td>green</td><td>500</td></tr><tr><td>2</td><td>UL1015</td><td>20</td><td>black</td><td>500</td></tr><tr><td>3</td><td></td><td></td><td></td><td></td></tr><tr><td>4</td><td>UL1015</td><td>20</td><td>white</td><td>500</td></tr></tbody></table>	Pin #	Wire	AWG	Color	Length ℓ (mm)	1	UL1015	20	green	500	2	UL1015	20	black	500	3					4	UL1015	20	white	500																														
Pin #	Wire	AWG	Color	Length ℓ (mm)																																																					
1	UL1015	20	green	500																																																					
2	UL1015	20	black	500																																																					
3																																																									
4	UL1015	20	white	500																																																					
●Model number H-IN-2 Housing : 10-63-3044 (Molex) Pin : 08-70-1030 or 08-70-1031 (Molex) Weight : 25g max	●Type	●Wire <table><thead><tr><th>Pin #</th><th>Wire</th><th>AWG</th><th>Color</th><th>Length ℓ (mm)</th></tr></thead><tbody><tr><td>1</td><td>UL1015</td><td>20</td><td>green</td><td>500</td></tr><tr><td>2</td><td>UL1015</td><td>20</td><td>white</td><td>500</td></tr><tr><td>3</td><td></td><td></td><td></td><td></td></tr><tr><td>4</td><td>UL1015</td><td>20</td><td>black</td><td>500</td></tr></tbody></table>	Pin #	Wire	AWG	Color	Length ℓ (mm)	1	UL1015	20	green	500	2	UL1015	20	white	500	3					4	UL1015	20	black	500																														
Pin #	Wire	AWG	Color	Length ℓ (mm)																																																					
1	UL1015	20	green	500																																																					
2	UL1015	20	white	500																																																					
3																																																									
4	UL1015	20	black	500																																																					
●Model number H-IN-8 Housing : 10-63-3044 (Molex) Pin : 08-70-1030 or 08-70-1031 (Molex) Weight : 25g max	●Type	●Wire <table><thead><tr><th>Pin #</th><th>Wire</th><th>AWG</th><th>Color</th><th>Length ℓ (mm)</th></tr></thead><tbody><tr><td>1</td><td>UL1015</td><td>20</td><td>green/yellow</td><td>500</td></tr><tr><td>2</td><td>UL1015</td><td>20</td><td>black</td><td>500</td></tr><tr><td>3</td><td></td><td></td><td></td><td></td></tr><tr><td>4</td><td>UL1015</td><td>20</td><td>white</td><td>500</td></tr></tbody></table>	Pin #	Wire	AWG	Color	Length ℓ (mm)	1	UL1015	20	green/yellow	500	2	UL1015	20	black	500	3					4	UL1015	20	white	500																														
Pin #	Wire	AWG	Color	Length ℓ (mm)																																																					
1	UL1015	20	green/yellow	500																																																					
2	UL1015	20	black	500																																																					
3																																																									
4	UL1015	20	white	500																																																					
●Model number H-IN-9 Housing : 10-63-3044 (Molex) Pin : 08-70-1030 or 08-70-1031 (Molex) Weight : 25g max	●Type	●Wire <table><thead><tr><th>Pin #</th><th>Wire</th><th>AWG</th><th>Color</th><th>Length ℓ (mm)</th></tr></thead><tbody><tr><td>1</td><td>UL1015</td><td>20</td><td>green/yellow</td><td>500</td></tr><tr><td>2</td><td>UL1015</td><td>20</td><td>white</td><td>500</td></tr><tr><td>3</td><td></td><td></td><td></td><td></td></tr><tr><td>4</td><td>UL1015</td><td>20</td><td>black</td><td>500</td></tr></tbody></table>	Pin #	Wire	AWG	Color	Length ℓ (mm)	1	UL1015	20	green/yellow	500	2	UL1015	20	white	500	3					4	UL1015	20	black	500																														
Pin #	Wire	AWG	Color	Length ℓ (mm)																																																					
1	UL1015	20	green/yellow	500																																																					
2	UL1015	20	white	500																																																					
3																																																									
4	UL1015	20	black	500																																																					
●Model number H-OU-1 Housing : 10-63-3064 (Molex) Pin : 08-70-1030 or 08-70-1031 (Molex) Weight : 40g max	●Type	●Wire <table><thead><tr><th>Pin #</th><th>Wire</th><th>AWG</th><th>Color</th><th>Length ℓ (mm)</th></tr></thead><tbody><tr><td>1</td><td></td><td></td><td></td><td></td></tr><tr><td>2</td><td>UL1015</td><td>20</td><td>black</td><td>500</td></tr><tr><td>3</td><td>UL1015</td><td>20</td><td>red</td><td>500</td></tr><tr><td>4</td><td>UL1015</td><td>20</td><td>purple</td><td>500</td></tr><tr><td>5</td><td>UL1015</td><td>20</td><td>gray</td><td>500</td></tr><tr><td>6</td><td>UL1015</td><td>20</td><td>orange</td><td>500</td></tr></tbody></table>	Pin #	Wire	AWG	Color	Length ℓ (mm)	1					2	UL1015	20	black	500	3	UL1015	20	red	500	4	UL1015	20	purple	500	5	UL1015	20	gray	500	6	UL1015	20	orange	500																				
Pin #	Wire	AWG	Color	Length ℓ (mm)																																																					
1																																																									
2	UL1015	20	black	500																																																					
3	UL1015	20	red	500																																																					
4	UL1015	20	purple	500																																																					
5	UL1015	20	gray	500																																																					
6	UL1015	20	orange	500																																																					
●Model number H-OU-2 Housing : 09-50-1053 (Molex) Pin : 08-70-1030 or 08-70-1031 (Molex) Weight : 40g max	●Type	●Wire <table><thead><tr><th>Pin #</th><th>Wire</th><th>AWG</th><th>Color</th><th>Length ℓ (mm)</th></tr></thead><tbody><tr><td>1</td><td>UL1015</td><td>20</td><td>red</td><td>500</td></tr><tr><td>2</td><td>UL1015</td><td>20</td><td>black</td><td>500</td></tr><tr><td>3</td><td>UL1015</td><td>20</td><td>orange</td><td>500</td></tr><tr><td>4</td><td>UL1015</td><td>20</td><td>gray</td><td>500</td></tr><tr><td>5</td><td>UL1015</td><td>20</td><td>purple</td><td>500</td></tr></tbody></table>	Pin #	Wire	AWG	Color	Length ℓ (mm)	1	UL1015	20	red	500	2	UL1015	20	black	500	3	UL1015	20	orange	500	4	UL1015	20	gray	500	5	UL1015	20	purple	500																									
Pin #	Wire	AWG	Color	Length ℓ (mm)																																																					
1	UL1015	20	red	500																																																					
2	UL1015	20	black	500																																																					
3	UL1015	20	orange	500																																																					
4	UL1015	20	gray	500																																																					
5	UL1015	20	purple	500																																																					
●Model number H-OU-4 Housing : 09-50-1103 (Molex) Pin : 08-70-1030 or 08-70-1031 (Molex) Weight : 100g max	●Type	●Wire <table><thead><tr><th>Pin #</th><th>Wire</th><th>AWG</th><th>Color</th><th>Length ℓ (mm)</th></tr></thead><tbody><tr><td>1</td><td>UL1015</td><td>18</td><td>red</td><td>500</td></tr><tr><td>2</td><td>UL1015</td><td>18</td><td>red</td><td>500</td></tr><tr><td>3</td><td>UL1015</td><td>18</td><td>black</td><td>500</td></tr><tr><td>4</td><td>UL1015</td><td>18</td><td>black</td><td>500</td></tr><tr><td>5</td><td>UL1015</td><td>18</td><td>orange</td><td>500</td></tr><tr><td>6</td><td>UL1015</td><td>18</td><td>orange</td><td>500</td></tr><tr><td>7</td><td>UL1015</td><td>18</td><td>gray</td><td>500</td></tr><tr><td>8</td><td>UL1015</td><td>18</td><td>gray</td><td>500</td></tr><tr><td>9</td><td>UL1015</td><td>18</td><td>purple</td><td>500</td></tr><tr><td>10</td><td>UL1015</td><td>18</td><td>purple</td><td>500</td></tr></tbody></table>	Pin #	Wire	AWG	Color	Length ℓ (mm)	1	UL1015	18	red	500	2	UL1015	18	red	500	3	UL1015	18	black	500	4	UL1015	18	black	500	5	UL1015	18	orange	500	6	UL1015	18	orange	500	7	UL1015	18	gray	500	8	UL1015	18	gray	500	9	UL1015	18	purple	500	10	UL1015	18	purple	500
Pin #	Wire	AWG	Color	Length ℓ (mm)																																																					
1	UL1015	18	red	500																																																					
2	UL1015	18	red	500																																																					
3	UL1015	18	black	500																																																					
4	UL1015	18	black	500																																																					
5	UL1015	18	orange	500																																																					
6	UL1015	18	orange	500																																																					
7	UL1015	18	gray	500																																																					
8	UL1015	18	gray	500																																																					
9	UL1015	18	purple	500																																																					
10	UL1015	18	purple	500																																																					

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cosel:](#)

[F-KMC15-2](#) [F-KMC30-2](#) [F-KMC30-1](#)