


2-polig

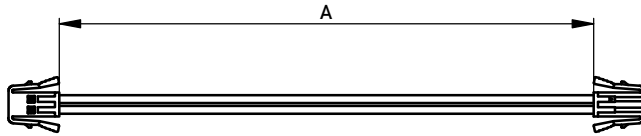

3-polig



4-polig




5-polig




6-polig



8-polig

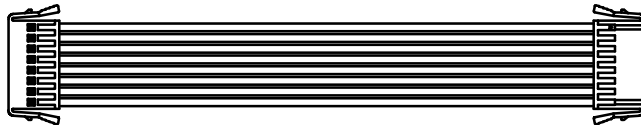

M 1:1

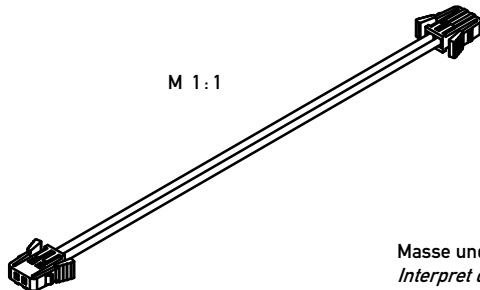

Masse und Toleranzen in Übereinstimmung mit ANSI Y15.5M-1994 /
Interpret dimensions according to ANSI Y15.5M-1994

100	109948	2	30 min.	Cable Assy 2E100 Sn AWG 22 PVC	Box	400
200	109949	2	30 min.	Cable Assy 2E200 Sn AWG 22 PVC	Box	400
300	109950	2	30 min.	Cable Assy 2E300 Sn AWG 22 PVC	Box	400
100	109951	2	30 min.	Cable Assy 2E100 Sn AWG 24 PVC	Box	400
200	109952	2	30 min.	Cable Assy 2E200 Sn AWG 24 PVC	Box	400
300	109953	2	30 min.	Cable Assy 2E300 Sn AWG 24 PVC	Box	400
100	109954	3	30 min.	Cable Assy 2E100 Sn AWG 22 PVC	Box	400
200	109955	3	30 min.	Cable Assy 2E200 Sn AWG 22 PVC	Box	400
300	109956	3	30 min.	Cable Assy 2E300 Sn AWG 22 PVC	Box	400
100	109957	3	30 min.	Cable Assy 2E100 Sn AWG 24 PVC	Box	400
200	109958	3	30 min.	Cable Assy 2E200 Sn AWG 24 PVC	Box	400
300	109959	3	30 min.	Cable Assy 2E300 Sn AWG 24 PVC	Box	400
100	109960	4	30 min.	Cable Assy 2E100 Sn AWG 22 PVC	Box	300
200	109961	4	30 min.	Cable Assy 2E200 Sn AWG 22 PVC	Box	300
300	109962	4	30 min.	Cable Assy 2E300 Sn AWG 22 PVC	Box	300
100	109963	4	30 min.	Cable Assy 2E100 Sn AWG 24 PVC	Box	300
200	109964	4	30 min.	Cable Assy 2E200 Sn AWG 24 PVC	Box	300
300	109965	4	30 min.	Cable Assy 2E300 Sn AWG 24 PVC	Box	300
100	109966	5	30 min.	Cable Assy 2E100 Sn AWG 22 PVC	Box	300
200	109967	5	30 min.	Cable Assy 2E200 Sn AWG 22 PVC	Box	300
300	109968	5	30 min.	Cable Assy 2E300 Sn AWG 22 PVC	Box	300
100	109969	5	30 min.	Cable Assy 2E100 Sn AWG 24 PVC	Box	300
200	109970	5	30 min.	Cable Assy 2E200 Sn AWG 24 PVC	Box	300
300	109971	5	30 min.	Cable Assy 2E300 Sn AWG 24 PVC	Box	240
100	109972	6	30 min.	Cable Assy 2E100 Sn AWG 22 PVC	Box	240
200	109973	6	30 min.	Cable Assy 2E200 Sn AWG 22 PVC	Box	240
300	109974	6	30 min.	Cable Assy 2E300 Sn AWG 22 PVC	Box	240
100	109975	6	30 min.	Cable Assy 2E100 Sn AWG 24 PVC	Box	240
200	109976	6	30 min.	Cable Assy 2E200 Sn AWG 24 PVC	Box	240
300	109977	6	30 min.	Cable Assy 2E300 Sn AWG 24 PVC	Box	240
100	109978	8	30 min.	Cable Assy 2E100 Sn AWG 22 PVC	Box	240
200	109979	8	30 min.	Cable Assy 2E200 Sn AWG 22 PVC	Box	240
300	109980	8	30 min.	Cable Assy 2E300 Sn AWG 22 PVC	Box	240
100	109981	8	30 min.	Cable Assy 2E100 Sn AWG 24 PVC	Box	240
200	109982	8	30 min.	Cable Assy 2E200 Sn AWG 24 PVC	Box	240
300	109983	8	30 min.	Cable Assy 2E300 Sn AWG 24 PVC	Box	240

Mass A	Id-Nr.	Polzahl # of positions	mating cycles	Bezeichnung description	Verpackung packaging	VPE: Stück packaging unit: pcs
--------	--------	---------------------------	------------------	----------------------------	-------------------------	-----------------------------------

Information:

Tolerances



Scale 5:1

All rights reserved.
Only for Information.
To ensure that this is the latest
version of this drawing, please
contact one of the ERNI companies
before using.

Subject to modification without
prior notice.
Drawing will not be updated.

Designation

iBridge cable assembly

www.ERNI.com

109984

I
A3

Index

Date

Class

IBRIDGE_CS

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ERNI Electronics:](#)

[109980](#)