


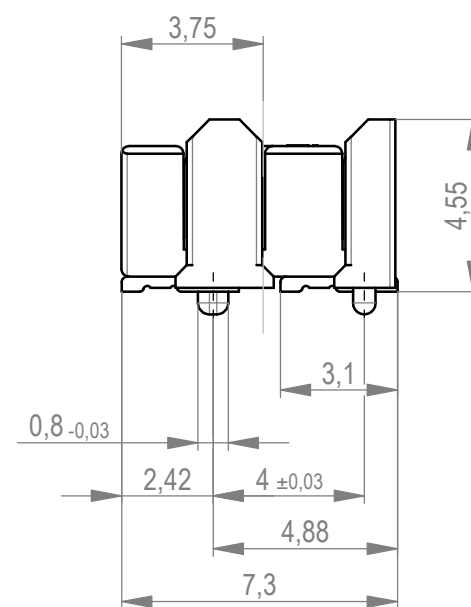
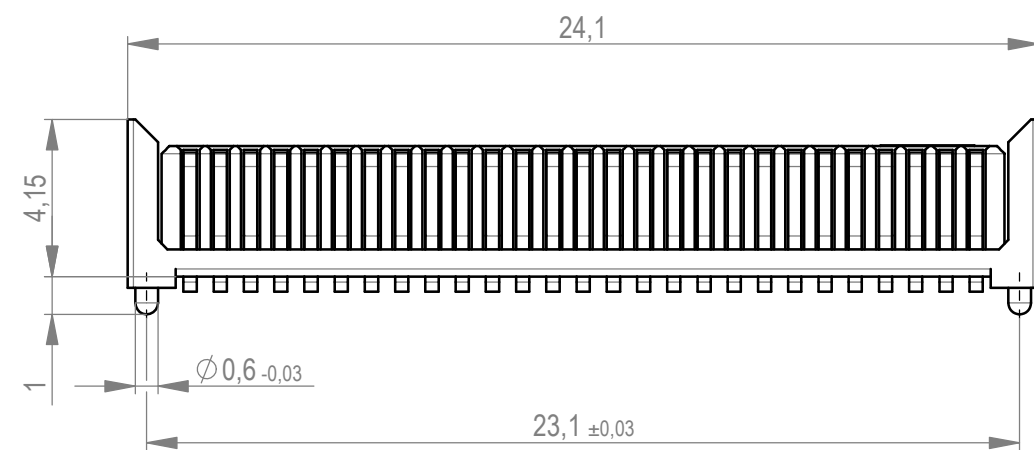


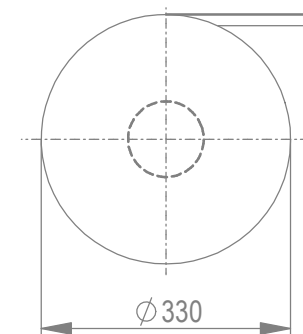

Verpackt im Gurt in Anlehnung an DIN IEC 60286-3
tape on reel packaging according to DIN IEC 60286-3
 Verpackungseinheit: 800 Stück
packaging unit: 800 pcs

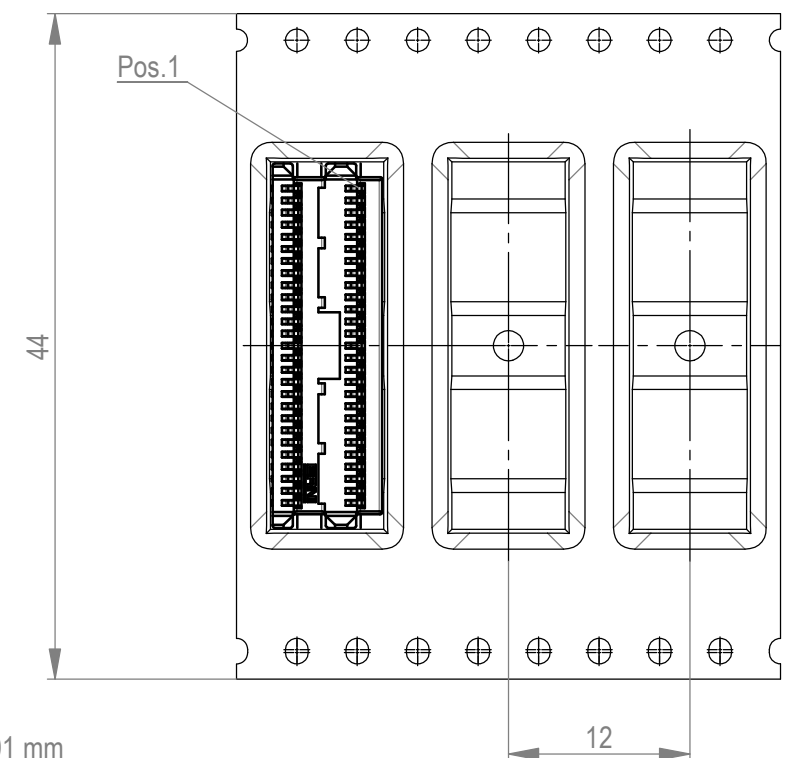


Abspulrichtung - reel off direction

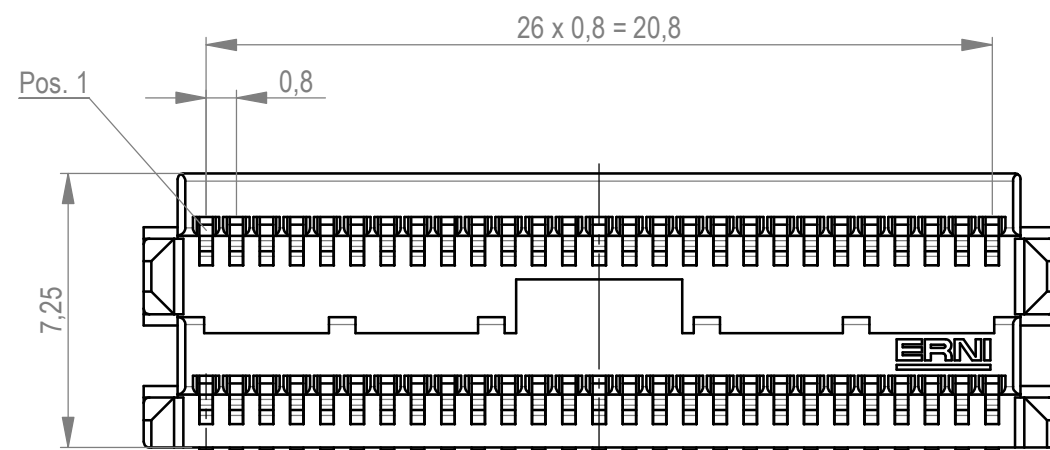

Leiterplatten-Layout Vorschlag

PCB-Layout Proposal

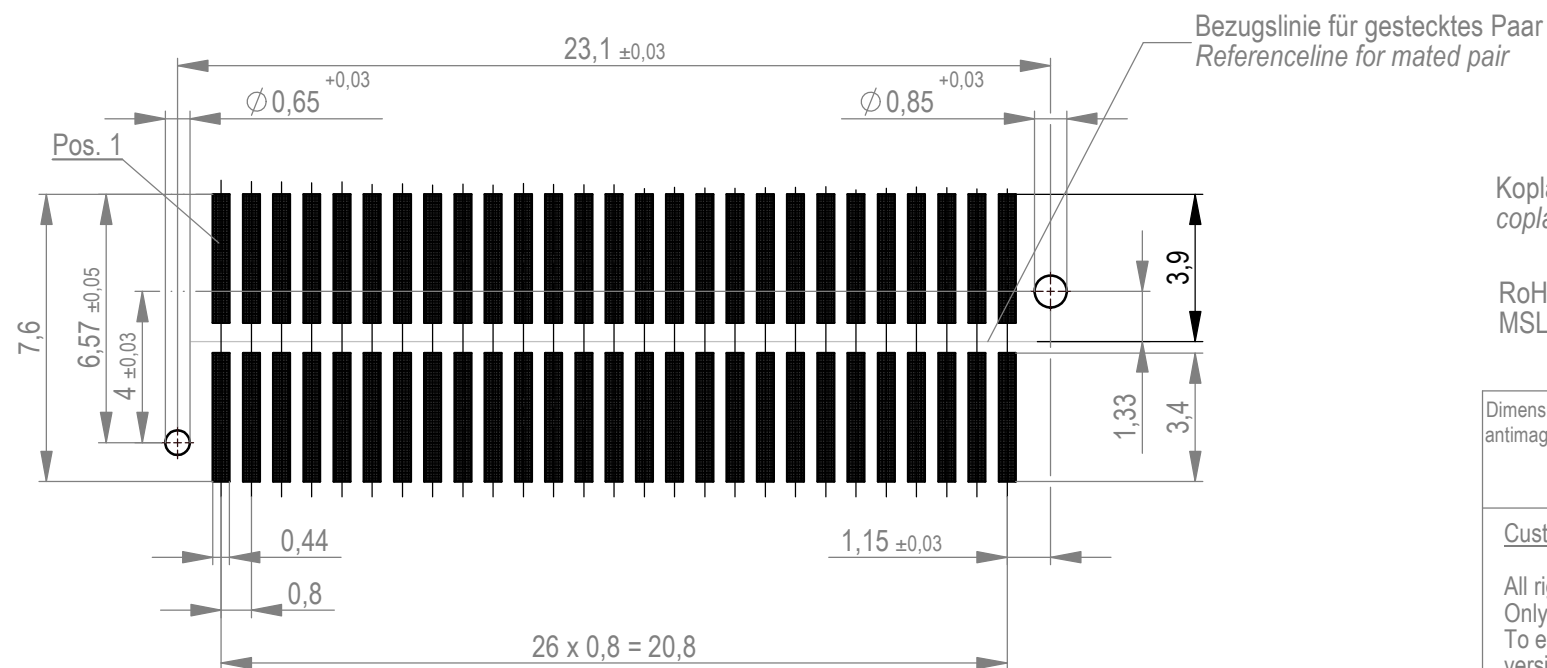

Koplanarität der Anschlüsse $\leq 01 \text{ mm}$
coplanarity area of termination $\leq 0,1 \text{ mm}$

RoHS: 6/6
MSL: 1

zweireihig, mit Zapfen

2 row, with pegs

Dimension no. antimagnetische Variante / <i>non magnetic type</i>		Tolerances ISO 8015		 All Dimensions in mm		Scale 5:1			
						Material			
<u>Customer drawing:</u> All rights reserved. Only for Information. To ensure that this is the latest version of this drawing, please contact one of the ERNI companies before using.		Subject to modification without prior notice. Drawing will not be updated.				MicroStac Steckverb., 54 polig <i>MicroStac Conn., 54 contacts</i>			
						484438			
b Index		12.11.2020 Date		 ERNI International AG Zürichstrasse 72 8306 Brüttisellen - Zürich Switzerland		Class		MICROS	
								I A3	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ERNI Electronics:](#)

[484438](#)