



ERbic Profibus, horizontal

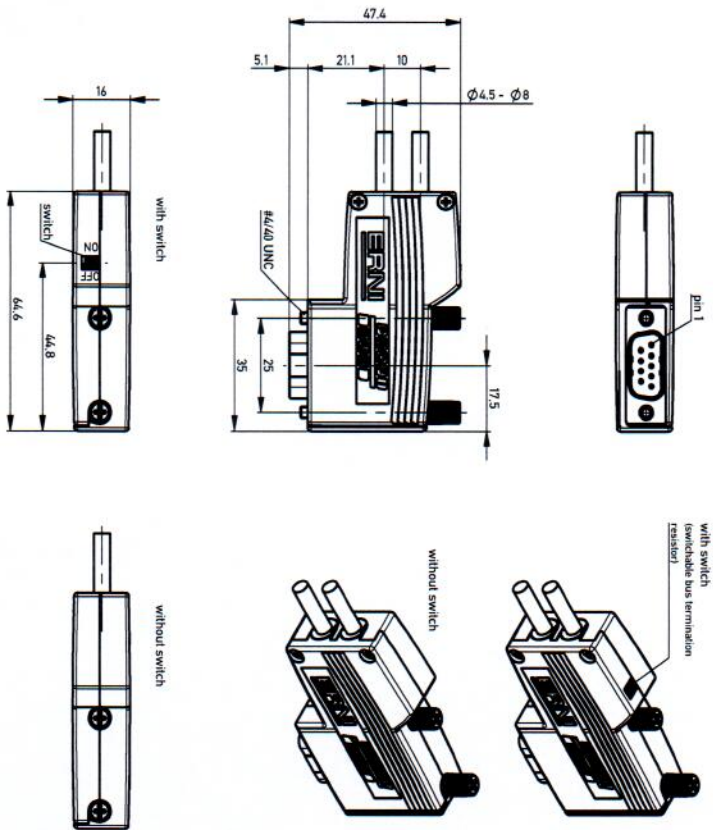

104050	Switch	without	Screw clamp 4 pin	pebble grey	A- and B Line	#4-40 UNC
174048			Spring clamp 4 pin			
144037			IDC terminal 2x2 pin			
134728			Screw clamp 4 pin			
103648	Node	Termination	Screw clamp 4 pin	yellow		
103649	Termination		Screw clamp 2 pin			
Part number	Type	Programming interface (PU)	Cable termination	Colour	Signals / Power supply	Fastening screw thread

ERbic Profibus with PU interface, horizontal

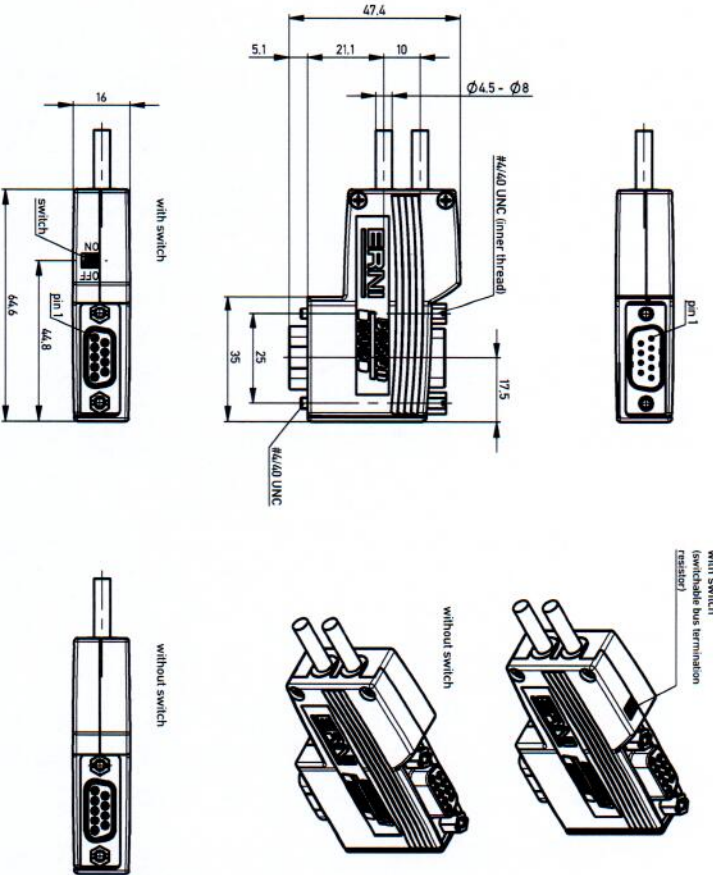

366326	Switch	with	Screw clamp 4 pin	light grey	A- and B Line	#4-40 UNC
174049			Spring clamp 4 pin			
144536			IDC terminal 2x2 pin			
144475			Screw clamp 4 pin			
103663	Node	Termination	Screw clamp 4 pin	yellow		
104329	Termination		Screw clamp 2 pin			
Part number	Type	Programming interface (PU)	Cable termination	Colour	Signals / Power supply	Fastening screw thread

Notes:

1. Operating temperature: -20°C / +70°C
2. Protection class: IP40
3. Sealing plate Drawing number 103356.

Information:		Tolerances:		Scale:	
All rights reserved.		All dimensions in mm		1:1	
Only for information.		Subject to modification without notice.		ERbic horizontal Profibus	
To ensure this is the latest version, please contact one of the ERNI companies before using.		Drawing will not be updated.		General plan	
www.ERNI.com		324261		1	
ERbic		ERbic		A2	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[ERNI Electronics:](#)

[144536](#)