


SERIES 76




SPST Rocker

FEATURES




- Raised and Recessed, Rocker and PIANO-DIP® Styles
- Sealed Base Standard
- Spring and Ball Contact
- Top Tape Seal Option

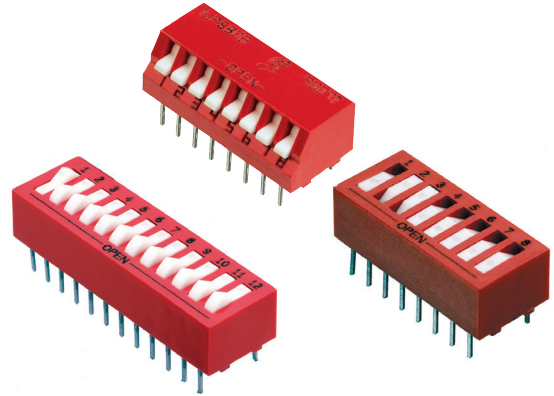

DIMENSIONS in inches (and millimeters)

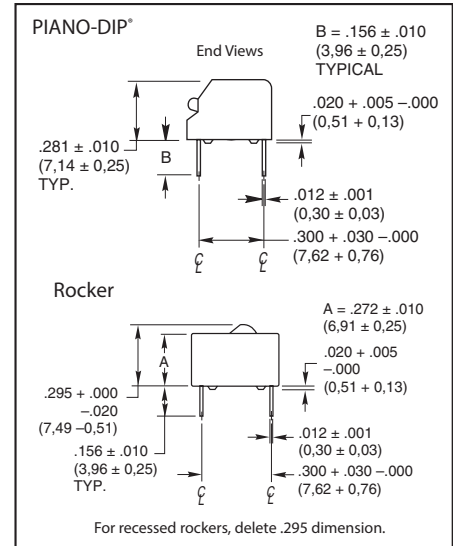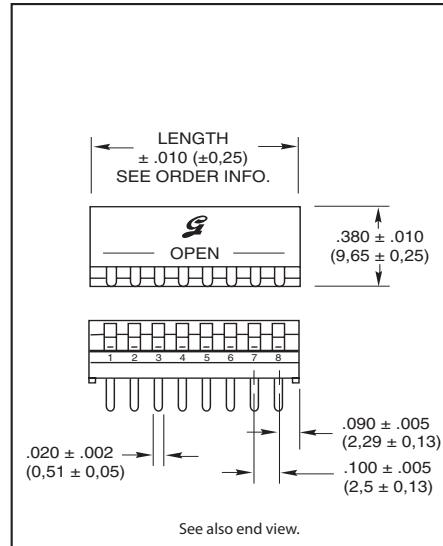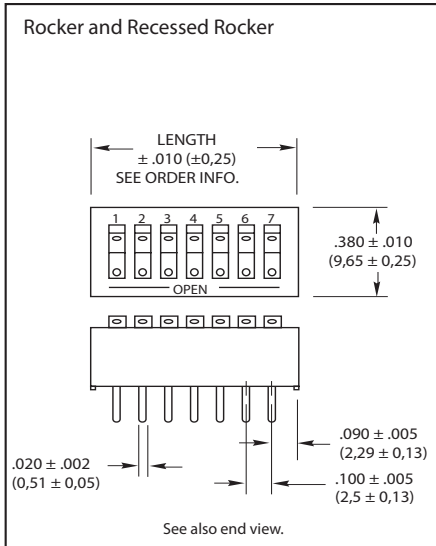

CIRCUITRY

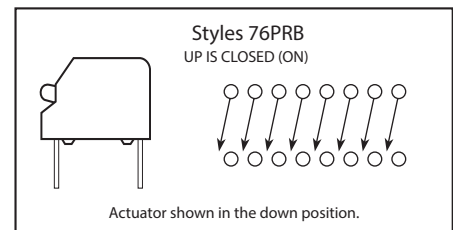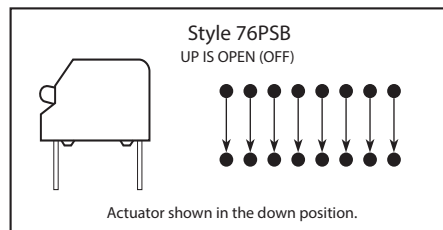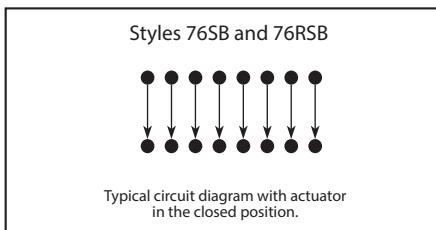

ORDERING INFORMATION

Series Switch Style: SB = Raised Rocker RSB = Recessed Rocker PSB = Piano-DIP (Up is Off) PRB = Piano-DIP (Up is On) T = RoHS compliant Sealed*: S = Tape Seal Number of Positions: 02 through 10, 12	No. of Pos.	Length (Inches)	Length (Metric)	No./Tube
	2	0.280"	7,1 mm	35
	3	0.380"	9,7 mm	27
	4	0.480"	12,2 mm	21
	5	0.580"	14,7 mm	18
	6	0.680"	17,3 mm	15
	7	0.780"	19,8 mm	13
	8	0.880"	22,4 mm	12
	10	1.080"	27,4 mm	9
	12	1.280"	32,5 mm	8

*A top tape seal is required for switches that are machine soldered or heavily cleaned after hand soldering. To order top seal versions, add "S" to the Grayhill part number.

Available from your local Grayhill Distributor.
For prices and discounts, contact a local Sales Office,
an authorized local Distributor or Grayhill.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Grayhill:](#)

[76RSB10SLT](#)