

Actuator

02-
810.001



<https://eao.com/p/02-810.001>

Your product:



02-810.001 Actuator

FRONT

Front form: rectangular

MOUNTING

Design: flush

Mounting cut-out: 21.2 mm x 29.2 mm

Mounting type: Panel mounting

ELECTRICAL CHARACTERISTICS

Operating voltage: 10 - 55 V AC

Switching voltage and switching current: 10 VAC ... 55 VAC, 25 mA
10 VDC ... 75 VDC, 15 mA

MECHANICAL CHARACTERISTIC

Terminal: Screw terminal

Tightening torque: Fixing sleeve max. 0.2 Nm, Screw terminal 0.8 Nm

Weight: 0.06 kg

ACOUSTICAL CHARACTERISTICS

Tone frequency: ca. 2.8 kHz

AMBIENT CONDITION

IP Protection: IP40 front side, according to DIN EN 60529

Operating temperature: - 20 °C ... + 60 °C

Storage temperature: – 30 °C ... + 70 °C

CERTIFICATE

Conformities: CE, UKCA, 2011 / 65 / EC (RoHS), 2014 / 30 / EU (EMC)

REACH: REACH compliant


RoHS: RoHS compliant

OTHER


Short Description: Actuator, 21.2 mm x 29.2 mm, rectangular, Screw terminal

Buzzer system: Electronic non-contacting buzzer with IC oscillator


Wiring diagrams:

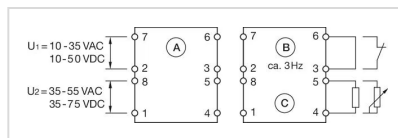

Mounting cut-outs:

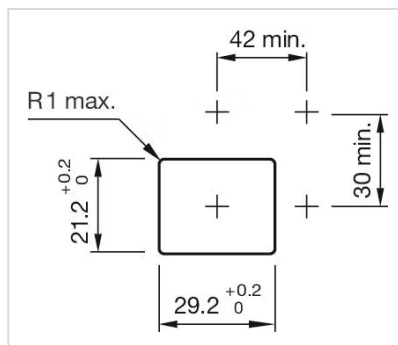

Dimension drawings:

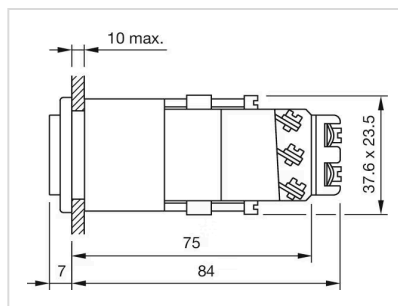

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[02-810.001](#)