

Actuator

14-
810.002



<https://eao.com/p/14-810.002>

Your product:



14-810.002 Actuator

FRONT

Front dimension:	Ø 29 mm
Front form:	round
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	raised
Mounting type:	Panel mounting

ELECTRICAL CHARACTERISTICS

Operating voltage:	24 V DC $\pm 10\%$
Operation current:	- 25

MECHANICAL CHARACTERISTIC

Terminal:	Plug-in terminal, 2.8 x 0.5 mm
Tightening torque:	Fixing nut max. 0.25 Nm
Weight:	0.016 kg

ACOUSTICAL CHARACTERISTICS

Tone frequency:	Approx. 3.2 kHz continuous tone only
-----------------	--------------------------------------

AMBIENT CONDITION

IP front protection: IP65, according to DIN EN 60529

Operating temperature: - 25 °C ... + 55 °C

Storage temperature: - 40 °C ... + 85 °C

CERTIFICATE

Approbations: CQC, EMC

Conformities: CE, UKCA, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)

REACH: REACH compliant

RoHS: RoHS compliant


OTHER

Short Description: Actuator, Ø 29 mm, round, Black, Plastic, Plug-in terminal, 2.8 x 0.5 mm, IP65, according to DIN EN 60529



Hints: For PCB application use print adator

Buzzer system: Piezo disc


Wiring diagrams:

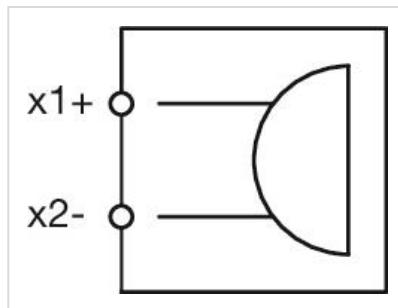

Mounting cut-outs:

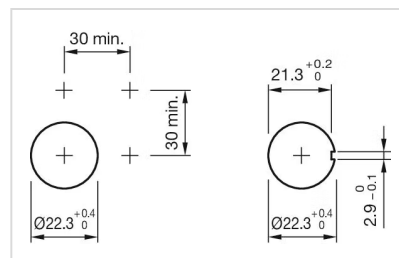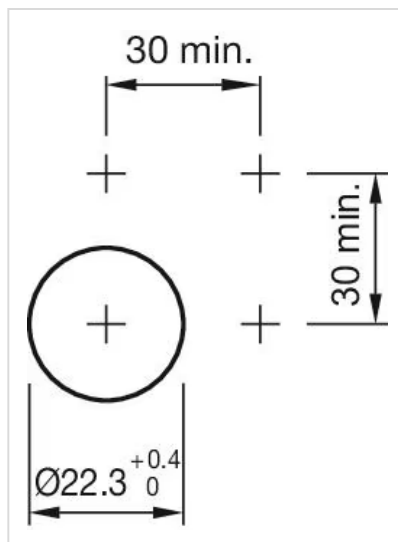

Dimension drawings:

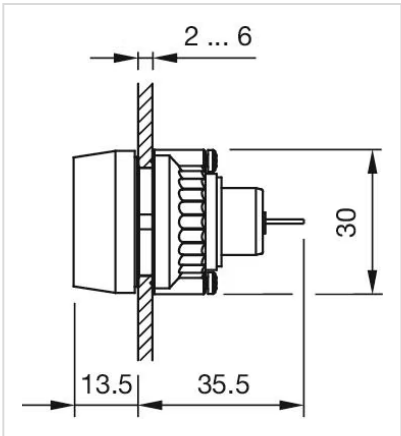

Where to Buy

Distributor		Quantity in Stock		
	Distrelec	80 in stock	Buy	
	Farnell UK	42 in stock	Buy	
	Newark	42 in stock	Buy	
	element14 Singapore	42 in stock	Buy	
	DigiKey	38 in stock	Buy	

Show more +

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[14-810.002](#)