

# Actuator

45-  
2131.1150.000



<https://eao.com/p/45-2131.1150.000>

Your product:

---



## 45-2131.1150.000 Actuator

### FRONT

Front dimension:	Ø 29,5 mm
Front form:	round
Front bezel colour:	Black
Front bezel material:	Plastic

### MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm
Mounting type:	Panel mounting

### OPERATING-/INDICATION PART

Lens colour:	Green
Lens material:	Plastic
Lens illumination:	non illuminative
Lens shape:	flush
Lens optics:	opaque

### MECHANICAL CHARACTERISTIC

Switching action:	Momentary
Switching system:	Slow-make switching element
Mechanical lifetime:	500 000 cycles of operation
Operating frequency:	Max. 3 600/h

**Weight:** 0.019 kg

## AMBIENT CONDITION

**IP front protection:** IP66, IP67, IP69K

**Operating temperature:** – 25 °C ... + 70 °C

**Storage temperature:** – 40 °C ... + 80 °C

**Shock resistance:** According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

**Vibration resistance:** According to IEC 60068-2-6: 20 ... 500 Hz: 5 g

**Climate resistance:** During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

## CERTIFICATE

**REACH:** REACH compliant

**RoHS:** RoHS compliant


## OTHER

**Short Description:** Actuator, Ø 22.3 mm, Ø 29,5 mm, flush, non illuminative, Green, Plastic, opaque, round, Black, Plastic, Momentary, IP66, IP67, IP69K

**Housing colour:** Black

**Housing material:** Plastic

**Wiring diagrams:**

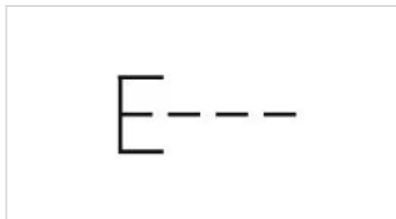

**Mounting cut-outs:**



Dimension drawings:



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-2131.1150.000](#)