

# Actuator

45-  
2234.4FH0.000



<https://eao.com/p/45-2234.4FH0.000>

Your product:

---



## 45-2234.4FH0.000 Actuator

### FRONT

Front dimension:	Ø 38 mm
Front form:	round
Front bezel colour:	Sand grey
Front bezel material:	Metal

### MOUNTING

Design:	flush
Mounting cut-out:	Ø 30.5 mm
Mounting type:	Panel mounting

### OPERATING-/INDICATION PART

Lens colour:	Green
Lens material:	Plastic
Lens illumination:	illuminative
Lens shape:	flush
Lens optics:	transparent
Illumination colour:	Green

### MECHANICAL CHARACTERISTIC

Switching action:	Maintained
Switching system:	Slow-make switching element
Mechanical lifetime:	500 000 cycles of operation

**Operating frequency:** Max. 1 800/h

**Weight:** 0.073 kg

## AMBIENT CONDITION

**IP front protection:** IP66, IP67, IP69K

**Operating temperature:** – 25 °C ... + 70 °C

**Storage temperature:** – 40 °C ... + 80 °C

**Shock resistance:** According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

**Vibration resistance:** According to IEC 60068-2-6: 20 ... 500 Hz: 5 g

**Climate resistance:** During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

## CERTIFICATE

**REACH:** REACH compliant

**RoHS:** RoHS compliant

## OTHER


**Short Description:** Actuator, Ø 30.5 mm, Ø 38 mm, flush, illuminative, Green, Plastic, transparent, round, Sand grey, Metal, Maintained, IP66, IP67, IP69K, Green

**Housing colour:** Silver


**Housing material:** Metal

**Hints:** Push to unlatch

**Wiring diagrams:**

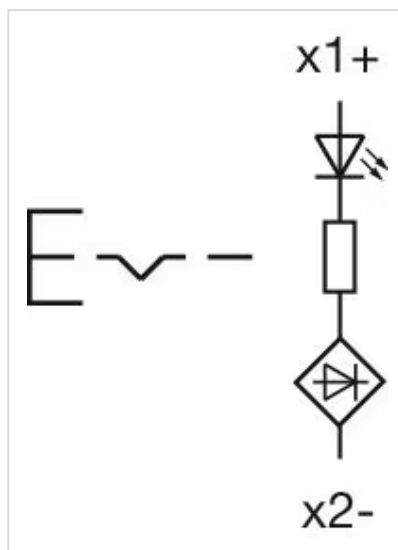

**Dimension drawings:**

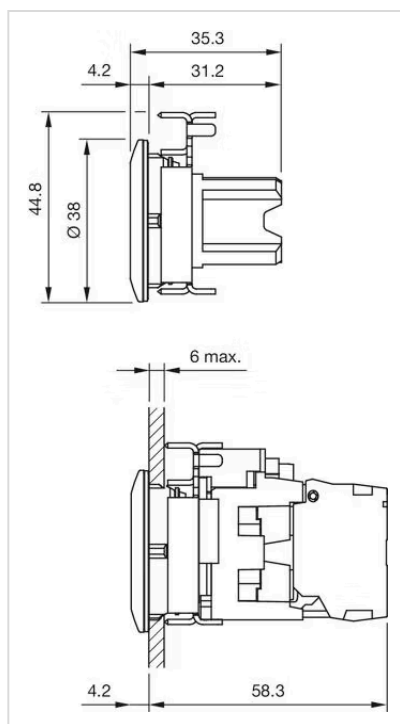

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-2234.4FH0.000](#)