

Actuator

45-

2234.4FK0.000



<https://eao.com/p/45-2234.4FK0.000>

Your product:



45-2234.4FK0.000 Actuator

FRONT

Front dimension: Ø 38 mm

Front form: round

Front bezel colour: Sand grey

Front bezel material: Metal

MOUNTING

Design: flush

Mounting cut-out: Ø 30.5 mm

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens colour: Colourless

Lens material: Plastic

Lens illumination: illuminative

Lens shape: flush

Lens optics: transparent

Illumination colour: White

MECHANICAL CHARACTERISTIC

Switching action: Maintained

Switching system: Slow-make switching element

Mechanical lifetime: 500 000 cycles of operation

Operating frequency: Max. 1 800/h

Weight: 0.072 kg

AMBIENT CONDITION

IP front protection: IP66, IP67, IP69K

Operating temperature: – 25 °C ... + 70 °C

Storage temperature: – 40 °C ... + 80 °C

Shock resistance: According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

Vibration resistance: According to IEC 60068-2-6: 20 ... 500 Hz: 5 g

Climate resistance: During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant

OTHER


Short Description: Actuator, Ø 30.5 mm, Ø 38 mm, flush, illuminative, Colourless, Plastic, transparent, round, Sand grey, Metal, Maintained, IP66, IP67, IP69K, White

Housing colour: Silver


Housing material: Metal

Hints: Push to unlatch

Wiring diagrams:

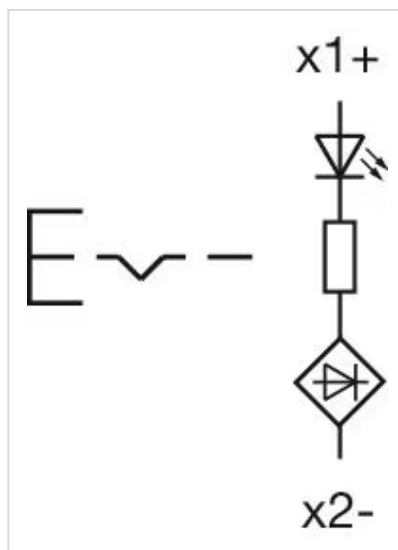

Dimension drawings:

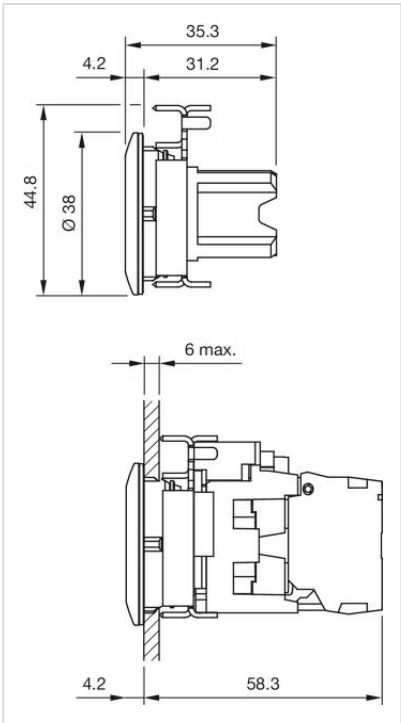

Where to Buy

Distributor		Quantity in Stock		
	Digi-Key	5 in stock	Buy	
	Mouser Electronics	0 in stock	Buy	
	Sager	0 in stock	Buy	
	Newark Electronics	0 in stock	Buy	
	RS Americas	0 in stock	Buy	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-2234.4FK0.000](#)