

# Actuator

45-  
2819.2D90.003



<https://eao.com/p/45-2819.2D90.003>

Your product:

---



## 45-2819.2D90.003 Actuator

### FRONT

Front dimension:	Ø 29,5 mm
Front form:	round
Front bezel colour:	Silver
Front bezel material:	Metal

### MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm
Mounting type:	Panel mounting

### OPERATING-/INDICATION PART

Lever colour:	White
Lever material:	plastic
Lever shape:	long

### MECHANICAL CHARACTERISTIC

Switching action:	Maintained - Rest - Maintained
Switching positions:	3 positions
Switching angle:	45° left / 45° right / -45° ... +45°
Mechanical lifetime:	1 Mio. cycles of operation
Operating frequency:	1 800/h
Weight:	0.052 kg

## AMBIENT CONDITION

<b>IP front protection:</b>	IP66, IP67, IP69K
<b>Operating temperature:</b>	– 25 °C ... + 70 °C
<b>Storage temperature:</b>	– 40 °C ... + 80 °C
<b>Shock resistance:</b>	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms
<b>Vibration resistance:</b>	According to IEC 60068-2-6: 10 ... 500 Hz: 5 g
<b>Climate resistance:</b>	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

## CERTIFICATE


<b>REACH:</b>	REACH compliant
<b>RoHS:</b>	RoHS compliant

## OTHER

<b>Short Description:</b>	Actuator, Ø 22.3 mm, Ø 29,5 mm, optional illuminative, White, long, round, Silver, Metal, Maintained - Rest - Maintained, IP66, IP67, IP69K
<b>Housing material:</b>	Metal
<b>Hints:</b>	External diameter of the long lever 44.8 mm
<b>Switching positions:</b>	




## Wiring diagrams:

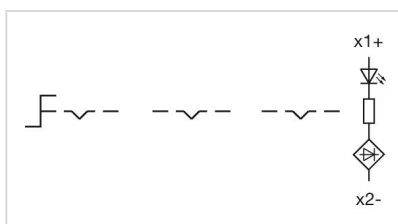







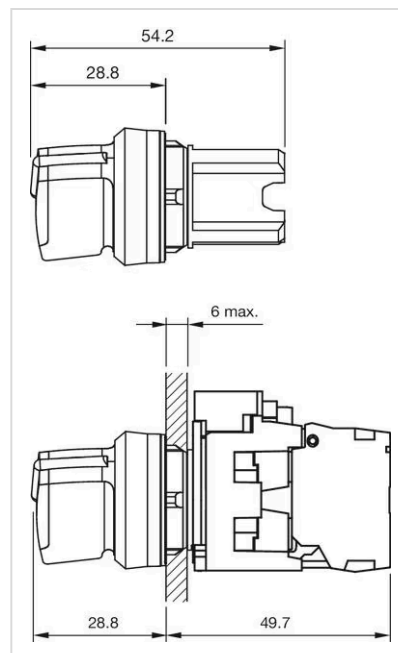



**Mounting cut-outs:**



**Dimension drawings:**



Where to Buy

Distributor		Quantity in Stock		
	Digi-Key	4 in stock	Buy	
	Mouser Electronics	2 in stock	Buy	
	Sager	0 in stock	Buy	
	RS Americas	0 in stock	Buy	
	Newark Electronics	0 in stock	Buy	

Powered by oemsecrets.com

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-2819.2D90.003](#)