

Actuator

45-
290K.1000.116



<https://eao.com/p/45-290K.1000.116>

Your product:



45-290K.1000.116 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front form:	round
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	raised
Mounting cut-out:	Ø 22.3 mm
Mounting type:	Panel mounting

MECHANICAL CHARACTERISTIC

Switching action:	Rest (a) - Momentary
Switching positions:	2 positions
Switching angle:	45° right
Mechanical lifetime:	1 Mio. cycles of operation
Operating frequency:	1 800/h
Weight:	0.054 kg

AMBIENT CONDITION

IP front protection:	IP66, IP67, IP69K
Operating temperature:	- 25 °C ... + 70 °C
Storage temperature:	- 40 °C ... + 80 °C

Shock resistance:

According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms

Vibration resistance:

According to IEC 60068-2-6: 10 ... 500 Hz: 5 g

Climate resistance:

During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

CERTIFICATE**REACH:**

REACH compliant

RoHS:

RoHS compliant

OTHER**Short Description:**


Actuator, Ø 22.3 mm, Ø 29,5 mm, round, Black, Plastic, Rest (a) - Momentary, IP66, IP67, IP69K


Housing material:

Plastic


Hints:

The standard lock: RONIS, T254

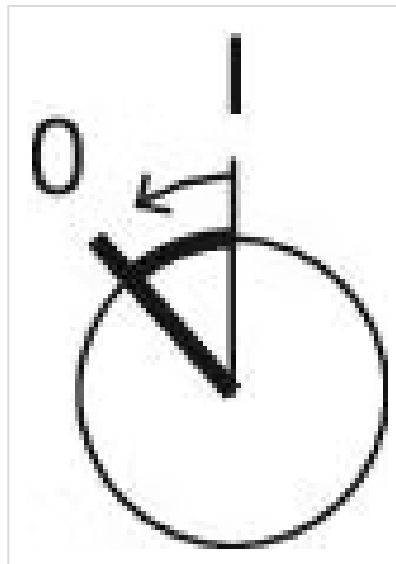Switching positions:**Wiring diagrams:****Mounting cut-outs:**

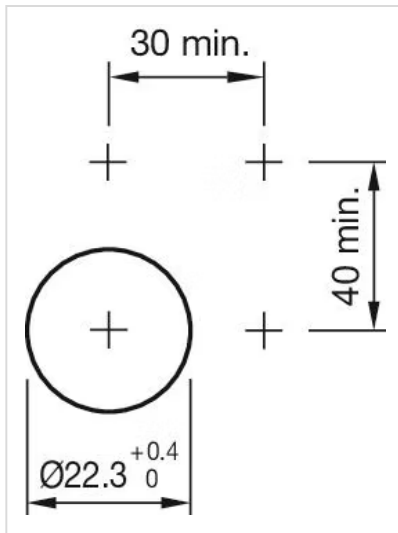

Dimension drawings:

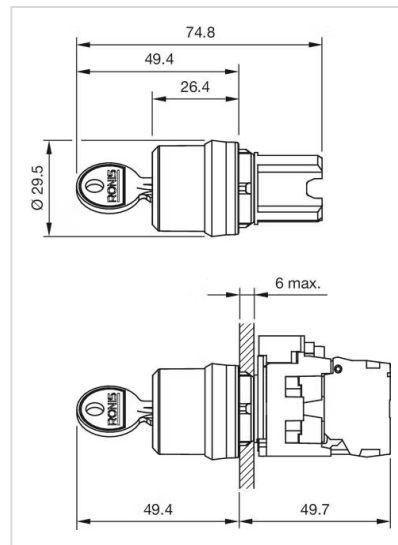

Where to Buy

Distributor		Quantity in Stock		
	Mouser Electronics	3 in stock	Buy	
	Newark Electronics	2 in stock	Buy	
	element14 Singapore	2 in stock	Buy	
	Farnell element14 UK	2 in stock	Buy	
	Digi-Key	0 in stock	Buy	

Show more +

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-290K.1000.116](#)