

# Actuator

45-  
2T00.10J0.000

Distribution by  
Mouser



<https://mouser.eao.com/p/45-2T00.10J0.000>

Your product:

---



## 45-2T00.10J0.000 Actuator

### FRONT

**Front dimension:** Ø 30 mm

**Front form:** round

### MOUNTING

**Design:** raised

**Mounting cut-out:** Ø 22.3 mm

**Mounting type:** Panel mounting

### OPERATING-/INDICATION PART

**Lens cap colour:** Blue

**Lens cap material:** Plastic

**Lens cap shape:** flush

**Lens cap optical effect:** transparent

**Illumination colour:** Blue

### MECHANICAL CHARACTERISTIC

**Weight:** 0.012 kg

### AMBIENT CONDITION

**IP front protection:** IP66, IP67, IP69K

**Operating temperature:** – 25 °C ... + 70 °C

**Storage temperature:** – 40 °C ... + 80 °C


<b>Shock resistance:</b>	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms
<b>Vibration resistance:</b>	According to IEC 60068-2-6: 2 ... 500 Hz: 5 g
<b>Climate resistance:</b>	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

## CERTIFICATE

<b>REACH:</b>	REACH compliant
<b>RoHS:</b>	RoHS compliant

## OTHER


<b>Short Description:</b>	Actuator, Ø 22.3 mm, Ø 30 mm, round, IP66, IP67, IP69K, Blue
<b>Housing material:</b>	Plastic
<b>Wiring diagrams:</b>	

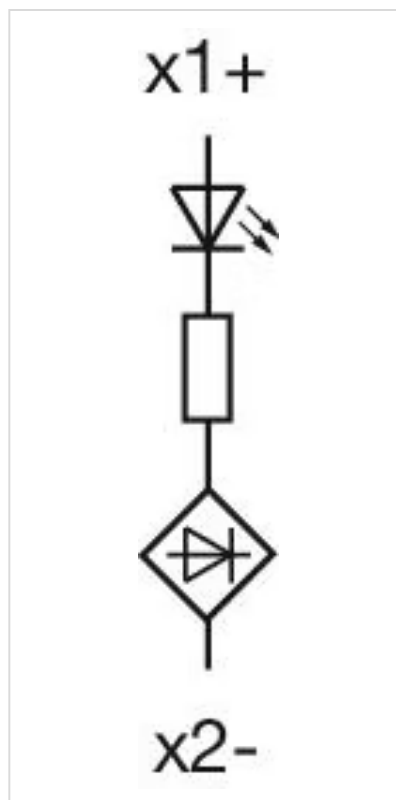

**Mounting cut-outs:**



**Dimension drawings:**

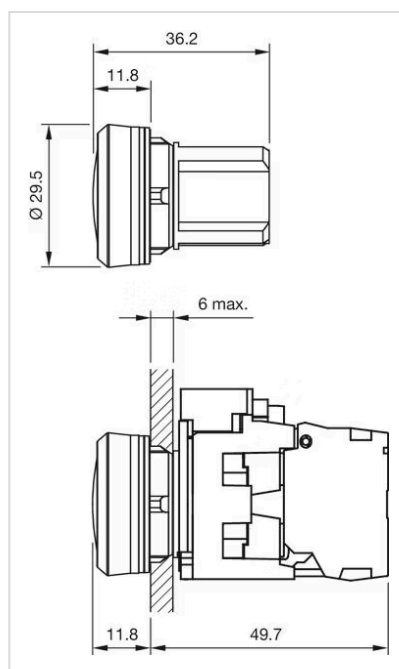

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-2T00.10J0.000](#)