

# Actuator

46-

2134.1110.000



<https://eao.com/p/46-2134.1110.000>

Your product:

---



46-2134.1110.000

Actuator

#### FRONT

**Front dimension:** Ø 29 mm

**Front form:** round

**Front bezel colour:** Black

**Front bezel material:** Plastic

#### MOUNTING

**Design:** raised

**Mounting cut-out:** Ø 22.3 mm

**Mounting type:** Panel mounting

#### OPERATING-/INDICATION PART

**Lens colour:** Black

**Lens material:** Plastic

**Lens illumination:** non illuminative

**Lens shape:** flush

**Lens optics:** opaque

#### ELECTRICAL CHARACTERISTICS

**Protection class:** II

#### MECHANICAL CHARACTERISTIC

**Switching action:** Maintained

|                             |                                  |
|-----------------------------|----------------------------------|
| <b>Mechanical lifetime:</b> | 500 000 cycles of operation      |
| <b>Tightening torque:</b>   | 2 ... 3 Nm (17.7 ... 26.6 Lb-in) |
| <b>Weight:</b>              | 0.019 kg                         |

## AMBIENT CONDITION


|                               |                                                                |
|-------------------------------|----------------------------------------------------------------|
| <b>IP front protection:</b>   | IP65                                                           |
| <b>IK front protection:</b>   | IK03                                                           |
| <b>Operating temperature:</b> | – 25 °C ... + 55 °C                                            |
| <b>Shock resistance:</b>      | 30g, 18ms (EN-IEC 60068-2-27)<br>50g, 11ms (EN-IEC 60068-2-27) |
| <b>Vibration resistance:</b>  | 5g f= 2...500Hz (EN-IEC 60068-2-6)                             |
| <b>Climate resistance:</b>    | +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)                   |

## CERTIFICATE


|                      |                                                    |
|----------------------|----------------------------------------------------|
| <b>Approbations:</b> | CSA, EAC, UL                                       |
| <b>Conformities:</b> | CE                                                 |
| <b>REACH:</b>        | REACH compliant                                    |
| <b>RoHS:</b>         | RoHS compliant                                     |
| <b>Standards:</b>    | CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508 |

## OTHER

|                                           |                                                                                                                              |
|-------------------------------------------|------------------------------------------------------------------------------------------------------------------------------|
| <b>Short Description:</b>                 | Actuator, Ø 22.3 mm, Ø 29 mm, flush, non illuminative, Black, Plastic, opaque, round, Black, Plastic, Maintained, IP65, IK03 |
| <b>Housing colour:</b>                    | Black                                                                                                                        |
| <b>Housing material:</b>                  | Plastic                                                                                                                      |
| <b>max. number of switching elements:</b> | 4                                                                                                                            |
| <b>Mounting cut-outs:</b>                 |                                                                                                                              |

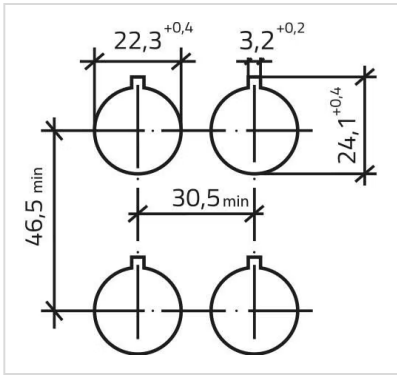

**Dimension drawings:**

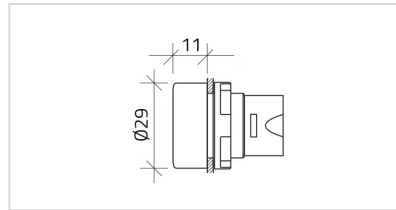

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[46-2134.1110.000](#)