

Actuator

46-

2736.1910.000



<https://eao.com/p/46-2736.1910.000>

Your product:



46-2736.1910.000

Actuator

FRONT

Front dimension: Ø 40 mm

Front form: round

Front bezel colour: Yellow

Front bezel material: Plastic

MOUNTING

Design: raised

Mounting cut-out: Ø 22.3 mm

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens colour: Black

Lens material: Plastic

Lens illumination: non illuminative

Lens shape: mushroom-head

Lens optics: opaque

ELECTRICAL CHARACTERISTICS

Protection class: II

MECHANICAL CHARACTERISTIC

Release type: Twist to unlock

Mechanical lifetime:	50 000 cycles of operation
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Weight:	0.036 kg

AMBIENT CONDITION


IP front protection:	IP65
IK front protection:	IK03
Operating temperature:	– 25 °C ... + 55 °C
Shock resistance:	30g, 18ms (EN-IEC 60068-2-27) 50g, 11ms (EN-IEC 60068-2-27)
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

CERTIFICATE


Approbations:	CSA, EAC, UL
Conformities:	CE
REACH:	REACH compliant
RoHS:	RoHS compliant
Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UL508, UNI EN ISO 12100, UNI EN ISO 13850

OTHER

Short Description:	Actuator, Ø 22.3 mm, Ø 40 mm, mushroom-head, non illuminative, Black, Plastic, opaque, round, Yellow, Plastic, IP65, IK03, Twist to unlock
Dimension:	Ø 40 mm
Housing colour:	Yellow
Housing material:	Plastic
max. number of switching elements:	4
Mounting cut-outs:	

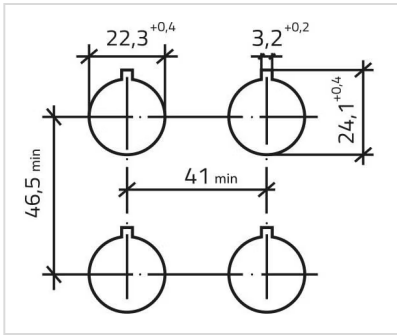

Dimension drawings:

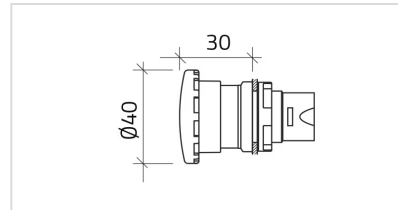

Where to Buy

Distributor		Quantity in Stock		
	Distrelec	19 in stock	Buy	
	Mouser Electronics	15 in stock	Buy	
	DigiKey	5 in stock	Buy	
	element14 Singapore	5 in stock	Buy	
	Newark	5 in stock	Buy	

Show more +

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[46-2736.1910.000](#)