

Actuator

46-

2737.1920.000



<https://eao.com/p/46-2737.1920.000>

Your product:



46-2737.1920.000 Actuator

FRONT

Front dimension: Ø 40 mm

Front form: round

MOUNTING

Design: raised

Mounting cut-out: Ø 22.3 mm

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens colour: Red

Lens material: Plastic

Lens illumination: non illuminative

Lens shape: mushroom-head

Lens optics: opaque

ELECTRICAL CHARACTERISTICS

Protection class: II

MECHANICAL CHARACTERISTIC

Release type: Pull unlock

Mechanical lifetime: 50 000 cycles of operation

Tightening torque: 2 ... 3 Nm (17.7 ... 26.6 Lb-in)

Weight: 0.036 kg

AMBIENT CONDITION

IP front protection: IP65

IK front protection: IK03

Operating temperature: - 25 °C ... + 55 °C

Shock resistance: 30g, 18ms (EN-IEC 60068-2-27)
50g, 11ms (EN-IEC 60068-2-27)

Vibration resistance: 5g f= 2...500Hz (EN-IEC 60068-2-6)

Climate resistance: +25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)

CERTIFICATE

Approbations: CSA, EAC, UL

Conformities: CE

REACH: REACH compliant

RoHS: RoHS compliant

Standards: CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, IEC EN 60947-5-5, UL508, UNI EN ISO 12100, UNI EN ISO 13850

OTHER

Short Description: Actuator, Ø 22.3 mm, Ø 40 mm, mushroom-head, non illuminative, Red, Plastic, opaque, round, IP65, IK03, Pull unlock


Dimension: Ø 40 mm

Housing colour: Yellow


Housing material: Plastic

max. number of switching elements: 4

Mounting cut-outs:

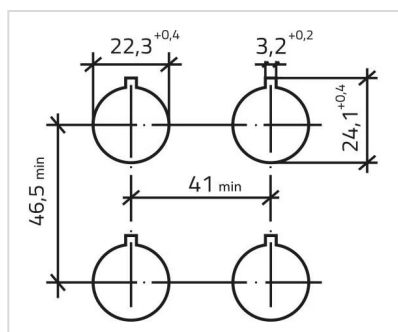

Dimension drawings:

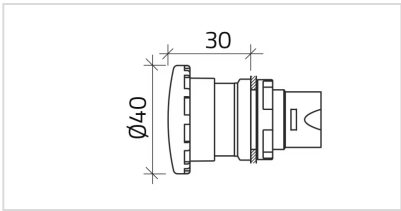

Where to Buy

Distributor		Quantity in Stock		
	Distrelec	20 in stock	Buy	
	Mouser Electronics	14 in stock	Buy	
	DigiKey	5 in stock	Buy	
	TME	5 in stock	Buy	
	Farnell UK	5 in stock	Buy	

Show more +

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[46-2737.1920.000](#)