

Actuator

46-
2W44.1CN0.001



<https://eao.com/p/46-2W44.1CN0.001>

Your product:



46-2W44.1CN0.001 Actuator

FRONT

Front dimension: Ø 30 mm

Front form: round

Front bezel colour: Black

Front bezel material: Plastic

MOUNTING

Design: raised

Mounting cut-out: Ø 22.3 mm

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lever colour: White

Lever bar colour: White

Lever material: plastic

Lever shape: short

ELECTRICAL CHARACTERISTICS

Protection class: II

MECHANICAL CHARACTERISTIC

Switching action: Maintained - Momentary

Switching positions: 2 positions

Switching angle:	90°
Mechanical lifetime:	1 Mio. cycles of operation
Tightening torque:	2 ... 3 Nm (17.7 ... 26.6 Lb-in)
Weight:	0.027 kg


AMBIENT CONDITION

IP front protection:	IP65
IK front protection:	IK03
Operating temperature:	– 25 °C ... + 55 °C
Shock resistance:	30g, 18ms (EN-IEC 60068-2-27)
Vibration resistance:	5g f= 2...500Hz (EN-IEC 60068-2-6)
Climate resistance:	+25°C-97%RH / +45°C-93%RH (IEC-EN60068-2-30)


CERTIFICATE

Conformities:	CE
REACH:	REACH compliant
RoHS:	RoHS compliant
Standards:	CSA C22-2, IEC EN 60947-1, IEC EN 60947-5-1, UL508


OTHER

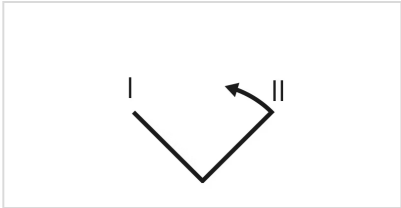Short Description:	Actuator, Ø 22.3 mm, Ø 30 mm, illuminative, White, short, round, Black, Plastic, Maintained - Momentary, IP65, IK03
Housing colour:	Black
Housing material:	Plastic
max. number of switching elements:	2
Switching positions:	

Mounting cut-outs:

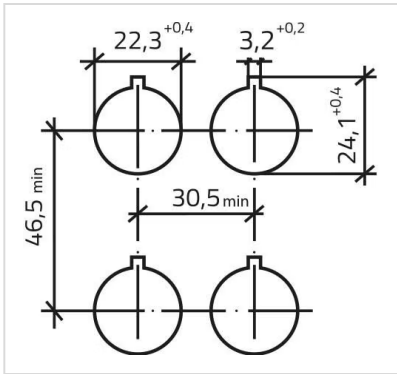

Dimension drawings:

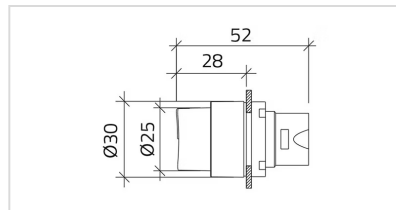

Where to Buy

	Distributor	Quantity in Stock	
	Mouser Electronics	20 in stock	Buy 
	Distrelec	20 in stock	Buy 
	DigiKey	5 in stock	Buy 
	Newark	5 in stock	Buy 
	element14 Singapore	5 in stock	Buy 

[Show more](#) 

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[46-2W44.1CN0.001](#)