

Actuator

61-0009.0



<https://eao.com/p/61-0009.0>

Your product:



61-0009.0 Actuator

MOUNTING

Mounting type: Panel mounting

MECHANICAL CHARACTERISTIC

Tightening torque: Max. 0.5 Nm

Weight: 0.005 kg

AMBIENT CONDITION

IP Protection: IP40 rear side, according to EN IEC 60529, IP67 front side, according to EN IEC 60529

Operating temperature: – 25 °C ... + 55 °C

Storage temperature: – 40 °C ... + 85 °C

CERTIFICATE

REACH: REACH compliant


RoHS: RoHS compliant

OTHER


Short Description: Actuator

Housing material: Plastic, according to UL 94 V0, self-extinguishing

Wiring diagrams:

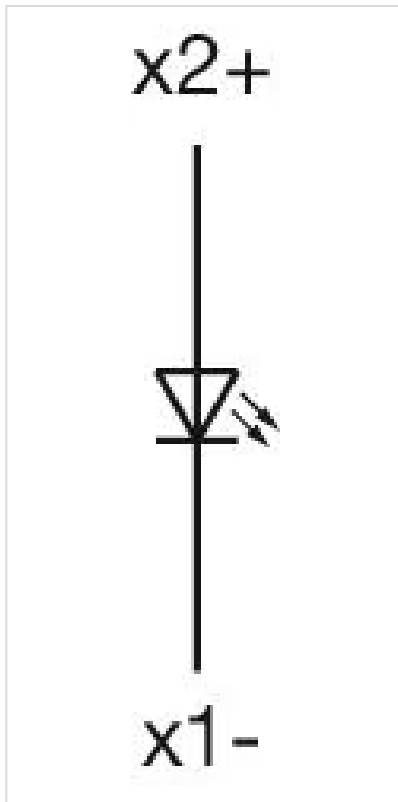


Mounting cut-outs:

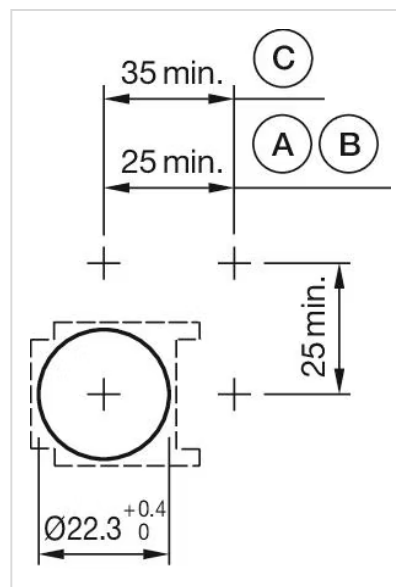


A = Solder/Plug-in terminal 2.8 mm x 0.5 mm
 B = Solder terminal
 C = Screw terminal

Dimension drawings:

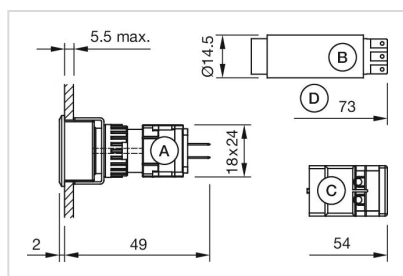

A = Plug-in terminal 2.8 mm x 0.5 mm
 B = Solder terminal
 C = Screw terminal
 D = Flasher

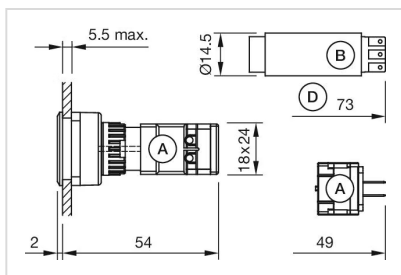

A = Plug-in terminal 2.8 mm x 0.5 mm
 B = Solder terminal
 C = Screw terminal
 D = Flasher

Where to Buy

Distributor		Quantity in Stock	
	Digi-Key	112 in stock	Buy 
	Mouser Electronics	22 in stock	Buy 
	RS Americas	13 in stock	Buy 
	Transfer Multisort Elektronik	8 in stock	Buy 
	Farnell element14 UK	3 in stock	Buy 

[Show more](#) 

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[61-0009.0](#)