


Actuator

61-0029.0

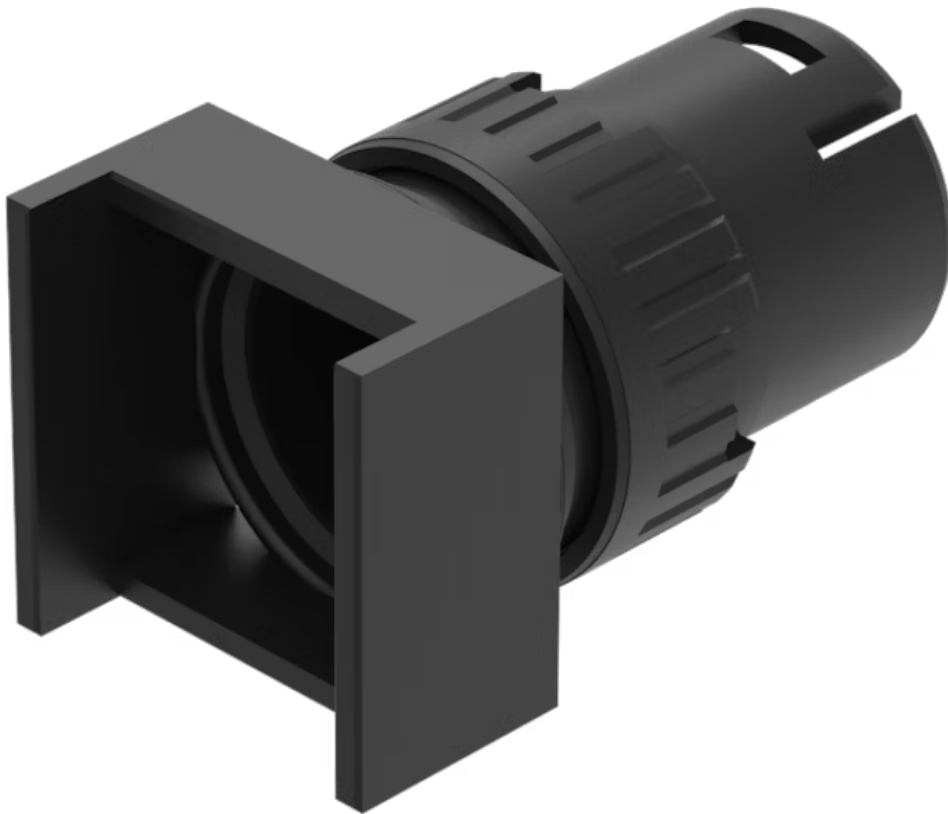

<https://eao.com/p/61-0029.0>

Your product:



61-0029.0 Actuator

FRONT

Front dimension:	18 mm
Front form:	square
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Mounting type:	Panel mounting
----------------	----------------

MECHANICAL CHARACTERISTIC

Tightening torque:	Max. 0.5 Nm
Weight:	0.005 kg

AMBIENT CONDITION


IP Protection:	IP40 rear side, according to EN IEC 60529, IP67 front side, according to EN IEC 60529
Operating temperature:	– 25 °C ... + 55 °C
Storage temperature:	– 40 °C ... + 85 °C

CERTIFICATE


REACH:	REACH compliant
RoHS:	RoHS compliant

OTHER

Short Description:	Actuator, 18 mm, square, Black, Plastic
Dimension:	18 mm x 18 mm
Internal size:	15,3 mm x 15,3 mm
Housing colour:	Black
Housing material:	Plastic, according to UL 94 V0, self-extinguishing
Wiring diagrams:	

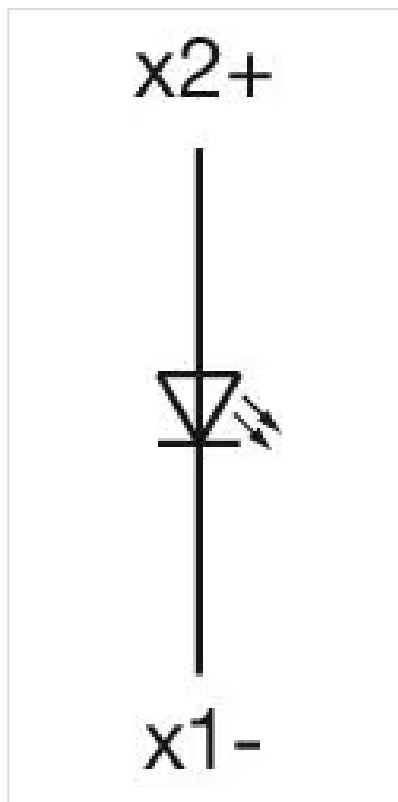


Mounting cut-outs:

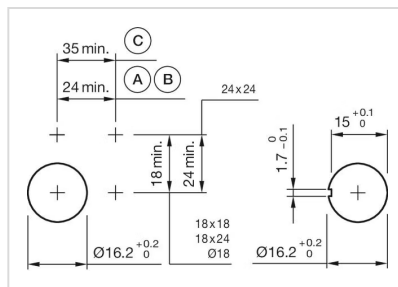

A = Solder/Plug-in terminal 2.8 mm x 0.5 mm
 B = Solder terminal
 C = Screw terminal

Dimension drawings:

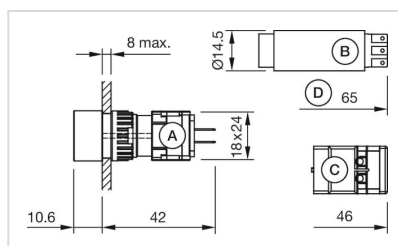

A = Plug-in terminal 2.8 mm x 0.5 mm
 B = Solder terminal
 C = Screw terminal
 D = Flasher
 E = Slow-make switching element
 F = Snap-action switching element

Where to Buy

	Distributor	Quantity in Stock	
	Mouser Electronics	24 in stock	Buy 
	Digi-Key	1 in stock	Buy 
	Sager	0 in stock	Buy 
	RS Americas	0 in stock	Buy 
	Newark Electronics	0 in stock	Buy 

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[61-0029.0](#)