


Actuator

704.064.2A

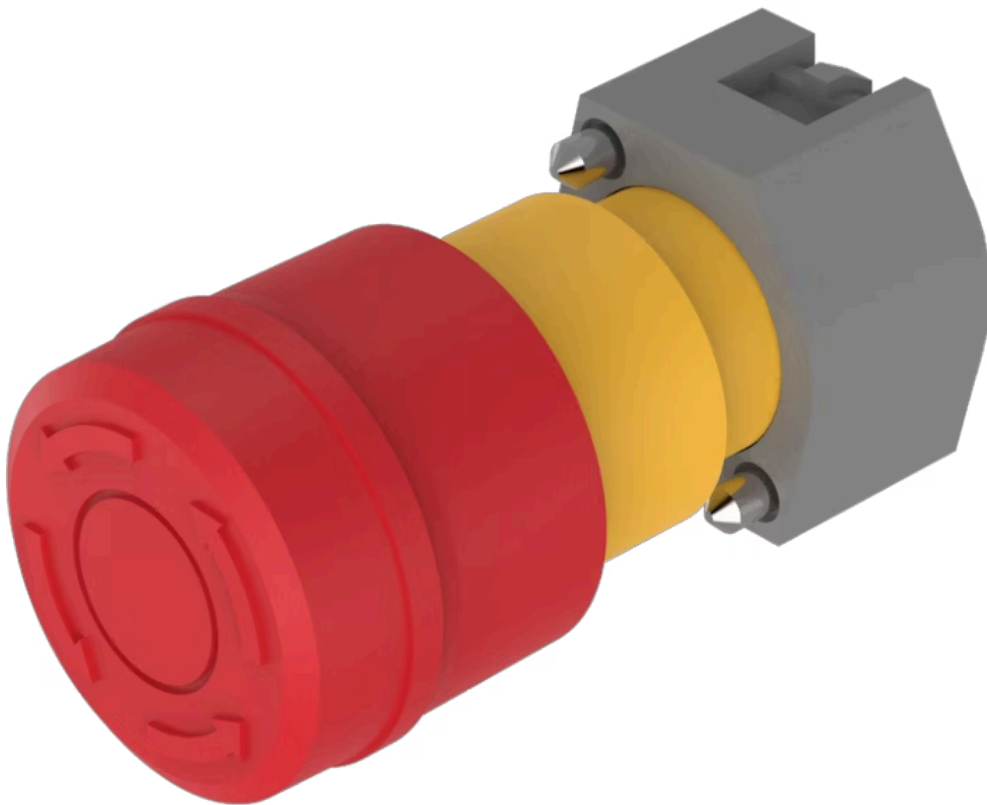

<https://eao.com/p/704.064.2A>

Your product:



704.064.2A Actuator

FRONT

Front dimension: Ø 37 mm

Front form: round

MOUNTING

Design: raised

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens colour: Red

Lens material: Plastic

Lens illumination: non illuminative

Lens shape: mushroom-head

Lens optics: opaque

MECHANICAL CHARACTERISTIC

Switching action: Maintained

Release type: Twist to unlock

Mechanical lifetime: ≥50 000 cycles of operation

Operating force: 8 N

Operating Travel: ca. 5.8 mm ± 0.2 mm

Weight: 0.03 kg

AMBIENT CONDITION

Operating temperature: – 25 °C ... + 55 °C

Storage temperature: – 40 °C ... + 85 °C

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant

OTHER

Short Description: Actuator, Ø 37 mm, mushroom-head, non illuminative, Red, Plastic, opaque, round, Maintained, Twist to unlock

Housing colour: Yellow

Housing material: Plastic


Marking: Arrows

Hints: Shaft yellow


Wiring diagrams:



Mounting cut-outs:

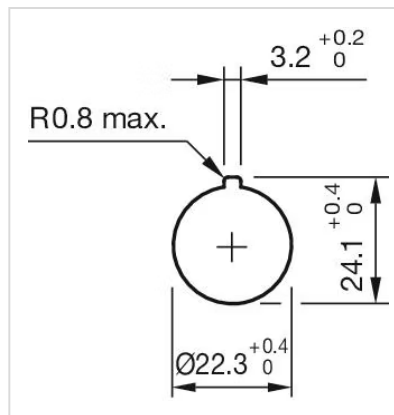



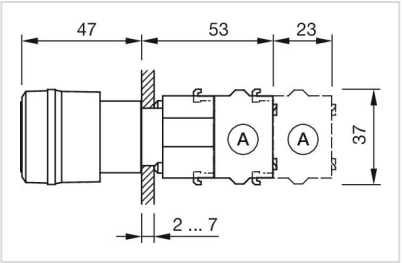







Dimension drawings:



A = Screw terminal

Where to Buy

Distributor		Quantity in Stock		
	Digi-Key	16 in stock	Buy	
	RS UK	9 in stock	Buy	
	Rapid Electronics	7 in stock	Buy	
	Mouser Electronics	6 in stock	Buy	
	RS Americas	5 in stock	Buy	

Show more +

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[704.064.2A](#)