

Actuator

704.633.1



<https://eao.com/p/704.633.1>

Your product:



704.633.1 Actuator

MOUNTING

Mounting type: Panel mounting

ELECTRICAL CHARACTERISTICS

Standards: The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

MECHANICAL CHARACTERISTIC

Weight: 0.009 kg

AMBIENT CONDITION

IP Protection: IP65 front side

Operating temperature: – 40 °C ... + 55 °C

Storage temperature: – 40 °C ... + 85 °C

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant


OTHER

Short Description: Actuator


Housing colour: Grey

Housing material: Plastic


Wiring diagrams:

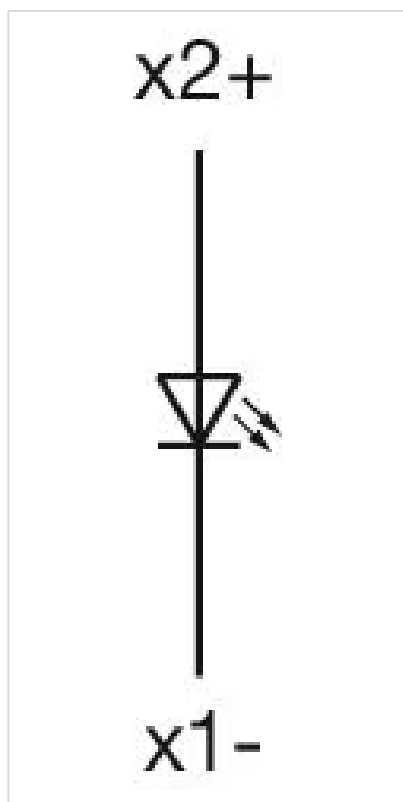


Mounting cut-outs:

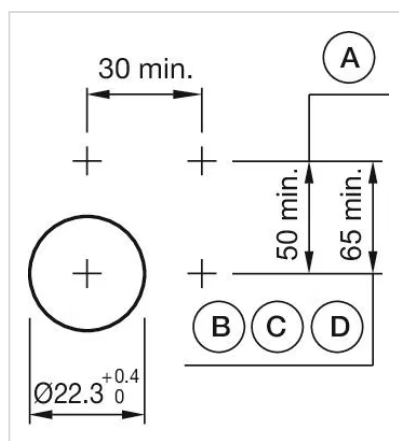


A = Screw terminal
 B = Push-in terminal (PIT)
 C = Plug-in terminal 6.3 mm x 0.8 mm
 D = Double plug-in terminal 6.3 mm x 0.8 mm

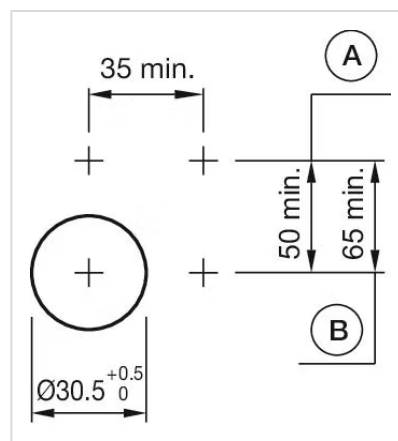

A = Screw terminal
 B = Push-in terminal (PIT)

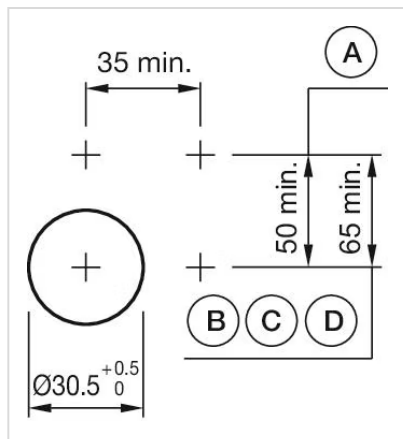


A = Screw terminal
 B = Push-in terminal (PIT)
 C = Plug-in terminal 6.3 mm x 0.8 mm
 D = Double plug-in terminal 6.3 mm x 0.8 mm

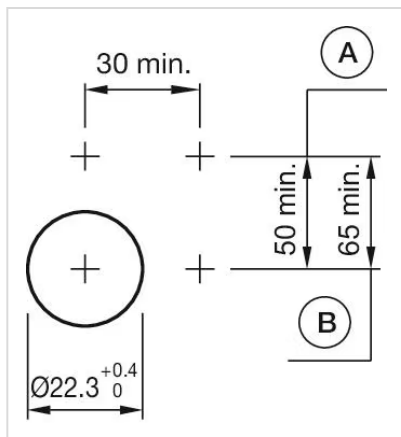


A = Screw terminal
 B = Push-in terminal (PIT)


Dimension drawings:

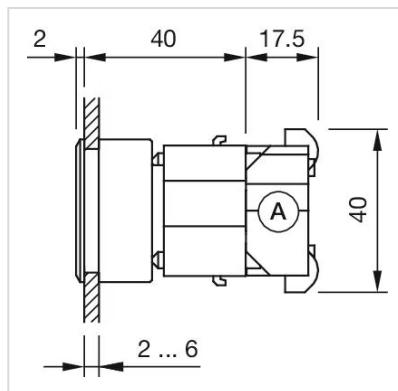


A = Screw terminal

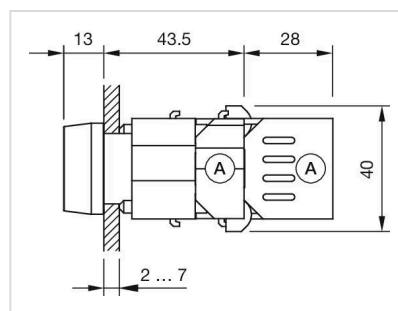

X = Screw terminal

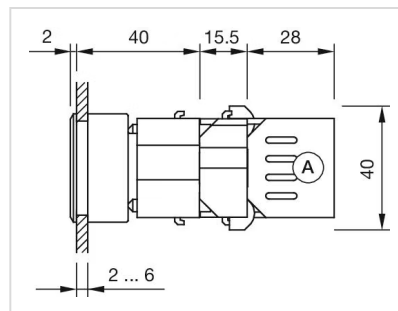

A = Screw terminal

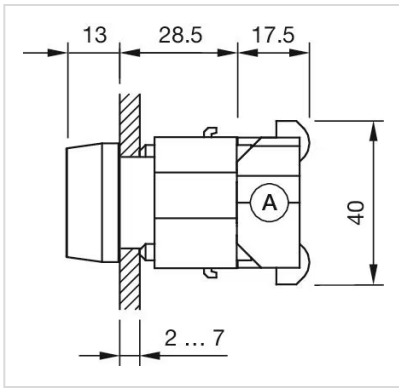

A = Screw terminal

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[EUS-704.633.1/634](#) [EUS-704.633.1/1109](#) [EUS-704.633.1/584](#) [EUS-704.633.1/614](#) [EUS-704.633.1/1110](#) [EUS-704.633.1/1486](#) [EUS-704.633.1/1106](#) [EUS-704.633.1/784](#) [EUS-704.633.1/1027](#)