

Actuator

704.642.2



<https://eao.com/p/704.642.2>

Your product:



704.642.2 Actuator

FRONT

Front dimension: Ø 29 mm

Front form: round

MOUNTING

Design: raised

Mounting type: Panel mounting

ELECTRICAL CHARACTERISTICS

Standards: The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

MECHANICAL CHARACTERISTIC

Weight: 0.009 kg

AMBIENT CONDITION

IP Protection: IP65 front side

Operating temperature: – 40 °C ... + 55 °C

Storage temperature: – 40 °C ... + 85 °C

CERTIFICATE

REACH: REACH compliant

RoHS: RoHS compliant


OTHER

Short Description: Actuator, Ø 29 mm, round


Housing colour: Grey

Housing material: Plastic


Wiring diagrams:

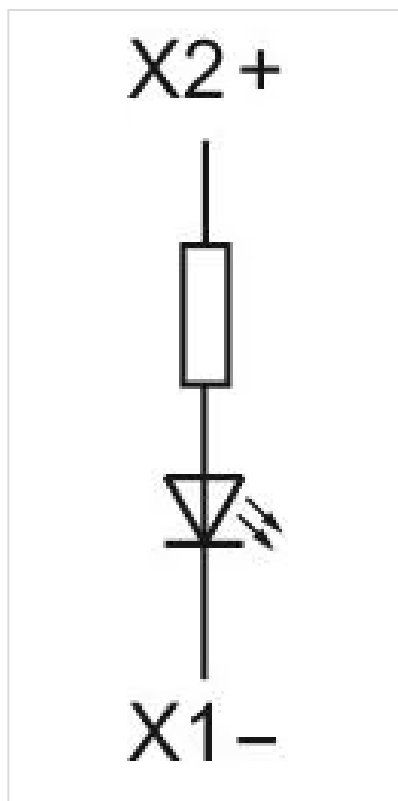



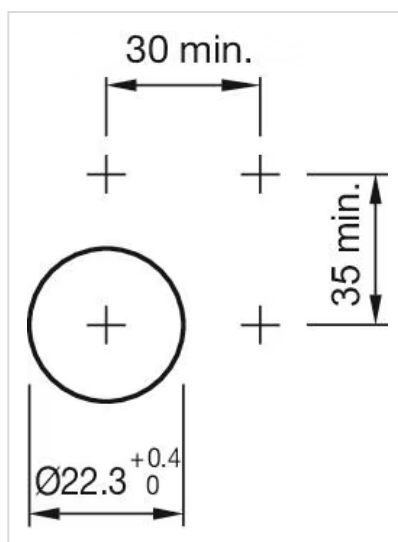



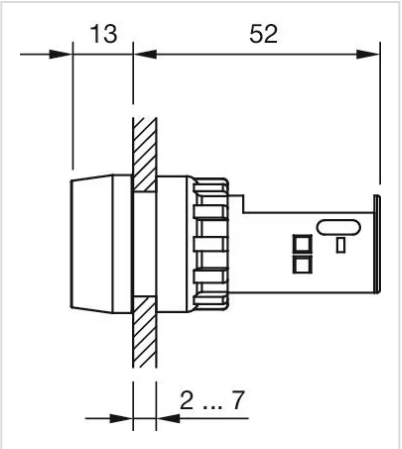



Mounting cut-outs:



Dimension drawings:



Where to Buy

Distributor		Quantity in Stock	
	Digi-Key	10 in stock	<div>Buy</div>
	Mouser Electronics	0 in stock	<div>Buy</div>
	RS Americas	0 in stock	<div>Buy</div>
	Newark Electronics	0 in stock	<div>Buy</div>
	Sager	0 in stock	<div>Buy</div>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[704.642.2](#)