


# Actuator


704.732.1

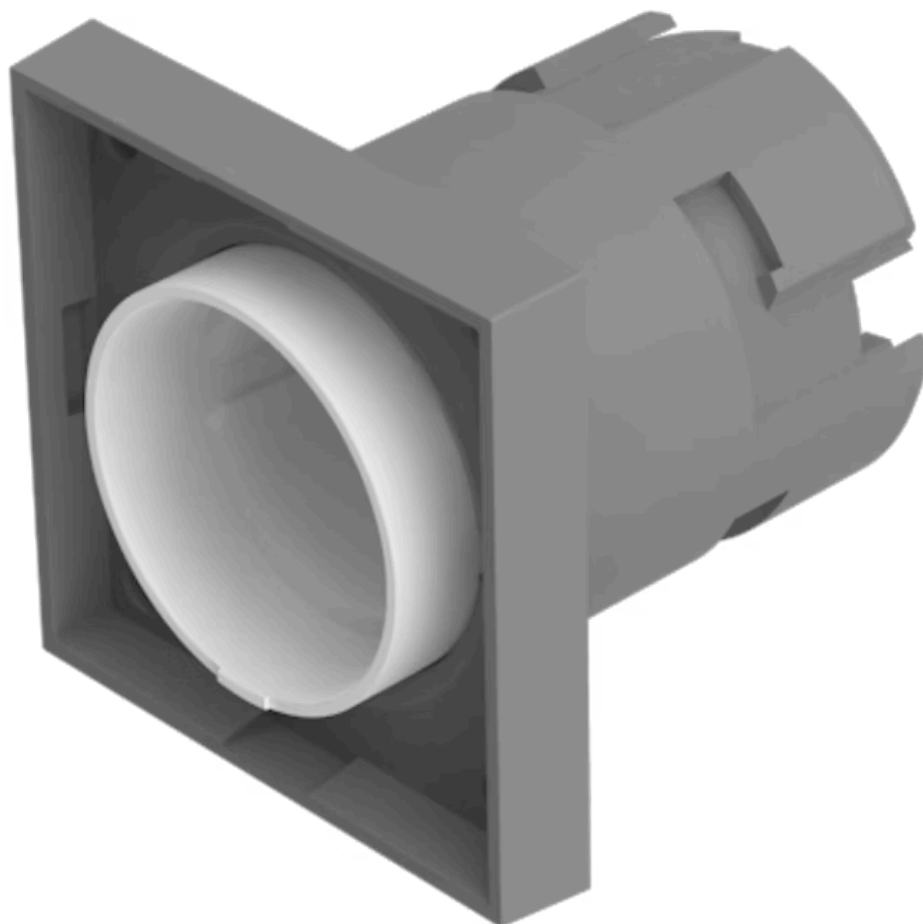

<https://eao.com/p/704.732.1>

Your product:

---

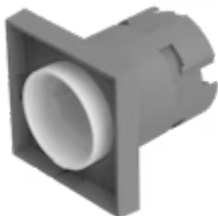

## 704.732.1 Actuator

### FRONT

**Front dimension:** 30 mm x 30 mm

**Front form:** square

### MOUNTING

**Design:** raised

**Mounting type:** Panel mounting

### OPERATING-/INDICATION PART

**Lens illumination:** illuminative

### ELECTRICAL CHARACTERISTICS

**Standards:** The switches comply with the "Standards for low-voltage switching devices" DIN EN 60947-1

### MECHANICAL CHARACTERISTIC

**Switching action:** Maintained

**Mechanical lifetime:** ≤3 Mio. cycles of operation

**Operating force:** 8 N

**Operating Travel:** ca. 5.8 mm ± 0.2 mm

**Weight:** 0.009 kg

### AMBIENT CONDITION

**IP Protection:** IP65 front side

**Operating temperature:** – 40 °C ... + 55 °C

**Storage temperature:** – 40 °C ... + 85 °C

## CERTIFICATE

**REACH:** REACH compliant

**RoHS:** RoHS compliant

## OTHER

**Short Description:** Actuator, 30 mm x 30 mm, illuminative, square, Maintained


**Housing colour:** Grey

**Housing material:** Plastic


**Hints:** Max. 3 switching elements can be clipped on

**max. number of switching elements:** 3

**Wiring diagrams:**

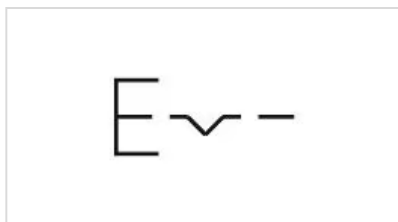


**Mounting cut-outs:**

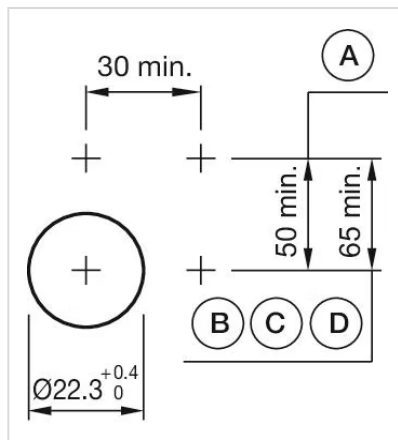


A = Screw terminal  
B = Push-in terminal (PIT)  
C = Plug-in terminal 6.3 mm x 0.8 mm  
D = Double plug-in terminal 6.3 mm x 0.8 mm

**Dimension drawings:**

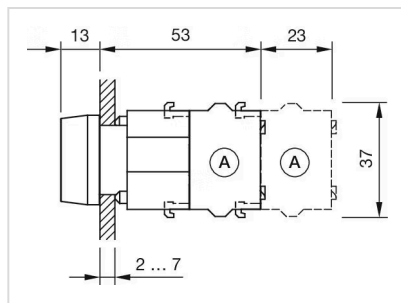



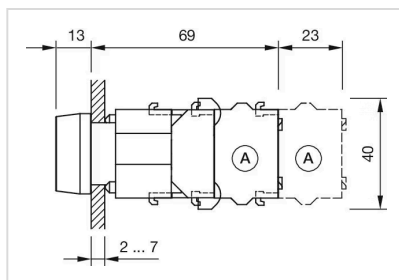







A = Screw terminal



A = Screw terminal

## Where to Buy

Distributor		Quantity in Stock		
	DigiKey	22 in stock	Buy	
	Mouser Electronics	3 in stock	Buy	
	RS Americas	2 in stock	Buy	
	Sager	0 in stock	Buy	
	Newark	0 in stock	Buy	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[704.732.1](#)