

Actuator

84-0100.0



<https://eao.com/p/84-0100.0>

Your product:



84-0100.0 Actuator

FRONT

Front dimension:	Ø 25 mm
Front form:	round
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	flush
Mounting cut-out:	Ø 22.5 mm
Mounting type:	Panel mounting

MECHANICAL CHARACTERISTIC

Tightening torque:	Fixing nut 0.8 Nm
Weight:	0.003 kg


AMBIENT CONDITION

IP front protection:	IP67
IP Protection:	IP67
Operating temperature:	– 25 °C ... + 70 °C
Storage temperature:	– 40 °C ... + 85 °C
Climate resistance:	Damp heat, cyclic: 96 hours, + 25 °C/97 %, + 55 °C/93 % relative humidity, as per EN IEC 60068-2-30 Damp heat, steady: 56 days, + 40 °C/93 % relative humidity, according to EN IEC 60068-2-78 Rapid change of temperature: 100 cycles, – 40 °C ... + 80 °C, as per EN / IEC 60068-2-14


CERTIFICATE

Approbations:	EBC (TSI PRM), NFF
Conformities:	CE, UKCA, 2011 / 65 / EC (RoHS)
REACH:	REACH compliant
RoHS:	RoHS compliant


OTHER

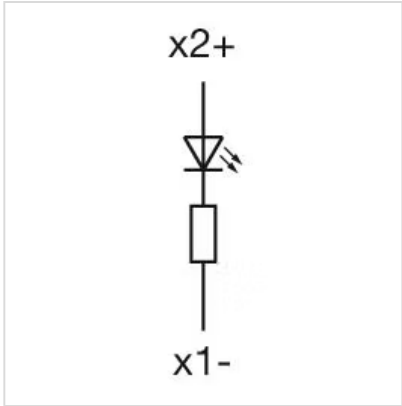Short Description:	Actuator, Ø 22.5 mm, Ø 25 mm, round, Black, Plastic, IP67
Hints:	Illuminated lens, non-illuminated bezel
Wiring diagrams:	


Mounting cut-outs:

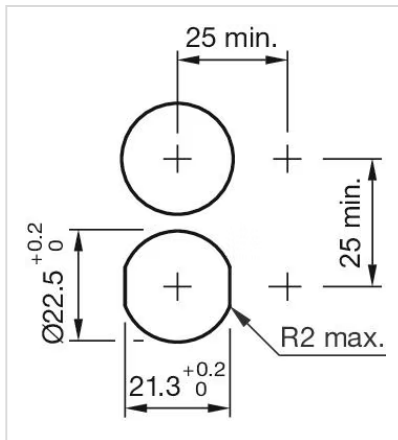

Dimension drawings:

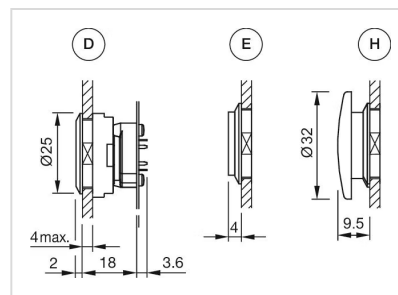

A = Lens level with bezel
 E = Lens raised above bezel
 H = Mushroom-head cap

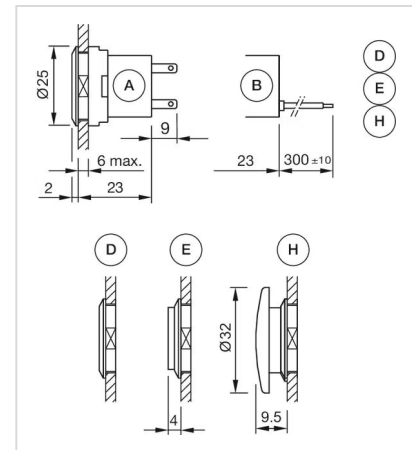

A = Plug-in terminal 2.8 mm x 0.8 mm
 B = Flat ribbon cable
 D = Lens level with bezel
 E = Lens raised above bezel
 H = Mushroom-head cap

Where to Buy

Distributor		Quantity in Stock	
	RS UK	104 in stock	Buy 
	Distrelec	21 in stock	Buy 
	Mouser Electronics	20 in stock	Buy 
	DigiKey	12 in stock	Buy 
	element14 Singapore	6 in stock	Buy 

Show more 

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[84-0100.0](#)