

Actuator

84-0200.7



<https://eao.com/p/84-0200.7>

Your product:



84-0200.7 Actuator

FRONT

Front dimension:	Ø 25 mm
Front form:	round
Front bezel colour:	Nature
Front bezel material:	Aluminium

MOUNTING

Design:	flush
Mounting cut-out:	Ø 22.5 mm
Mounting type:	Panel mounting

MECHANICAL CHARACTERISTIC

Tightening torque:	Fixing nut 0.8 Nm
Weight:	0.008 kg


AMBIENT CONDITION

IP front protection:	IP67
IP Protection:	IP67
Operating temperature:	– 25 °C ... + 70 °C
Storage temperature:	– 40 °C ... + 85 °C
Climate resistance:	Damp heat, cyclic: 96 hours, + 25 °C/97 %, + 55 °C/93 % relative humidity, as per EN IEC 60068-2-30 Damp heat, steady: 56 days, + 40 °C/93 % relative humidity, according to EN IEC 60068-2-78 Rapid change of temperature: 100 cycles, – 40 °C ... + 80 °C, as per EN / IEC 60068-2-14


CERTIFICATE

Approbations:	EBC (TSI PRM), NFF
Conformities:	CE, UKCA, 2011 / 65 / EC (RoHS)
REACH:	REACH compliant
RoHS:	RoHS compliant


OTHER

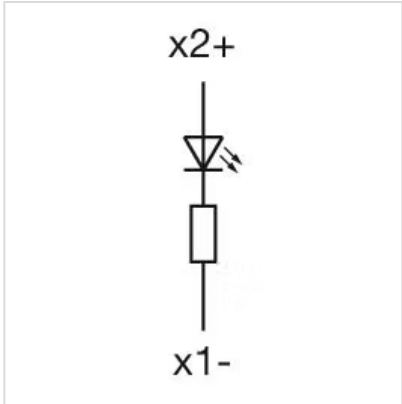Short Description:	Actuator, Ø 22.5 mm, Ø 25 mm, round, Nature, Aluminium, anodised, IP67
Hints:	Illuminated lens, non-illuminated bezel
Wiring diagrams:	


Mounting cut-outs:

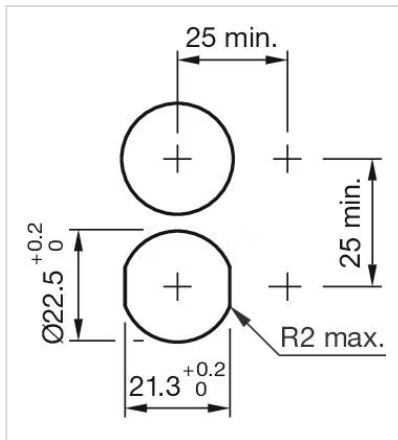

Dimension drawings:

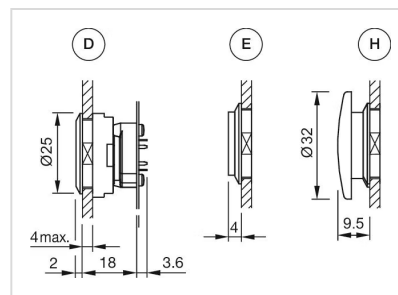

A = Lens level with bezel
 E = Lens raised above bezel
 H = Mushroom-head cap

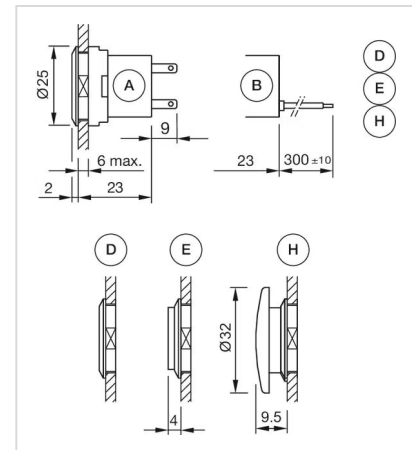

A = Plug-in terminal 2.8 mm x 0.8 mm
 B = Flat ribbon cable
 D = Lens level with bezel
 E = Lens raised above bezel
 H = Mushroom-head cap

Where to Buy

	Distributor	Quantity in Stock	
	RS UK	152 in stock	Buy 
	RS Americas	72 in stock	Buy 
	Mouser Electronics	43 in stock	Buy 
	DigiKey	28 in stock	Buy 
	TME	3 in stock	Buy 

Show more 

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[84-0200.7](#)