

IO-Link Touch Hygiene

84-ACKS-C14-04C2



<https://eao.com/p/84-ACKS-C14-04C2>

Your product:



84-ACKS-C14-04C2 IO-Link Touch Hygiene

FRONT

Front dimension:	Ø 30 mm
Front form:	round
Front bezel material:	Plastic

MOUNTING

Design:	flush
Mounting cut-out:	Ø 22.5 mm
Mounting type:	Panel mounting

OPERATING-/INDICATION PART

Lens material:	Plastic
Lens illumination:	illuminative
Lens shape:	flush
Lens optics:	transparent
Symbol:	Standby (C14)

ELECTRICAL CHARACTERISTICS

Operating voltage:	8,4 - 32 V DC
--------------------	---------------

MECHANICAL CHARACTERISTIC

Terminal:	Connector M12
Switching system:	Capacitive

Operating force: No actuating force necessary

Weight: 0.015 kg

AMBIENT CONDITION

IP front protection: IP69K

IK front protection: IK08

Operating temperature: – 30 °C ... + 65 °C

Climate resistance: Relative humidity, max. 95%, non-condensing

CERTIFICATE

Approbations: CSA, EHEDG

Conformities: CE, UKCA

REACH: REACH compliant

RoHS: RoHS compliant




OTHER

Short Description: IO-Link Touch Hygiene, Ø 22.5 mm, Ø 30 mm, flush, illuminative, Plastic, transparent, round, Plastic, Connector M12, IP69K, IK08, Standby (C14)




Housing colour: Black

Housing material: Plastic


Wiring diagrams:

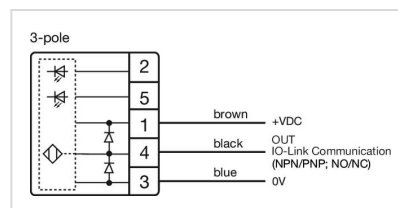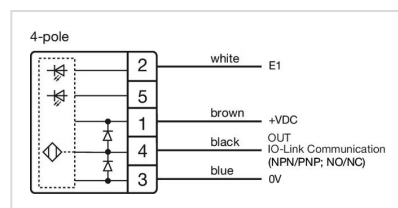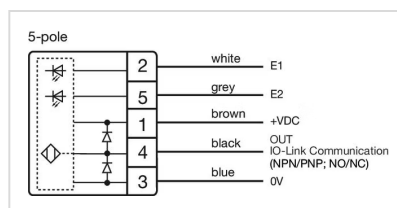


Component layouts:

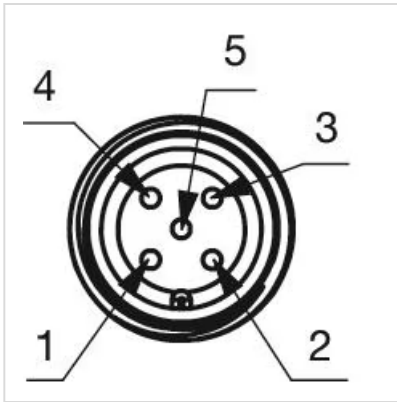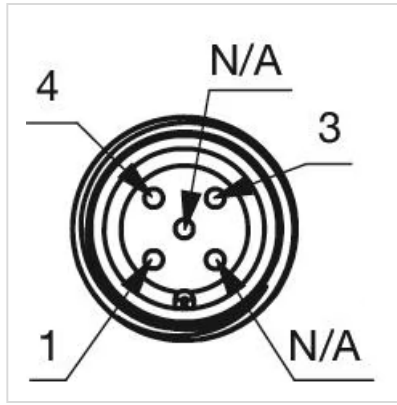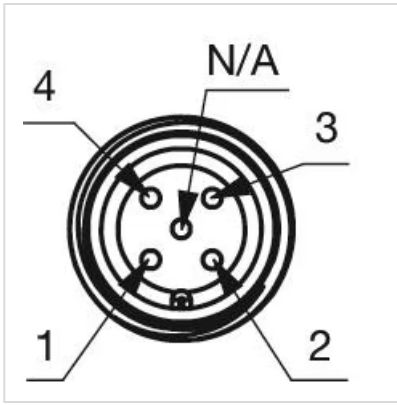

Mounting cut-outs:

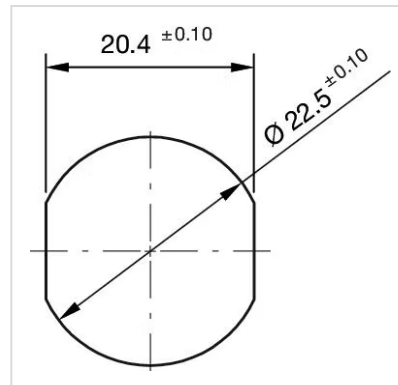

Dimension drawings:

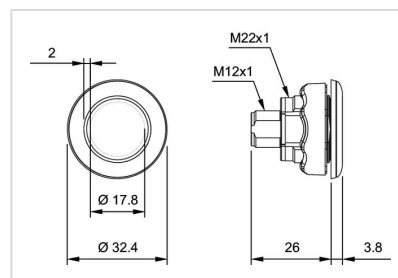

Where to Buy

Distributor		Quantity in Stock		
	DigiKey	10 in stock	Buy	
	Newark	10 in stock	Buy	
	element14 Singapore	10 in stock	Buy	
	Farnell UK	10 in stock	Buy	
	Mouser Electronics	0 in stock	Buy	

Show more +

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[84-ACKS-C14-04C2](#)