

## Illuminated pushbutton Ø 22 mm silver contact

82-6552.1124



<https://eao.com/p/82-6552.1124>

Your product:

---



82-6552.1124

Illuminated pushbutton Ø  
22 mm silver contact

#### FRONT

**Front dimension:** Ø 25 mm

**Front form:** round

**Front bezel material:** Aluminium

**Front bezel shape:** flush

#### MOUNTING

**Mounting cut-out:** Ø 22 mm

**Mounting type:** Panel mounting

#### OPERATING-/INDICATION PART

**Lens colour:** Nature

**Lens material:** Aluminium

**Lens illumination:** illuminative

**Lens shape:** flush

**Lens optics:** opaque

**Illumination colour:** Blue

**Shape of illumination:** Ring

#### ELECTRICAL CHARACTERISTICS

**Contacts:** 1 C

**Operating voltage:** 24 V AC/DC

**Operation current:** 7 mA

<b>Switching voltage and switching current:</b>	according to IEC 60947-5-1 (Silver contacts)	
	Service categorie AC-15	
	Voltage	Current
	24 VAC	1 A
	35 VAC	1 A (M12 versio
	110 VAC	1 A
	220 VAC	0.5 A
	Switch rating DC service categorie DC-13 (Silver contacts)	
	Voltage	Current
	24 VDC	0.7 A
	35 VDC	0.5 A (M12 vers
	110 VDC	0.2 A
	220 VDC	0.1 A

	according to UL 508 (Silver contacts)	
	$\cos\phi$ 0,75 ... 0,8	
	Voltage	Current
	120 VAC	5 A
	240 VAC	3 A
	24 VAC	1 A

<b>Rated Operational Voltage Ue:</b>	250 VAC
<b>Rated insulation voltage Ui:</b>	250 V
<b>Electrical lifetime:</b>	50 000 cycles of operation
<b>Electric strength:</b>	1500 VAC, 50 Hz 1 minute between life terminals and ground
<b>Pollution degree:</b>	2, according to EN IEC 60947-1
<b>Thermal current Ith:</b>	5 A

## MECHANICAL CHARACTERISTIC

<b>Terminal:</b>	Screw terminal
<b>Contact material:</b>	Silver
<b>Switching action:</b>	Momentary
<b>Switching system:</b>	Snap-action switching element
<b>Operating force:</b>	4 N ... 7 N
<b>Operating Travel:</b>	ca. 3 mm
<b>Tightening torque:</b>	0.5 ... 0.6 Nm
<b>Weight:</b>	0.018 kg

## AMBIENT CONDITION

<b>IP front protection:</b>	IP65, IP67
<b>Operating temperature:</b>	– 30 °C ... + 70 °C
<b>Storage temperature:</b>	– 40 °C ... + 80 °C
<b>Shock resistance:</b>	

Max. 500 m / s<sup>2</sup> as per IEC 60068-2-27

**Vibration resistance:** 10 ... 500 Hz, amplitude 1.5 mm p-p according to IEC 60068-2-6

**Climate resistance:** Damp heat, 21 days according to IEC 60512-11

## CERTIFICATE

**Approbations:** CB, CCC, C UL, UL

**Conformities:** CE, 2011 / 65 / EC (RoHS), 2014 / 35 / EU (LVD)

**REACH:** REACH compliant


**RoHS:** RoHS compliant

## OTHER


**Short Description:** Illuminated pushbutton Ø 22 mm silver contact, Momentary, 24 V AC/DC, 1 C, Screw terminal, round, Aluminium, Blue, Nature

**Kind of illumination:** Single-LED


**Wiring diagrams:**

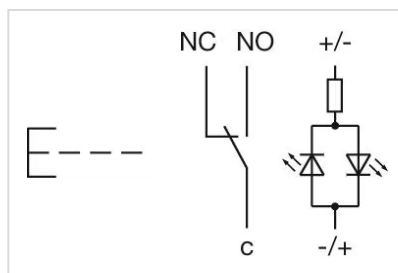


**Component layouts:**

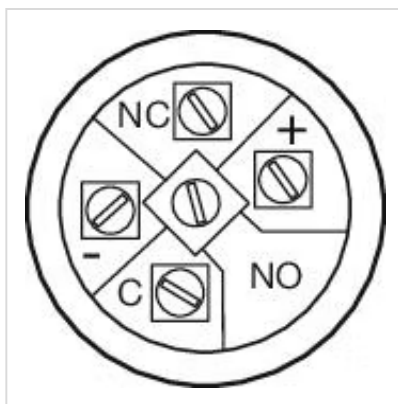

**Mounting cut-outs:**

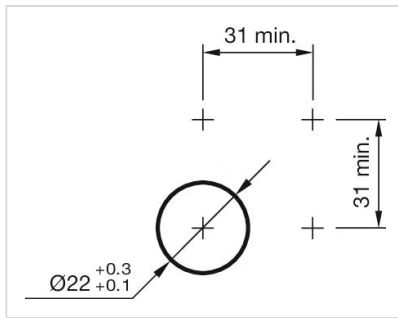



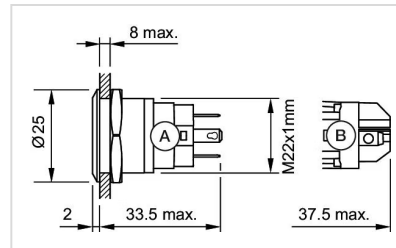







# **Dimension drawings:**



A = Solder terminal  
B = Screw terminal

Where to Buy

Distributor		Quantity in Stock		
	DigiKey	3 in stock	Buy	
	RS UK	2 in stock	Buy	
	Farnell UK	1 in stock	Buy	
	Newark	1 in stock	Buy	
	element14 Singapore	1 in stock	Buy	

Show more +

Powered by oemsecrets.com

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[82-6552.1124](#)