

Filament lamp

10-1214.1249



<https://eao.com/p/10-1214.1249>

Your product:



10-1214.1249 Filament lamp

OPERATING-/INDICATION PART

Illumination colour: White

ELECTRICAL CHARACTERISTICS

Operating voltage: 30 V AC/DC

Operation current: 40 mA $\pm$ 10 %

Lumi. Intensity: mcd

MECHANICAL CHARACTERISTIC

Weight: 0.002 kg

CERTIFICATE


REACH: REACH compliant

RoHS: RoHS compliant

OTHER

Short Description: Filament lamp, T6.9, White, 30 V AC/DC

Wiring diagrams:

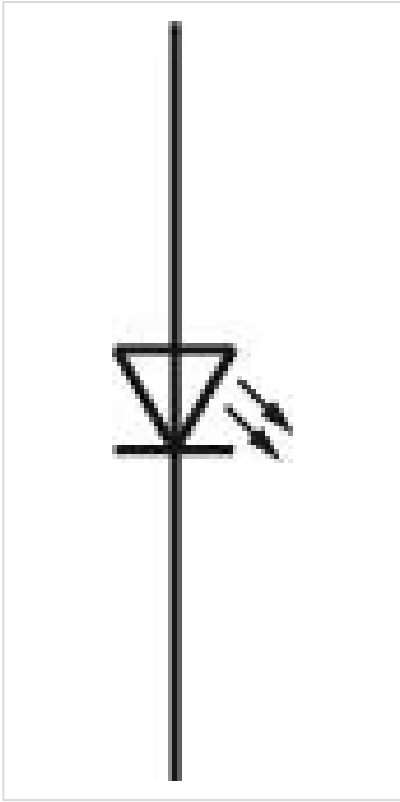

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[10-1214.1249](#)