

LED

46-
39J.0987



<https://eao.com/p/46-39J.0987>

Your product:



46-39J.0987
LED

OPERATING-/INDICATION PART

Lens illumination: illuminative

Illumination colour: White

ELECTRICAL CHARACTERISTICS

Operating voltage: 130 AC/DC -20% / +10%

Electrical lifetime: 50 000 h

MECHANICAL CHARACTERISTIC

Weight: 0.002 kg

AMBIENT CONDITION

Operating temperature: – 25 °C ... + 55 °C

CERTIFICATE

Conformities: CE

REACH: REACH compliant

RoHS: RoHS compliant


Standards: EN 55015, EN 61000-3-2, EN 61000-3-3, EN 61547, IEC EN 62471

OTHER







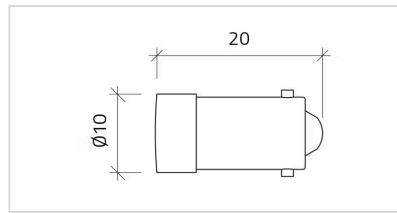



Short Description: LED, White, 130 AC/DC -20% / +10%

Kind of illumination: Multi-LED EN 50155

Dimension drawings:



Where to Buy

Distributor		Quantity in Stock		
	Mouser Electronics	35 in stock	Buy	
	Distrelec	10 in stock	Buy	
	DigiKey	5 in stock	Buy	
	Sager	5 in stock	Buy	
	Newark	5 in stock	Buy	

Show more +

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[46-39J.0987](#)