


Illumination element

45-320.1E12

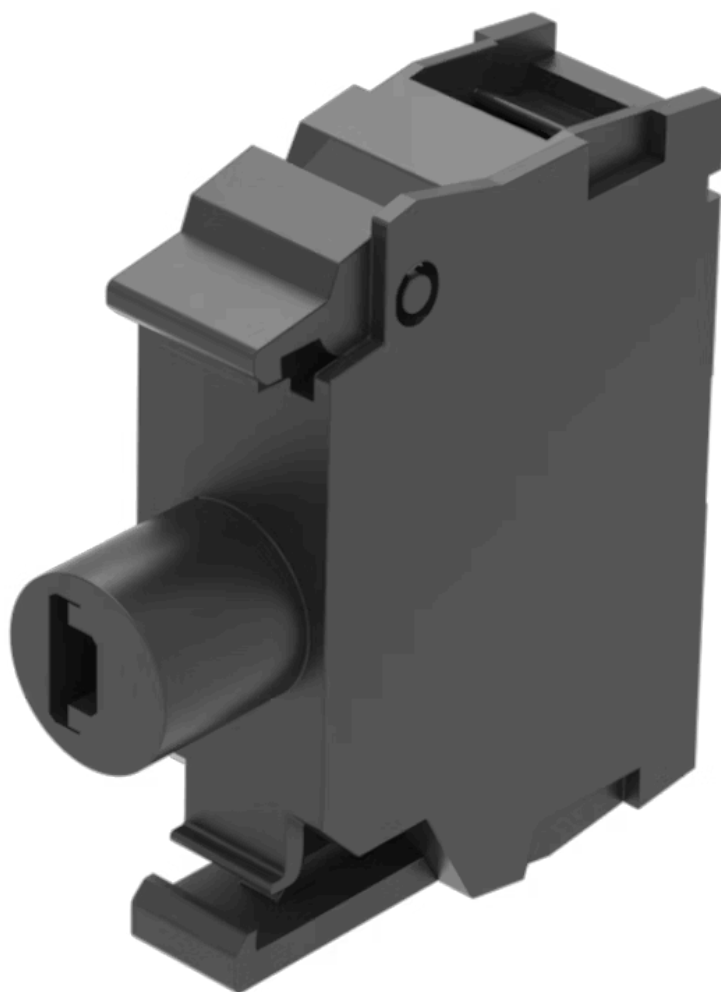

<https://eao.com/p/45-320.1E12>

Your product:



45-320.1E12

Illumination element

MOUNTING

Component mounting type: Front mounting

OPERATING-/INDICATION PART

Illumination colour: Red

ELECTRICAL CHARACTERISTICS

Operating voltage: 24 - 240 V AC/DC

Surge voltage resistance: 4 kV

Lumi. Intensity: 450 - 1120 mcd

MECHANICAL CHARACTERISTIC

Terminal: Screw terminal

Weight: 0.011 kg

CERTIFICATE


REACH: REACH compliant

RoHS: RoHS compliant


OTHER

Short Description: Illumination element, Screw terminal, Red, 24 - 240 V AC/DC, Front mounting

Wiring diagrams:

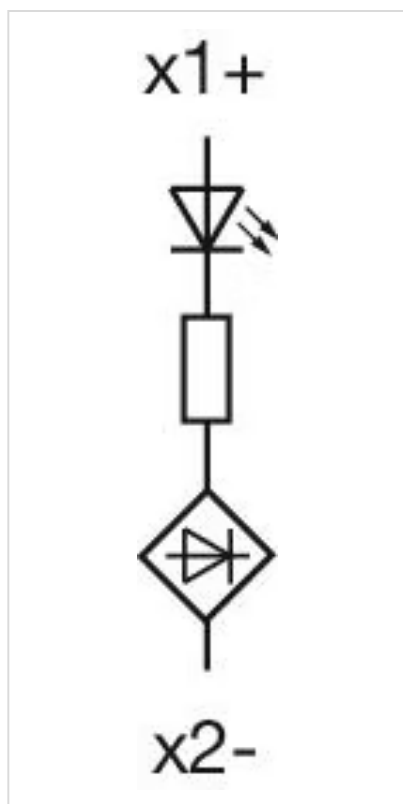

Dimension drawings:

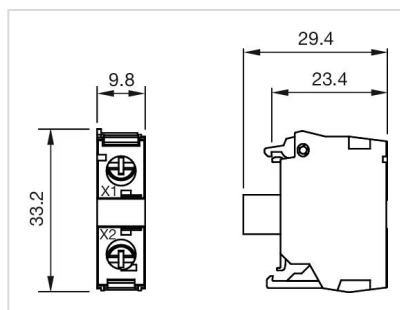

Where to Buy

Distributor		Quantity in Stock		
	Digi-Key	16 in stock	Buy	
	RS UK	12 in stock	Buy	
	Mouser Electronics	7 in stock	Buy	
	Newark Electronics	5 in stock	Buy	
	Rapid Electronics	5 in stock	Buy	

Show more 

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-320.1E12](#)