


Illumination element

45-320.1G16

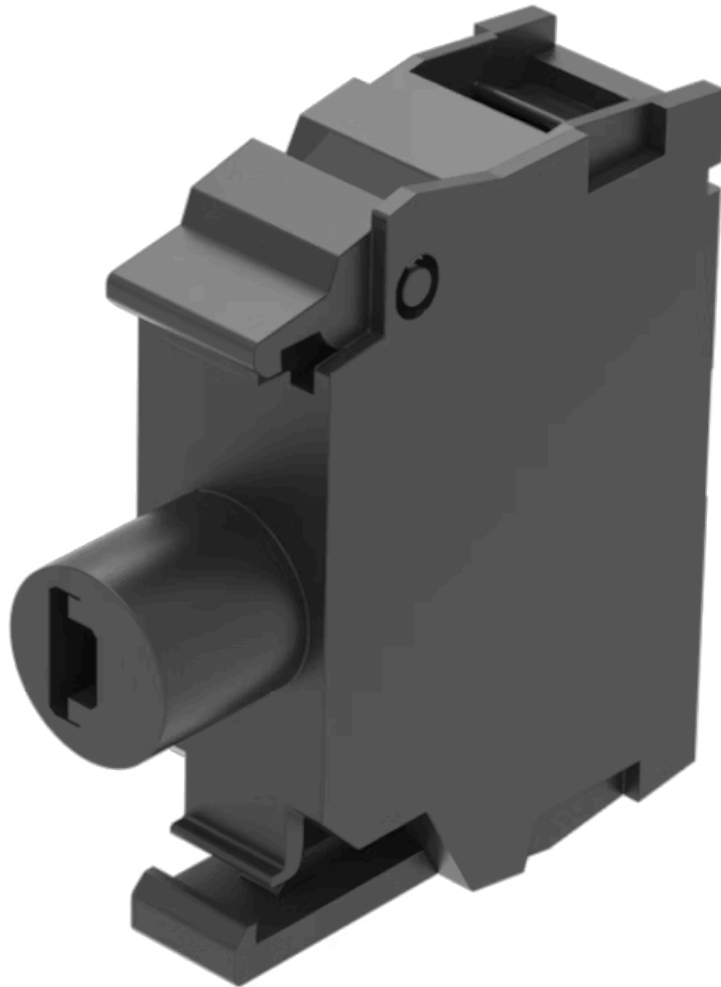

<https://eao.com/p/45-320.1G16>

Your product:



45-320.1G16

Illumination element

MOUNTING

Component mounting type: Front mounting

OPERATING-/INDICATION PART

Illumination colour: Yellow

ELECTRICAL CHARACTERISTICS

Operating voltage: 24 V AC/DC

Surge voltage resistance: 4 kV

Lumi. Intensity: 900 - 1400 mcd

MECHANICAL CHARACTERISTIC

Terminal: Screw terminal

Weight: 0.01 kg

CERTIFICATE


REACH: REACH compliant

RoHS: RoHS compliant


OTHER

Short Description: Illumination element, Screw terminal, Yellow, 24 V AC/DC, Front mounting



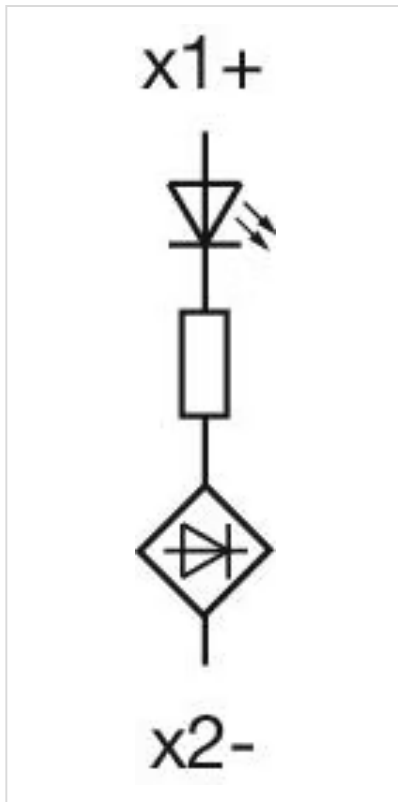



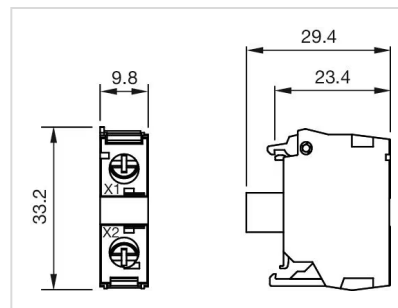



Wiring diagrams:



Dimension drawings:



Where to Buy

Distributor		Quantity in Stock		
	Rapid Electronics	20 in stock	Buy	
	Digi-Key	17 in stock	Buy	
	Newark Electronics	5 in stock	Buy	
	Farnell element14 UK	5 in stock	Buy	
	Transfer Multisort Elektronik	5 in stock	Buy	

Show more +

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-320.1G16](#)