


Illumination element

45-320.1H46

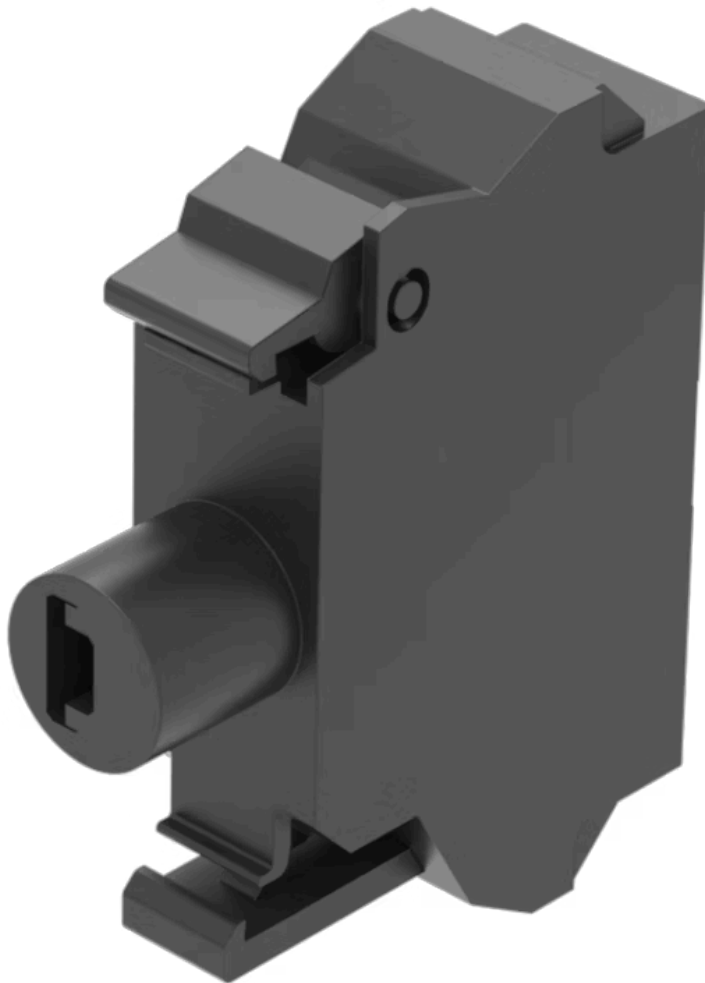

<https://eao.com/p/45-320.1H46>

Your product:



45-320.1H46

Illumination element

MOUNTING

Component mounting type: Front mounting

OPERATING-/INDICATION PART

Illumination colour: Green

ELECTRICAL CHARACTERISTICS

Operating voltage: 24 V AC/DC

Surge voltage resistance: 4 kV

Lumi. Intensity: 900 - 1400 mcd

MECHANICAL CHARACTERISTIC

Terminal: Spring-type terminal

Weight: 0.009 kg

CERTIFICATE


REACH: REACH compliant

RoHS: RoHS compliant


OTHER

Short Description: Illumination element, Spring-type terminal, Green, 24 V AC/DC, Front mounting



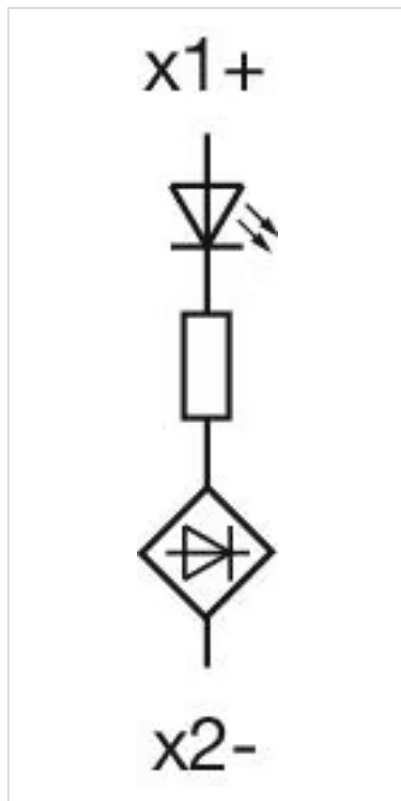



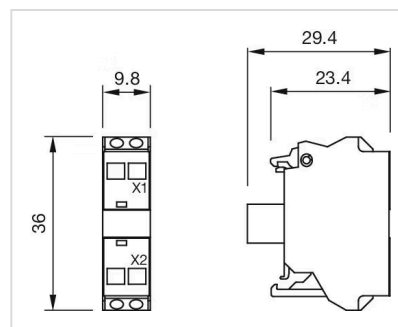


Wiring diagrams:



Dimension drawings:



Where to Buy

Distributor		Quantity in Stock		
	Farnell element14 UK	32 in stock	Buy	
	element14 Singapore	32 in stock	Buy	
	Distrelec	15 in stock	Buy	
	Transfer Multisort Elektronik	7 in stock	Buy	
	RS Americas	4 in stock	Buy	

Show more +

Powered by oemsecrets.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-320.1H46](#)