

# Illumination element

45-320.2N12



<https://eao.com/p/45-320.2N12>

Your product:

---



## 45-320.2N12

### Illumination element

#### MOUNTING

**Component mounting type:** Base mounting

#### OPERATING-/INDICATION PART

**Illumination colour:** White

#### ELECTRICAL CHARACTERISTICS

**Operating voltage:** 24 - 240 V AC/DC

**Surge voltage resistance:** 4 kV

**Lumi. Intensity:** 900 - 1400 mcd

#### MECHANICAL CHARACTERISTIC

**Terminal:** Screw terminal

**Weight:** 0.02 kg

#### CERTIFICATE

**REACH:** REACH compliant


**RoHS:** RoHS compliant

#### OTHER


**Short Description:** Illumination element, Screw terminal, White, 24 - 240 V AC/DC, Base mounting

**Hints:** Illumination element base mounting can used only with enclosure



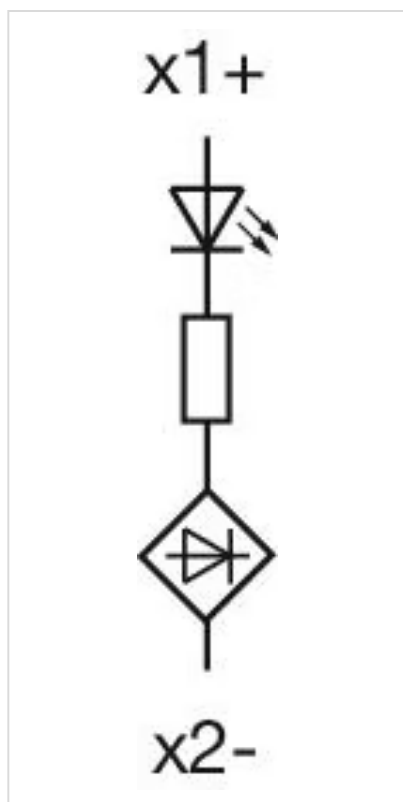



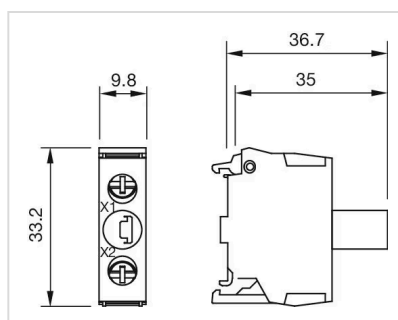



**Wiring diagrams:**



**Dimension drawings:**



Where to Buy

Distributor		Quantity in Stock		
	Digi-Key	10 in stock	Buy	
	Mouser Electronics	0 in stock	Buy	
	RS Americas	0 in stock	Buy	
	Newark Electronics	0 in stock	Buy	
	Sager	0 in stock	Buy	

Powered by oemsecrets.com

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[45-320.2N12](#)