

# Indicator element

84-8001.2620



<https://eao.com/p/84-8001.2620>

Your product:

---



## 84-8001.2620

### Indicator element

#### OPERATING-/INDICATION PART

**Illumination colour:** Red

#### ELECTRICAL CHARACTERISTICS

**Operating voltage:** 24 V DC  $\pm 10\%$

**Lumi. Intensity:** mcd

#### MECHANICAL CHARACTERISTIC

**Terminal:** Plug-in terminal, 2.8 x 0.8 mm

**Weight:** 0.005 kg

#### AMBIENT CONDITION

**IP Protection:** IP40

#### CERTIFICATE

**REACH:** REACH compliant

**RoHS:** RoHS compliant

#### OTHER


**Short Description:** Indicator element, Red, Single-LED, 24 V DC  $\pm 10\%$ , Plug-in terminal, 2.8 x 0.8 mm

**Kind of illumination:** Single-LED







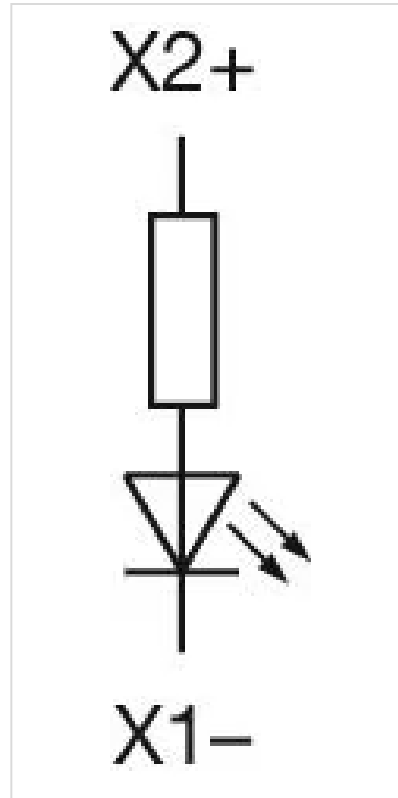



**Hints:** LED and built-in resistor included, Standard version: Cable length 300 mm, Other options on request: Customisation of cable and connectors, rear side fully sealed (IP 67), Protection degree (rear side): IP 40, upgrade to IP 67 with plug Part No. 84-

900 possible. With applications where strong vibrations occur, the plugs may become loose. Luminosity and wave length variations caused by LED manufacturing processes may cause slight differences regarding the illumination. The customer has to decide what resistor shall be used to the LED

**Wiring diagrams:**



Where to Buy

	Distributor	Quantity in Stock	
	Distrelec	42 in stock	<a href="#">Buy</a> 
	RS UK	40 in stock	<a href="#">Buy</a> 
	Mouser Electronics	16 in stock	<a href="#">Buy</a> 
	Farnell UK	10 in stock	<a href="#">Buy</a> 
	DigiKey	5 in stock	<a href="#">Buy</a> 

[Show more](#) 

Powered by oemsecrets.com

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[EAO:](#)

[84-8001.2620](#)